

Test Plugs 4 mm System



Type

VST 100

4mm spring loaded connector pin, nickel plated brass, screw terminal up to 1.5mm².

Pin diameter

4 mm (0.157")

PART NO. / Housing color

930581000



VST 20

4mm spring loaded connector pin, nickel plated brass, M4 thread/ screw terminal up to 2mm².

4 mm (0.157")

930050000

Technical Data

Contact Type	spring loaded pin
Connection Type	screw terminal max. 1.5mm ²
Voltage Rating	30 VAC / 60 VDC
Measurement Category (IEC61010)	CAT I
Current Rating*	16A
Contact Resistance	3 mOhm

Material Specifications

Plug	nickel plated brass
Contact Spring	—
Housing	—

Environmental Conditions

Temperature range	-25 °C to +100°C (-13 to 212°F)
-------------------	---------------------------------

Flamability Rating

Housing	—
---------	---

spring loaded pin
M4 thread / soldering max. 2mm ²
30 VAC / 60 VDC
CAT I
16A
3 mOhm

nickel plated brass

—



—

-25 °C to +100°C (-13 to 212°F)

—

Drawing

Measurements are shown in millimeters.
Multiply by 0.03937 to convert to inches.

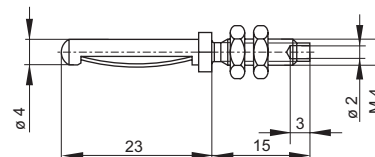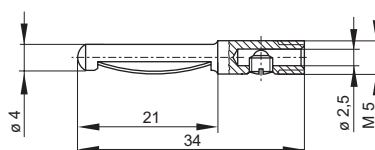

* Please consider derating graph on page 80.