


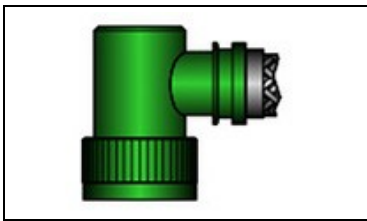

208M914-19B10 Product Details

[Share](#) [Print](#) [Email](#)


208M914-19B10

TE Internal Number: 128431-000

Active

Braid, Fixed, Spin and Tinel Lock Adapters

Not EU RoHS or ELV Compliant ([Find RoHS Compliant Alternates](#))

Product Highlights:

- Applies To Cable
- Military Style Number = MIL-C-38999
- Style = Braided
- Connector Code = 40
- 90°

[View all Features](#)

Quick Links

- ▶ [Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

[Add to My Part List](#) [Request Sample](#) [Find Similar Products](#) [Buy Product](#)

Documentation & Additional Information	
Documents are temporarily unavailable. We are working hard to correct the problem. Please try again later.	Related Products: • Tooling

Product Features (Please use the Product Drawing for all design activity)	
Product Type Features: • Style = Braided • Angle = 90° • Connector Shell Size = 14 • Finish = Cadmium Plating over Electroless Nickel • Color = Olive Drab Dimensions: • Boot Diameter (mm [in]) = 21.10 [0.831] Body Features: • Connector Code = 40 • Entry Size = 10 • Material = Aluminium Alloy	Configuration Features: • Braid = Preattached Single 36 AWG Braid Industry Standards: • Military Style Number = MIL-C-38999 • RoHS/ELV Compliance = Not ELV/RoHS compliant • Lead Free Solder Processes = Not relevant for lead free process Conditions for Usage: • Applies To = Cable Other: • Brand = Raychem • Comment = For Specific shell size information, refer to Harnware™ or Catalouge.

Corporate Information	Quick Links	Customer Support	Keep Me Informed
About TE Investors News Room Supplier Portal Careers Terms & Conditions Privacy Policy AODA Accessibility Policy AODA Multi-Year Accessibility Plan	Distributor Inventory Product Cross Reference Documents & Drawings Product Compliance Support Center Site Map	Email or Chat With Us Find a Phone Number Knowledge Base Manage Your Account	