


RIGHT ANGLE PLUGS CLAMP TYPE FOR FLEXIBLE CABLES

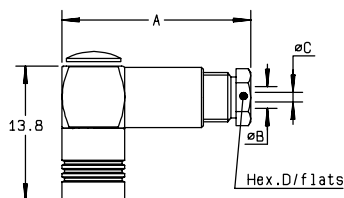

cable	part number	dimensions				captive center contact	assembly	finish	note
		A	B	C	D				
2/50/S	R114 163 000	19	2.2	1	5	yes	M04	Gold	
2/50/S	R114 163 133	16.1	2.2	1	5.5	yes	M05	Gold	conical braid clamp
2.6/50+75/S	R114 165 000	19	3	1.7	5	yes	M04	Gold	
2.6/50+75/S	R114 165 133	16.1	3	1.7	5.5	yes	M05	Gold	conical braid clamp

RIGHT ANGLE PLUGS SOLDER TYPE FOR SEMI RIGID CABLE

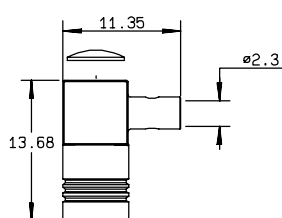


Fig. 1

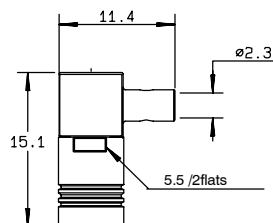


Fig. 2

cable	part number	fig.	captive center contact	assembly	finish	note
.085"	R114 152 000	1	yes	M13	Gold	
.085"	R114 169 000●	2	yes	M07	Gold	cable bending required

● upon request

* packaging: unit