
 


# LT Product Profile

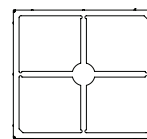

00422-C

**LEADER  
TECH**  
a HEICO company



## Two-Piece SMS Surface Mount Shield

Leader Tech SMS - Surface Mount Shields offer a highly reliable, cost effective, off-the-shelf solution for most surface mount shielding applications. Our SMS shields are supplied in tape & reel packaging and are suited for any volume application including automated pick and place assembly operations.

For board applications that require inspection, we offer a two piece Leader Tech SMS shield. This style allows for fast and easy removal of the cover providing full access to components.

## Applications

- Short lead times
- Automatic placement
- Cost effective
- No tooling costs

## Material

Pre-tin plated steel  
Alloy 770

## Two-Piece SMS Shields

- Two-Piece
- Frame & cover, form down construction (frame supplied in tape & reel packaging)



Frame shown in tape & reel packaging

| TWO-PIECE SURFACE MOUNT SHIELD |               |               |         |                |                  |                 |              |                            |                  |           |  |
|--------------------------------|---------------|---------------|---------|----------------|------------------|-----------------|--------------|----------------------------|------------------|-----------|--|
| Shield Width                   | Shield Length | Shield Height | Vented  | Parts per Reel | Material Options |                 | Part Number* |                            |                  |           |  |
|                                |               |               |         |                | Standard         | **add -N to P/N |              |                            |                  |           |  |
| 0.500                          | 12.700        | 0.538         | 13.665  | 0.100          | 2.540            | No              | 1000         | .008" Pre-Tin Matte Steel  | 008" Alloy 770** | SMS-401   |  |
| 0.500                          | 12.700        | 0.538         | 13.665  | 0.100          | 2.540            | Yes             | 1000         | .008" Pre-Tin Matte Steel  | 008" Alloy 770** | SMS-201   |  |
| 0.650                          | 16.510        | 0.650         | 16.510  | 0.142          | 3.607            | No              | 700          | .008" Pre-Tin Matte Steel  | 008" Alloy 770** | SMS-402   |  |
| 0.650                          | 16.510        | 0.650         | 16.510  | 0.142          | 3.607            | Yes             | 700          | .008" Pre-Tin Matte Steel  | 008" Alloy 770** | SMS-202   |  |
| 0.728                          | 18.491        | 1.156         | 29.362  | 0.276          | 7.010            | No              | 325          | .008" Pre-Tin Matte Steel  | 008" Alloy 770** | SMS-409   |  |
| 0.750                          | 19.050        | 0.750         | 19.050  | 0.200          | 5.080            | Yes             | 300          | .008" Pre-Tin Matte Steel  | 008" Alloy 770** | SMS-255   |  |
| 0.835                          | 21.209        | 1.543         | 39.192  | 0.286          | 7.264            | No              | 280          | .008" Pre-Tin Matte Steel  | 008" Alloy 770** | SMS-456   |  |
| 1.000                          | 25.400        | 1.500         | 38.100  | 0.236          | 5.994            | No              | 250          | .008" Pre-Tin Matte Steel  | 008" Alloy 770** | SMS-405   |  |
| 1.000                          | 25.400        | 1.500         | 38.100  | 0.236          | 5.994            | Yes             | 250          | .008" Pre-Tin Matte Steel  | 008" Alloy 770** | SMS-205   |  |
| 1.034                          | 26.264        | 1.034         | 26.264  | 0.070          | 1.778            | No              | 300          | .010" Pre-Tin Bright Steel | 010" Alloy 770** | SMS-452   |  |
| 1.034                          | 26.264        | 1.034         | 26.264  | 0.070          | 1.778            | Yes             | 300          | .010" Pre-Tin Bright Steel | 010" Alloy 770** | SMS-252   |  |
| 1.034                          | 26.264        | 1.034         | 26.264  | 0.098          | 2.489            | Yes             | 600          | .010" Pre-Tin Bright Steel | 010" Alloy 770** | SMS-254   |  |
| 1.034                          | 26.264        | 1.034         | 26.264  | 0.200          | 5.080            | Yes             | 300          | .008" Pre-Tin Matte Steel  | -                | SMS-203-M |  |
| 1.034                          | 26.264        | 1.034         | 26.264  | 0.200          | 5.080            | No              | 300          | .010" Pre-Tin Bright Steel | 010" Alloy 770** | SMS-403   |  |
| 1.034                          | 26.264        | 1.034         | 26.264  | 0.200          | 5.080            | Yes             | 300          | .010" Pre-Tin Bright Steel | 010" Alloy 770** | SMS-203   |  |
| 1.070                          | 27.178        | 1.304         | 33.122  | 0.236          | 5.994            | No              | 210          | .008" Pre-Tin Matte Steel  | 008" Alloy 770** | SMS-457   |  |
| 1.070                          | 27.178        | 1.540         | 39.116  | 0.236          | 5.994            | No              | 240          | .008" Pre-Tin Matte Steel  | 008" Alloy 770** | SMS-458   |  |
| 1.070                          | 27.178        | 1.623         | 41.224  | 0.236          | 5.994            | No              | 230          | .008" Pre-Tin Matte Steel  | 008" Alloy 770** | SMS-459   |  |
| 1.070                          | 27.178        | 1.767         | 44.882  | 0.236          | 5.994            | No              | 230          | .008" Pre-Tin Matte Steel  | 008" Alloy 770** | SMS-460   |  |
| 1.070                          | 27.178        | 2.206         | 56.032  | 0.236          | 5.994            | No              | 200          | .008" Pre-Tin Matte Steel  | 008" Alloy 770** | SMS-461   |  |
| 1.070                          | 27.178        | 2.758         | 70.053  | 0.236          | 5.994            | No              | 250          | .008" Pre-Tin Matte Steel  | 008" Alloy 770** | SMS-462   |  |
| 1.201                          | 30.505        | 1.732         | 43.993  | 0.118          | 2.997            | No              | 370          | .008" Pre-Tin Matte Steel  | 008" Alloy 770** | SMS-210   |  |
| 1.260                          | 32.004        | 1.260         | 32.004  | 0.236          | 5.994            | No              | 225          | .008" Pre-Tin Matte Steel  | 008" Alloy 770** | SMS-404   |  |
| 1.260                          | 32.004        | 1.260         | 32.004  | 0.236          | 5.994            | Yes             | 225          | .008" Pre-Tin Matte Steel  | 008" Alloy 770** | SMS-204   |  |
| 1.326                          | 33.680        | 1.450         | 36.830  | 0.200          | 5.080            | No              | 300          | .008" Pre-Tin Matte Steel  | 008" Alloy 770** | SMS-406   |  |
| 1.326                          | 33.680        | 1.450         | 36.830  | 0.200          | 5.080            | Yes             | 300          | .008" Pre-Tin Matte Steel  | 008" Alloy 770** | SMS-206   |  |
| 1.500                          | 38.100        | 2.000         | 50.800  | 0.200          | 5.080            | No              | 250          | .012" Pre-Tin Matte Steel  | 012" Alloy 770** | SMS-451   |  |
| 1.559                          | 39.599        | 1.559         | 39.599  | 0.276          | 7.010            | No              | 150          | .008" Pre-Tin Matte Steel  | 008" Alloy 770** | SMS-408   |  |
| 1.747                          | 44.374        | 1.747         | 44.374  | 0.384          | 9.754            | No              | 120          | .008" Pre-Tin Matte Steel  | 008" Alloy 770** | SMS-407   |  |
| 1.747                          | 44.374        | 1.747         | 44.374  | 0.384          | 9.754            | Yes             | 120          | .008" Pre-Tin Matte Steel  | 008" Alloy 770** | SMS-207   |  |
| 1.805                          | 45.847        | 3.979         | 101.067 | 0.236          | 5.994            | No              | 130          | .008" Pre-Tin Matte Steel  | 008" Alloy 770** | SMS-463   |  |

Black = inches Blue = mm

\*SMS-4XX-C: Part number when ordering cover only | SMS-4XX-F: Part number when ordering frame only

\*\*When ordering Alloy 770 include '-N' in part number. Example: SMS-2XX-N

**LEADER  
TECH**  
a HEICO company

**Global EMI Shielding Technology Center**  
12420 Race Track Rd., Tampa, Florida 33626  
866.TECH.EMI (866.832.4364) t 813.855.6921 f 813.855.3291

STATEMENT OF LIEU OF WARRANTY: All technical information and data in this document is based on tests and is believed to be accurate and reliable. Nevertheless, since the products described herein are not provided to conform with mutually accepted specifications and the use thereof is unknown, the manufacturer and seller of the products do not guarantee results, freedom from patent infringement, or suitability of the products for any application thereof. The manufacturer and seller of the products described in this document will provide all possible technical assistance and will replace any products proven defective. No statement or recommendations made by the manufacturer or seller not contained herein shall have any force of effect unless in conformity with an agreement signed by an officer of the seller and manufacturer. Product testing by the purchaser is recommended in order to confirm expected results.



[www.LeaderTechInc.com](http://www.LeaderTechInc.com)

ISO 9001: 2015  
CERTIFIED

RoHS  
COMPLIANT

Copyright© Leader Tech, Inc. 2018