



800U SERIES PUSHBUTTON SWITCH

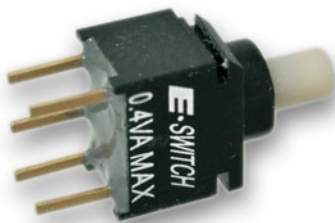

APPLICATIONS / MARKETS

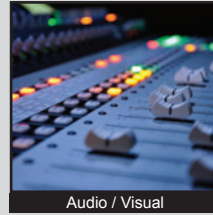

Audio / Visual




Consumer Electronics



Vending Machines



Kiosks

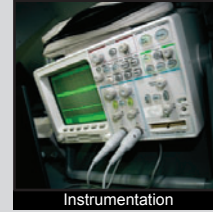

Instrumentation



Medical Equipment

RoHS

SPECIFICATIONS

Electrical Rating: 0.4VA @ 20V Max (AC or DC)
Mechanical Life: 40,000 Cycles
Electrical Life: 6,000 Cycles
Contact Resistance: 100mΩ initial
Insulation Resistance: 500 MΩ Min.
Dielectric Strength: 500VAC
Operating/Storage Temperature: -30°C to 85°C
Travel: 1.0mm
Circuit Function: SPDT, DPDT
Actuation Force: 250 gf

FEATURES & BENEFITS

- Ultra-miniature in size
- IP67 rated
- Multiple termination options
- Multiple cap colors
- Single or double pole

PART NUMBER CONFIGURATOR

Series	Circuit	Function	Actuator	Bushing	Terminal	Contact Material	Seal	Cap	Cap Color
8 0 0 U	S P	8	P 1	A 1	M 2	R	E	N R	N
800U	SP - Single Pole DP - Double Pole	8 - ON - (ON)*	P1 - 3.30 High	A1 - 1.6 High	M2 - PC thru-hole M6 - Right Angle, PC thru-hole M7 - Vertical right angle, PC thru-hole	R - Gold	E - Epoxy	None R1 - 4.0 dia. round	None BLK - Black RED - Red WHT - White

CAP CONFIGURATOR*

Series	Cap Style	Cap Color
8 0 0 U	R 1	B L K R E W H T
800U	R1	BLK - Black RED - Red WHT - White

* () denotes momentary

*You can order just the switch with or without the cap using the first ordering code above, or you can order the cap as a separate part number using the smaller ordering code directly above.

Specifications subject to change without notice



E-SWITCH®

www.e-switch.com



800.867.2717

2



800U SERIES PUSHBUTTON SWITCH

SPDT DIMENSIONS




M2 Termination

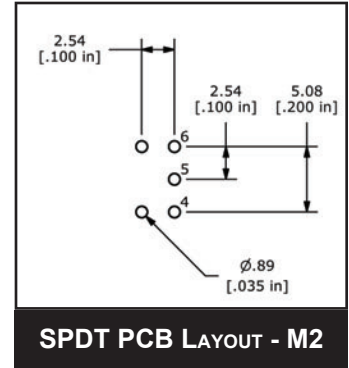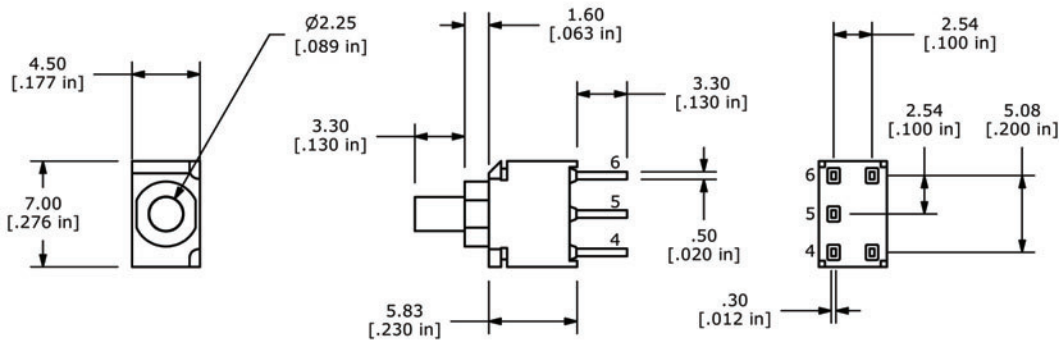

M6 Termination

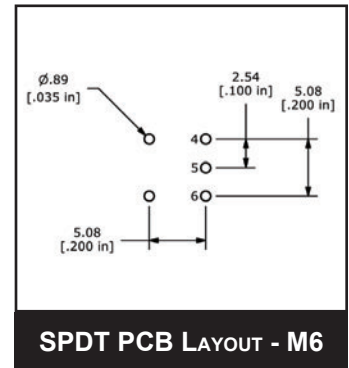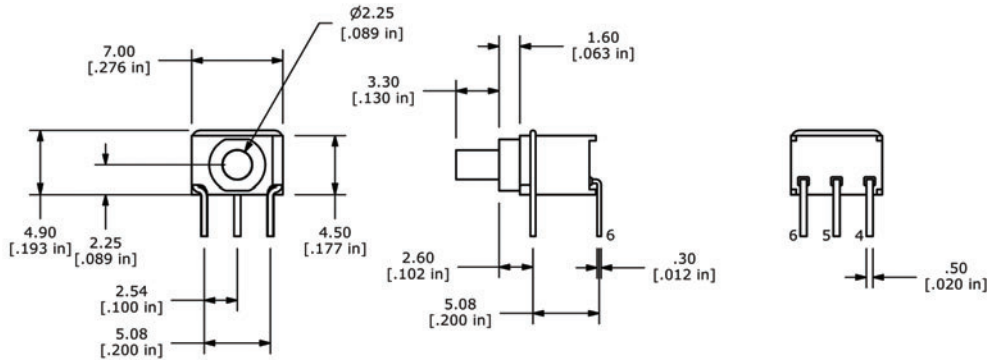


M7 Termination

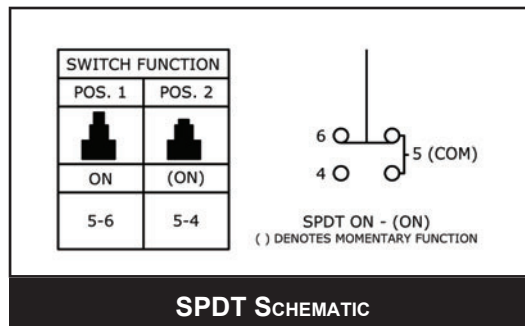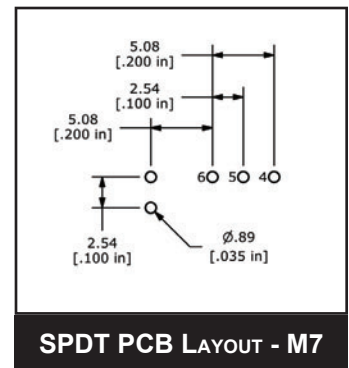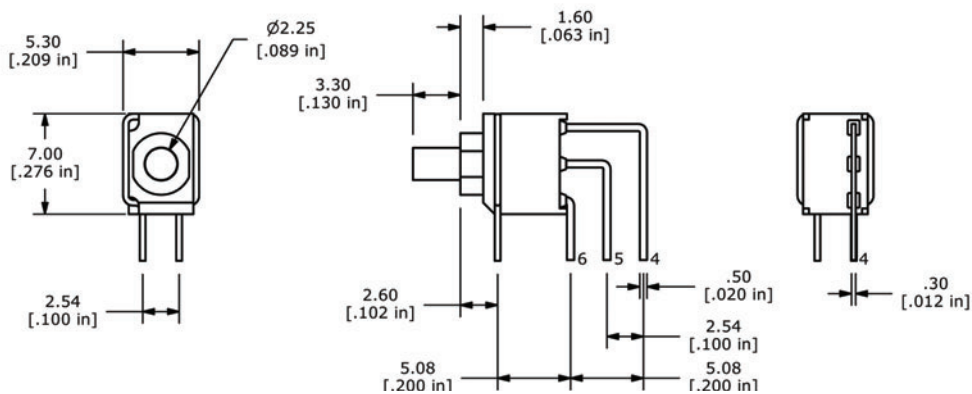

800U SERIES PUSHBUTTON SWITCH


DPDT DIMENSIONS

M2 Termination

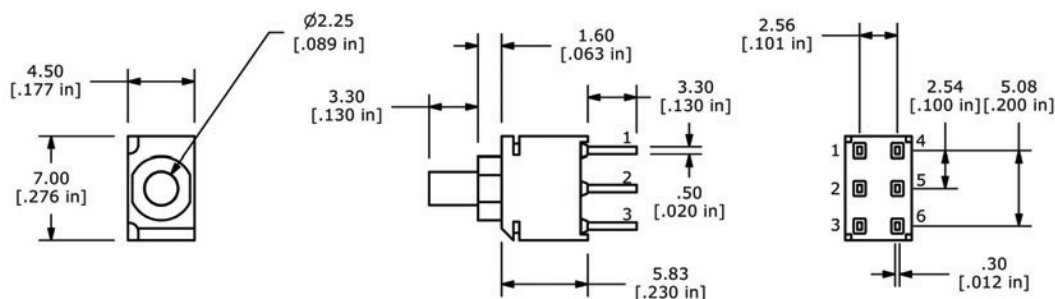


DPDT PCB LAYOUT - M2

M6 Termination

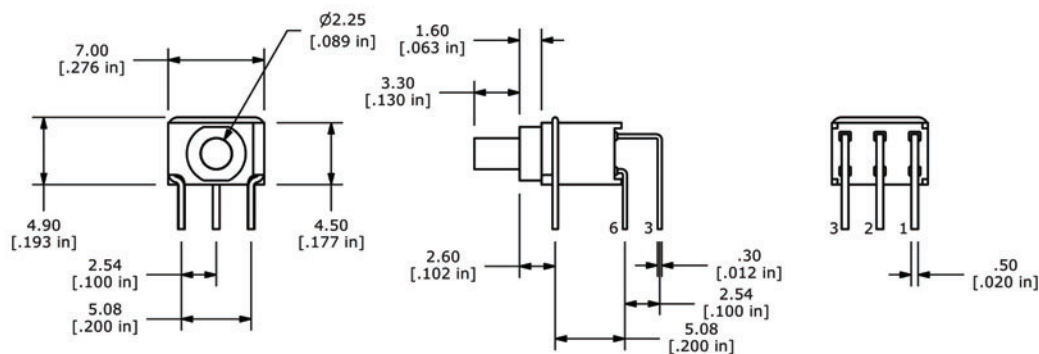


DPDT PCB LAYOUT - M6

M7 Termination

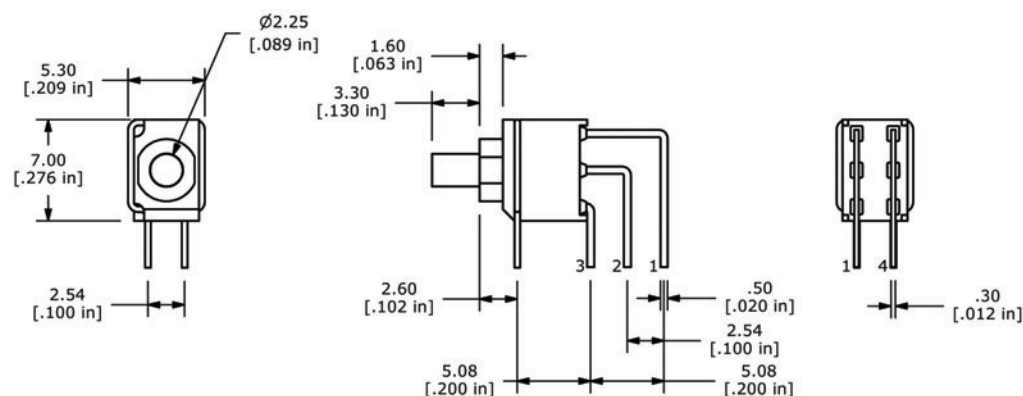


DPDT PCB LAYOUT - M7

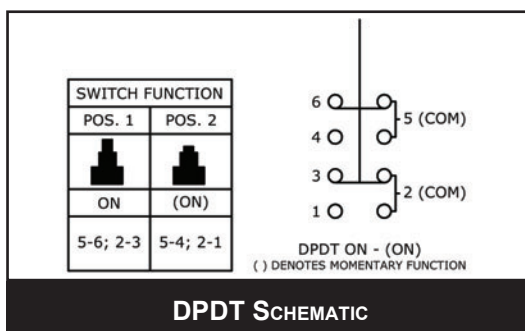


BUTTON POSITIONING

For specifications, please refer to the dimensions on previous pages.


M2 Button

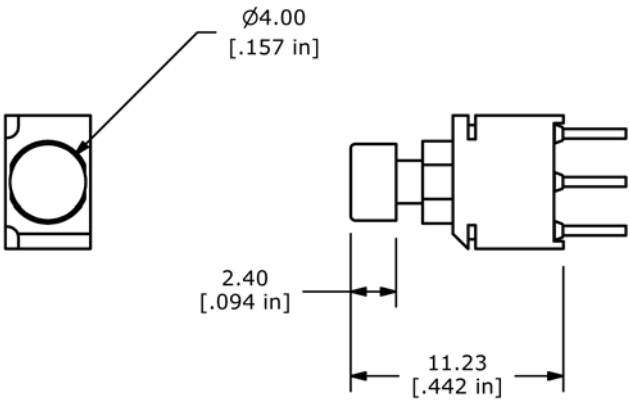

M6 Button

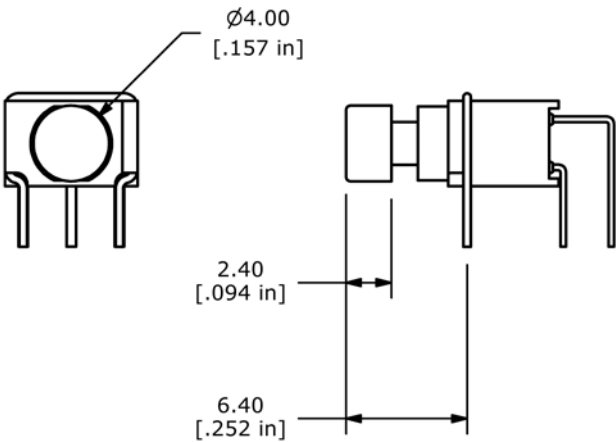

M7 Button

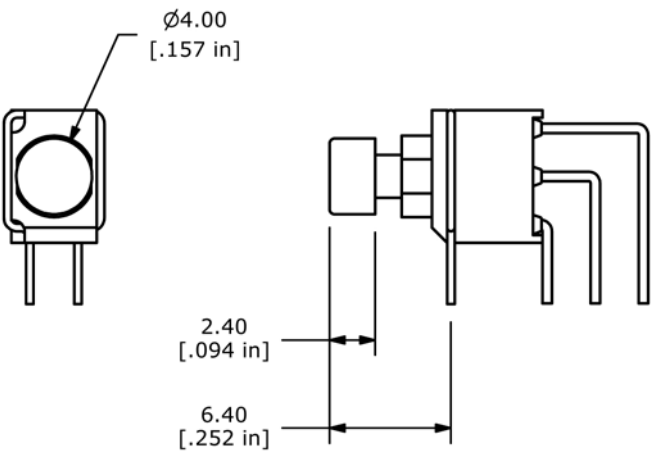

ANTI-VANDAL SWITCHES
DETECTOR SWITCHES
DIP SWITCHES
KEYLOCK SWITCHES
NAVIGATION SWITCHES
PUSHBUTTON SWITCHES
ROCKER SWITCHES
ROTARY SWITCHES
SLIDE SWITCHES
SNAP ACTION SWITCHES
TACTILE SWITCHES
TOGGLE SWITCHES
CAP OPTIONS