


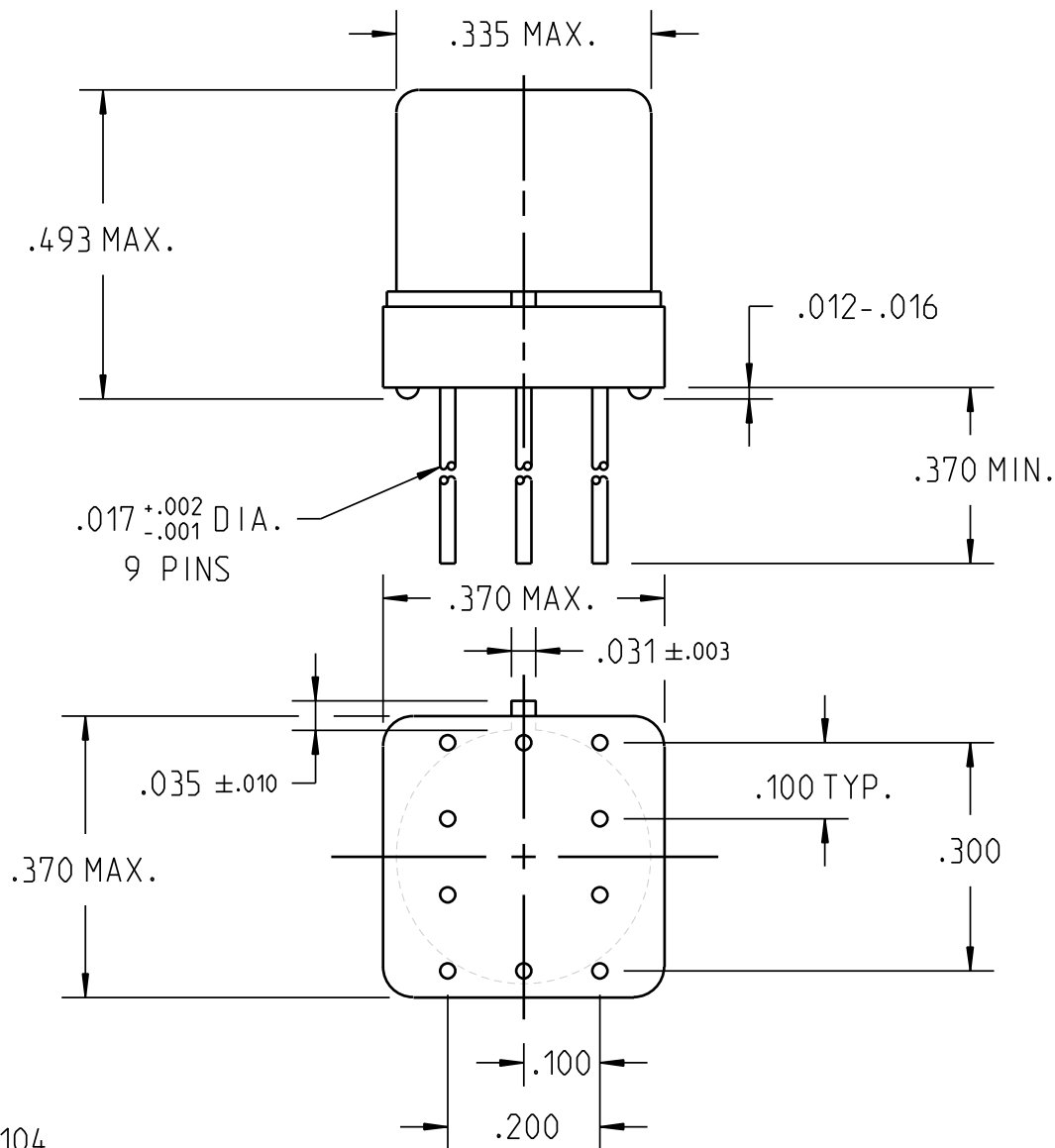


REV. 0
DCO 144104

COIL: @ 25°C
RESISTANCE 100 OHMS $\pm 10\%$
NOMINAL VOLTAGE 5 VDC
MUST OPERATE 2.8 VDC
TURN-ON BASE (CURRENT) .37 mADC
MUST RELEASE 1.4 VDC MAX, 0.22 MIN

ENVIRONMENT:
VIBRATION 10 Hz TO 3000 Hz @ 30 g's
SHOCK 75 g's 6 MS. DURATION
TEMPERATURE -65 °C TO +125 °C
NOTES: TURN-ON TIME 4.0 MS MAX
TURN-OFF TIME 7.5 MS MAX
CONTACT BOUNCE 1.5 MS MAX

CUSTOMER DATA SHEET

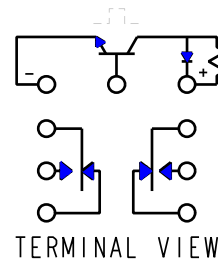

CONTACT RATING: LOW LEVEL TO
1A 28 VDC RESISTIVE 100,000
OPERATIONS

DR. ASB 170CT05 CK. JERRY C 10/17/05

CII Technologies
advanced control electronic solutions

CUST. QPL
CUST. NO. M28776/3-041L REV.

"JMST" RELAY

JMST-5XLS