



Connectors > Connector Accessories > Connector Caps & Covers



Connector Cover Type: Dust Cap

Features

Product Type Features

Connector Cover Type	Dust Cap
----------------------	----------

Housing Features

Compatible With Connector Shape	D-Shaped
---------------------------------	----------

Industry Standards

UL Flammability Rating	UL 94V-0
------------------------	----------

Packaging Features

Packaging Quantity	1500
Packaging Method	Bag

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2024 (240) Candidate List Declared Against: JAN 2024 (240) Does not contain REACH SVHC



Halogen Content	Not Low Halogen - contains Br or Cl > 900 ppm.
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # 2-5175677-9
CHAMP.050 PLUG CONN KIT 100P PB-FREE

Also in the Series | AMPLIMITE 0.50 Series



Connector Backshells(31)



Connector Caps & Covers(21)



Connector Hardware(7)



IDC D-Sub Connectors(64)



Insertion & Extraction Tools(1)



PCB D-Sub Connectors(172)



Customers Also Bought



TE Part #2-1986711-3
SCREWLESS, SW,23P,5.0 PCB



TE Part #1-2307729-6
16P,2MM,B-B,REC,DRHZ,SMD,0.1AU, TR



TE Part #2-1617108-3
HS-26B = HS RELAY




TE Part #2-1658048-1
MSB0.80PL19ASY040FL,-,F,-TY



TE Part #2031991-1
SDE JPT 12-24AWG ASSY



TE Part #2367197-5
1.0mm WTB Side Vertical Type With Latch

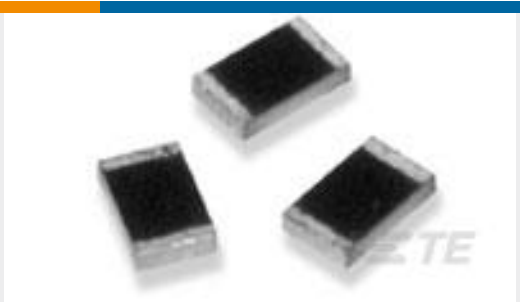

TE Part #5-1879272-8
RP 2A 374R 0.1% 15PPM CUT LENGTH



TE Part #2176368-2
RQ 0603 51K1 0.1% 10PPM 1K RL



TE Part #1-2176375-3
RQ 0805 1K54 0.1% 10PPM 1K RL

Documents

- CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_174528-9_L.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_174528-9_L.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_174528-9_L.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

- Product Specifications

Application Specification

English



Agency Approvals

UL

English