




MAK - Non-Contact Magnetic Switches



Switch					
Standard Version	New UL Version	Standard Version	New UL Version	Standard Version	New UL Version
MAK-4236-3	MAK-4236-BCD-3	MAK-5236-3	MAK-5236-BCD-3	MAK-5336-3	MAK-5336-BCD-3
649.0642.315	649.0642.315	649.0652.316	649.0652.327	649.0653.317	649.0653.323
3 m PVC cable	3 m PVC cable	3 m PVC cable	3 m PVC cable	3 m PVC cable	3 m PVC cable
MAK-4236-6	MAK-4236-BCD-6	MAK-5236-6	MAK-5236-BCD-6	MAK-5336-6	MAK-5336-BCD-6
649.0642.302	649.0642.319	649.0652.307	649.0652.328	649.0653.311	649.0653.324
6 m PVC cable	6 m PVC cable	6 m PVC cable	6 m PVC cable	6 m PVC cable	6 m PVC cable
MAK-4236-9	MAK-4236-BCD-9	MAK-5236-9	MAK-5236-BCD-9	MAK-5336-9	MAK-5336-BCD-9
649.0642.303	649.0642.320	649.0652.308	649.0652.329	649.0653.312	649.0653.325
9 m PVC cable	9 m PVC cable	9 m PVC cable	9 m PVC cable	9 m PVC cable	9 m PVC cable
MAK-4236-STK	MAK-4236-BCD-M8	MAK-5236-STK	MAK-5236-BCD-M8	MAK-5336-STK	MAK-5336-BCD-M12
649.0642.305	649.0642.321	649.0652.309	649.0652.322	649.0653.313	649.0653.326
4-pin connector	4-pin connector	4-pin connector	4-pin connector	4-pin connector	4-pin connector

Actuator and Safety Controller Sold Separately

-5 °C/+70 °C	-5 °C/+70 °C	-5 °C/+70 °C	-5 °C/+70 °C	-5 °C/+70 °C	-5 °C/+70 °C
+23 °F/+158 °F	+23 °F/+158 °F	+23 °F/+158 °F	+23 °F/+158 °F	+23 °F/+158 °F	+23 °F/+158 °F
IP67	IP67	IP67	IP67	IP67	IP67
PA 6.6	PA 6.6	PBT	PBT	PA 6.6	PA 6.6
4 mm	4 mm	3 mm	3 mm	3 mm	3 mm
14 mm	14 mm	14 mm	14 mm	14 mm	14 mm
Actuator					
TK-42-CD	TK-42-CD	TK-52-CD/2	TK-52-CD/2	TK-43-CD	TK-43-CD
640.2042.310	640.2042.310	640.2052.311	640.2052.311	640.2043.312	640.2043.312
Safety Controllers					
639.2701.306	639.2701.306	639.2701.306	639.2701.306	639.2701.306	639.2701.306
639.2702.307	639.2702.307	639.2702.307	639.2702.307	639.2702.307	639.2702.307

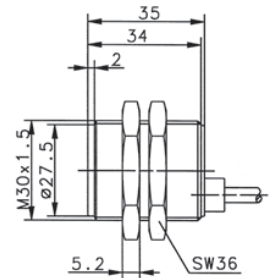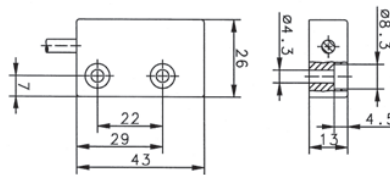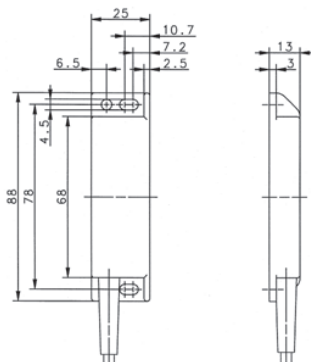

Drawing dimensions in mm