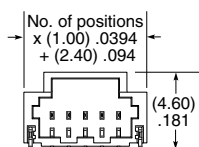
 
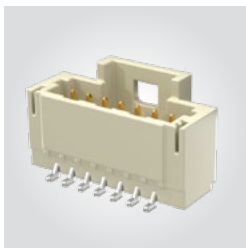
 
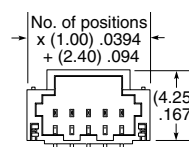
 


(1.00 mm) .0394" PITCH • DISCRETE WIRE TERMINAL STRIP

SERIES	NO. OF POSITIONS	PLATING OPTION	ROW OPTION	LATCH	OPTIONS	"X"R
T1M	-02, -03, -05, -07, -10, -15, -20	-F = 3 μ " (0.07 μ m) Gold on contact, Matte Tin on tail	-SH = Single Row Horizontal -SV = Single Row Vertical	(Required in callout) -L = Positive Latch	-K = (4.00 mm) .157" DIA Polyimide Film Pick & Place Pad (-SH only) -P = Pick & Place Pad (-SV only)	(Leave blank for Tape & Reel) -FR = Full Reel Tape & Reel (must order max. quantity per reel; contact Samtec for quantity breaks)

T1M-SH/SV

Cable Mates:
S1SS(T), S1SD(T)

**-SH****-SV****SPECIFICATIONS**

Insulator Material:
Natural LCP

Terminal Material:
Phosphor Bronze

Plating:

Sn or Au over
50 μ " (1.27 μ m) Ni

Operating Temp Range:

-55 °C to +125 °C

(Component only)

Voltage Rating:






250 VAC/353 VDC

View complete specifications at: samtec.com?T1M

SERIES	NO. OF POSITIONS	PLATING OPTION	ROW OPTION	OPTION	"X"R
T1M	-02, -03, -04, -05, -10, -15, -20 (Per Row)	-GF = 3 μ " (0.07 μ m) Gold contact and tail	-DH = Double Row Horizontal -DV = Double Row Vertical	-K = (4.00 mm) .157" DIA Polyimide Film Pick & Place Pad (-DV only)	(Leave blank for Tape & Reel) -FR = Full Reel Tape & Reel (must order max. quantity per reel; contact Samtec for quantity breaks)

T1M-DH/DV

Cable Mates:
S1SS(T), S1SD(T)

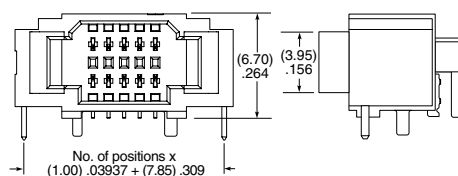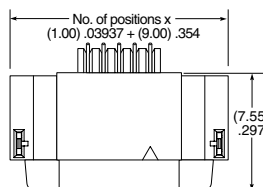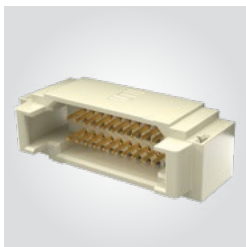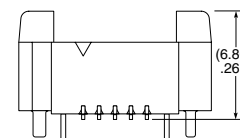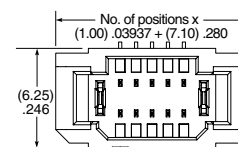**-DH****-DV****SPECIFICATIONS**

Insulator Material:
Natural LCP

Terminal Material:
Phosphor Bronze

Plating: Sn or Au over
50 μ " (1.27 μ m) Ni

Operating Temp Range:

-55 °C to +125 °C

(Component only)

Voltage Rating:

250 VAC/353 VDC

View complete specifications at: samtec.com?T1M

Note:
Some lengths, styles and options
are non-standard, non-returnable.