


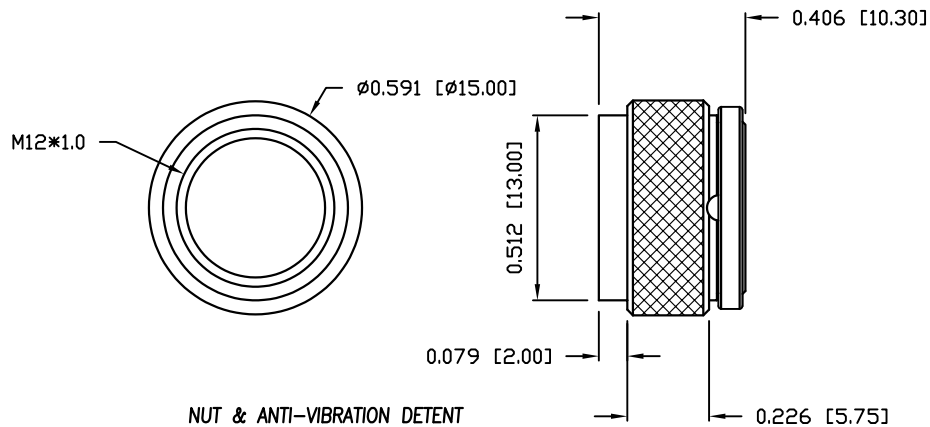


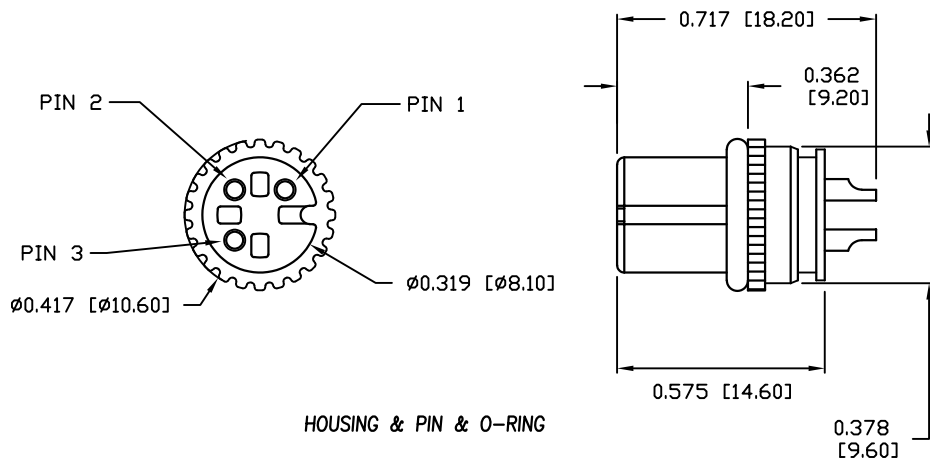

NUT & ANTI-VIBRATION DETENT

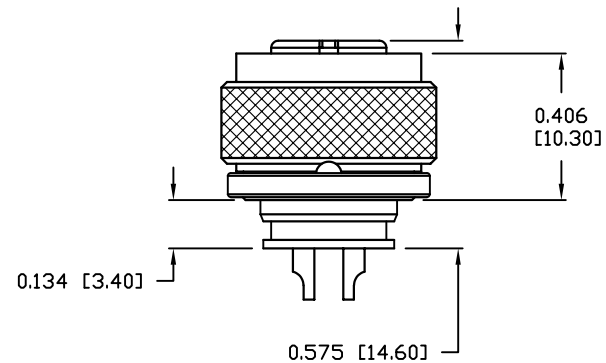

HOUSING & PIN & O-RING

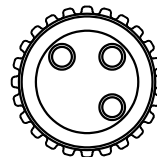

NOTE:

MATERIAL

HOUSING:

PA66 UL94V-0, BLACK

CONTACT:

BRASS

NUT:

BRASS

O-RING:

EPDM, BLACK

FINISH

CONTACT:

10u" GOLD PLATED

NUT:

NICKEL

ELECTRICAL

RATED CURRENT:

4A

RATED VOLTAGE:

250V

INSULATOR RESISTANCE:

100 MOhms MIN.

CONTACT RESISTANCE:

10 mOhms MAX.

WATER PROOF:

IP67

ENVIRONMENT

OPERATION TEMPERATURE:

-40°C TO +85°C

MAX WIRE AWG:

22 AWG

PLEASE NOTE THAT THE ANTI-VIBRATION DETENT IS MADE FROM PLASTIC AND IS NOT DESIGNED TO WITHSTAND MATING AND UN-MATING CYCLING; THIS WILL RESULT IN FAILURE OF THE ANTI-VIBRATION DETENT

RoHS COMPLIANT



THESE DRAWINGS AND SPECIFICATIONS ARE THE PROPERTY OF NorComp AND SHALL NOT BE REPRODUCED, COPIED OR USED AS THE BASIS FOR THE MANUFACTURE OR SALE OF APPARATUS WITHOUT WRITTEN PERMISSION.

DRAWN:

M. SIGMON

DATE:

08/04/2016

UNITS = inch [mm]

DO NOT SCALE FROM DRAWING

NorComp

SCALE:

NTS

SHEET

OF

1

1

REV

4

DWG NO.

858VA03-203RLU4