


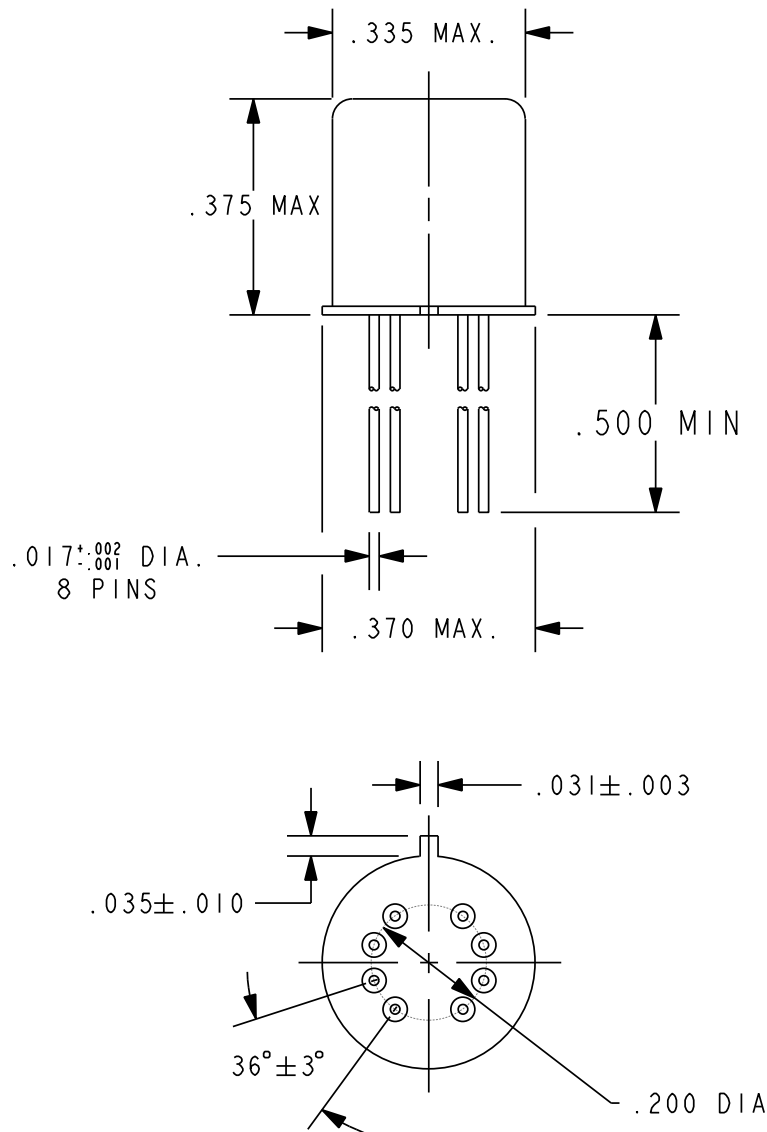


REV. 0
DCO 144009

COIL: @ 25°C
RESISTANCE 3300 OHMS ±10%
NOMINAL VOLTAGE 26.5 VDC
MUST OPERATE 15.2 VDC
MUST RELEASE 10.8 VDC MAX, 1.7 VDC MIN.

ENVIRONMENT:
VIBRATION 10 Hz TO 3000 Hz @ 30 g's
SHOCK 75 g's 6 MS. DURATION
TEMPERATURE -65 °C TO +125 °C
NOTES: OPERATE TIME 4.0 MS MAX.
RELEASE TIME 7.5 MS MAX.
CONTACT BOUNCE 1.5 MS MAX.

CUSTOMER DATA SHEET

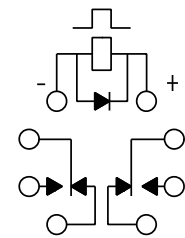

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 1A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. B.D. 08MAR2005 CK. JERRY C. 3/8/05

CII Technologies
advanced control electronic solutions

CUST. QPL
CUST. NO. M39016/21-038L REV.

"JMSDD" RELAY

JMSCDD-26XL