


**Mallory Sonalert Products, Inc.**Part #: **SBS12CLHSPPC****Sales Outline Drawing**Revision: **F**

| Specifications:               | cUL Recognized to IEC60601-1-8 AMD1             |                                                     |                                                     |                                                        |
|-------------------------------|-------------------------------------------------|-----------------------------------------------------|-----------------------------------------------------|--------------------------------------------------------|
|                               | Cardiac Melody                                  |                                                     |                                                     |                                                        |
| Sound Level Category:         | Silence                                         | Extra Loud                                          | Extra Loud                                          | Extra Loud                                             |
| Mode of Operation:            | Silence - NO SOUND - See Note 1                 | Low Priority Alarm - 2 beeps repeating every 20 sec | Slow Pulse @ 1PPS                                   | High Priority Alarm - 10 beeps repeating every 2.5 sec |
| Loudness @ 10cm:              | Silence                                         | 95 to 105 dB(A) Typ.                                | 95 to 105 dB(A)                                     | 95 to 105 dB(A)                                        |
| Frequency:                    | Silence                                         | 150 to 4000 Hz                                      | 2500 $\pm$ 300 Hz                                   | 150 to 4000 Hz                                         |
| Connection:                   | Connect "+" to "+" & "-" to "-" of Power Supply | Connect "+" to "+" & "-" & L to "-" of Power Supply | Connect "+" to "+" & "-" & M to "-" of Power Supply | Connect "+" to "+" & "-" & H to "-" of Power Supply    |
| Voltage Rating:               | 9 to 12 VDC                                     |                                                     |                                                     |                                                        |
| Average Current Draw:         | <40mA Typ.                                      | <70mA Typ.                                          | <250mA Typ.                                         | <200mA Typ.                                            |
| Ipk Current*:                 | 630mA                                           |                                                     |                                                     |                                                        |
| Housing Material:             | ABS 777D Plastic Resin, Black                   |                                                     |                                                     |                                                        |
| Storage Temperature:          | -40° to +85° C                                  |                                                     |                                                     |                                                        |
| Operating Temperature:        | -30° to +65° C                                  |                                                     |                                                     |                                                        |
| Weight Typical:               | 1.1 oz (32g)                                    |                                                     |                                                     |                                                        |
| Options:                      | Please contact factory.                         |                                                     |                                                     |                                                        |
| Condition by wave solder (°C) | 260 $\pm$ 5 within 5 sec                        |                                                     |                                                     |                                                        |
| Condition by hand solder (°C) | 350 $\pm$ 20 within 5 sec                       |                                                     |                                                     |                                                        |

**Dimensions:** Inches [mm]**cUL Recognized****ROHS Compliant**

PATENT NUMBER: 7880593

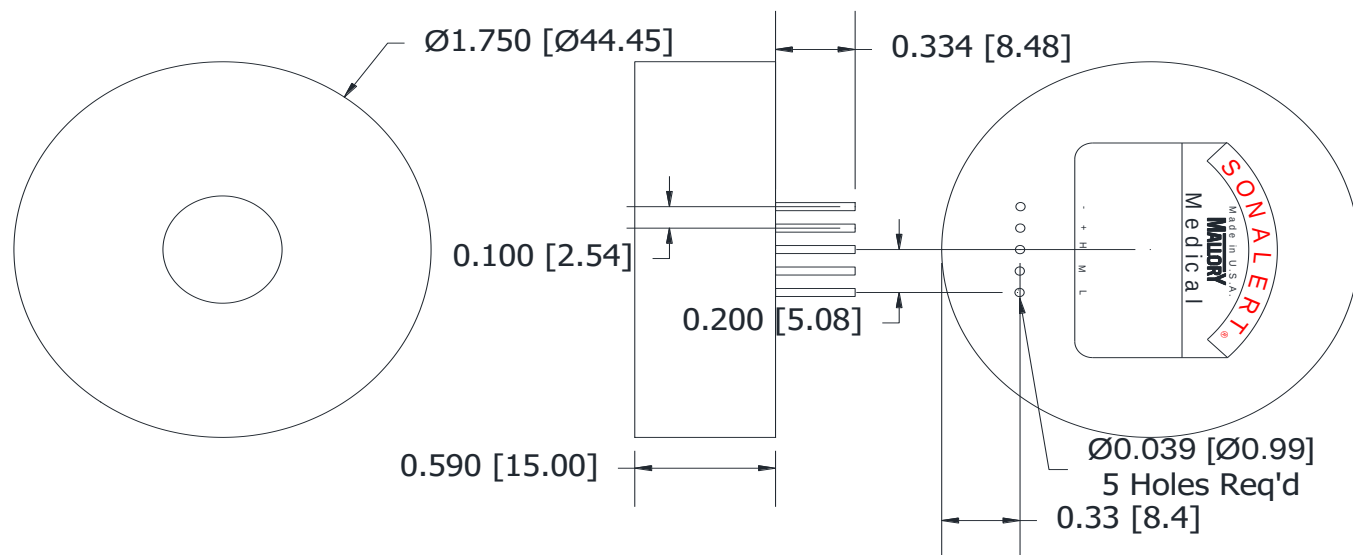

Note 1: Not intended to be energized when alarm not in use.

\*Ipk = Instantaneous Peak

tolerances:  $\pm 0.01$  [ $\pm 0.3$ ]  
 $\pm 0.005$  [ $\pm 0.1$ ]