



INSULATED BULKHEAD JACK RECEPTACLE
FR. MOUNT. WITH SOLD. POT CONT.+TAG-P100

R141.574.161



Series : BNC-COM

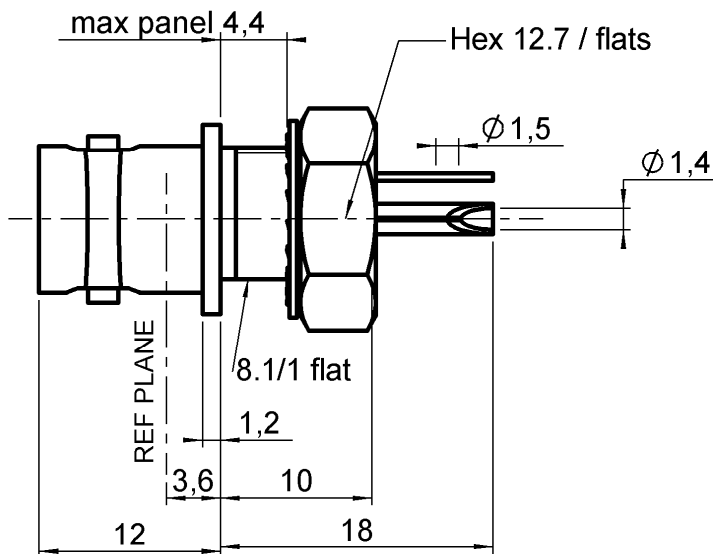

 
PANEL CUT OUT



	mm	
	Maxi	mini
A	9.7	9.6
B	8.9	8.8

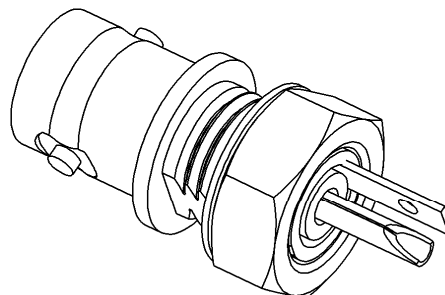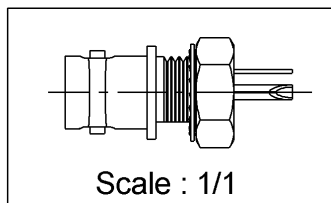

All dimensions are in mm.

 

COMPONENTS	MATERIALS	PLATING (µm)
BODY	NORYL	-
CENTER CONTACT	BRASS	GOLD 0.2 OVER NICKEL 2
OUTER CONTACT	BRASS	NICKEL 2
INSULATOR	NORYL	-
GASKET	-	-
OTHERS PARTS	-	-
-	-	-
-	-	-

Issue : 0907 D

In the effort to improve our products, we reserve the right to make changes judged to be necessary.

RADIAL 

INSULATED BULKHEAD JACK RECEPTACLE
FR. MOUNT. WITH SOLD. POT CONT.+TAG-P100

R141.574.161

Series : BNC-COM

PACKAGING

Standard	Unit	Other
100	'W' option	Contact us

SPECIFICATION**ELECTRICAL CHARACTERISTICS**

Impedance	50	Ω
Frequency	0-1.5	GHz
VSWR	1.08 + 0,0060	x F(GHz) Maxi
Insertion loss	.025*	$\sqrt{F}(\text{GHz})$ dB Maxi
RF leakage	- (57	- F(GHz)) dB Maxi
Voltage rating	500	Veff Maxi
Dielectric withstanding voltage	1500	Veff mini
Insulation resistance	5000	M Ω mini

ENVIRONMENTAL

Operating temperature	-35/+70	$^{\circ}\text{C}$
Hermetic seal	NA	Atm.cm3/s
Panel leakage	NA	

OTHER CHARACTERISTICS

Assembly instruction

Others :

* Coaxial Transmission Line Only

MECHANICAL CHARACTERISTICS

Center contact retention	
Axial force – Mating end	15 N mini
Axial force – Opposite end	15 N mini
Torque	NA N.cm mini
Recommended torque	
Mating	NA N.cm
Panel nut	80 N.cm
Mating life	100 Cycles mini
Weight	4,7700 g

Issue : 0907 D

In the effort to improve our products, we reserve the right to make changes judged to be necessary.

RADIAL 