

Straight Panel Jack Receptacle

- Extended contact and insulator
- 1/2" square flange

Captive contact:


9004-1113-000 (Gold plated)

9004-9113-000 (Passivated)

Noncaptive contact:

9004-1213-000 (Gold plated)

9004-9213-000 (Passivated)

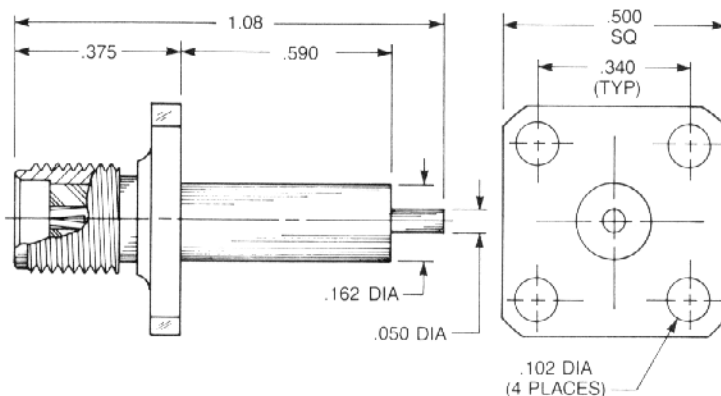

Straight Panel Jack Receptacle

- Extended contact and insulator
- 2-hole flange

Captive contact:


9008-1113-000 (Gold plated)

9008-9113-000 (Passivated)

Noncaptive contact:

9008-1213-000 (Gold plated)

9008-9213-000 (Passivated)

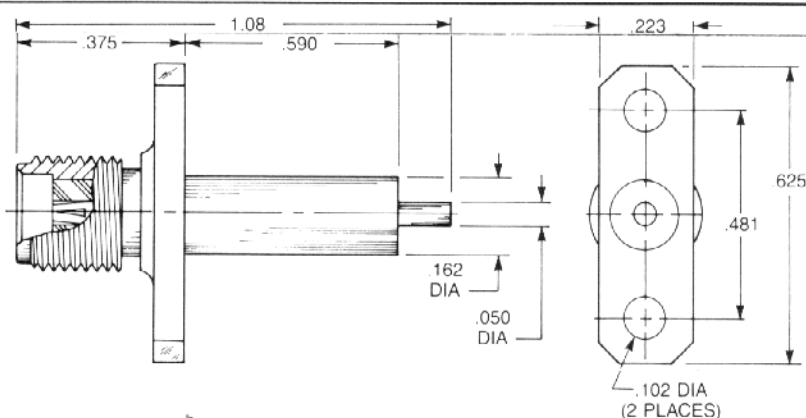

Straight Panel Jack Receptacle

- Extended contact and insulator
- 3/8" square flange

Captive contact:


9076-1113-000 (Gold plated)

9076-9113-000 (Passivated)

Noncaptive contact:

9076-1213-000 (Gold plated)

9076-9213-000 (Passivated)

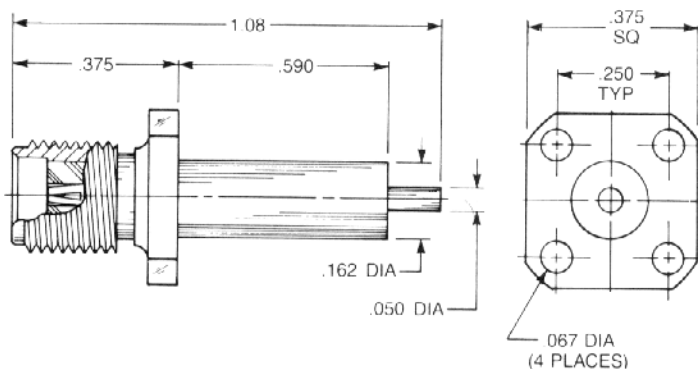

Straight Panel Jack Receptacle

- Extended contact and insulator
- Rectangular flange

Captive contact:


9007-1113-000 (Gold plated)


9007-9113-000 (Passivated)

Noncaptive contact:

9007-1213-000 (Gold plated)

9007-9213-000 (Passivated)

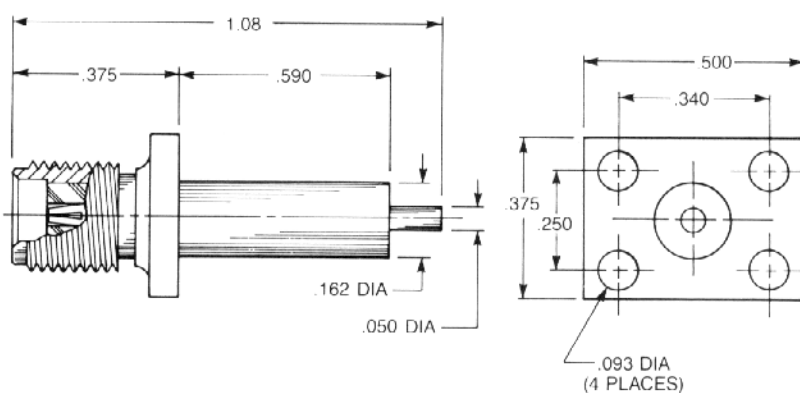

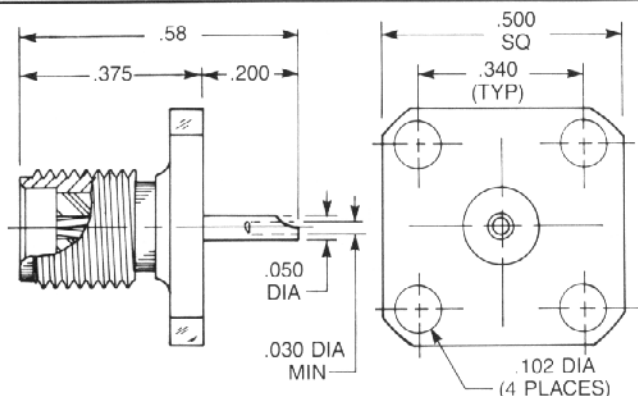

Straight Panel Jack Receptacle


- Solder pot contact
- 1/2" square flange

Captive contact:

9404-1113-000 (Gold plated)

9404-9113-000 (Passivated)

QPL version available (M39012/60)

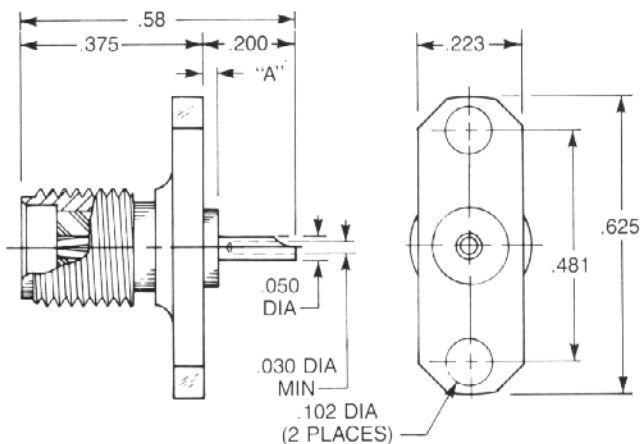

Straight Panel Jack Receptacle

- Solder pot contact
- 2-hole flange

Captive contact (A = .030):

9408-1113-000 (Gold plated)


9408-9113-000 (Passivated)

Captive contact (A = .000):

9408-1113-002 (Gold plated)

9408-9113-002 (Passivated)

QPL version available (M39012/60)

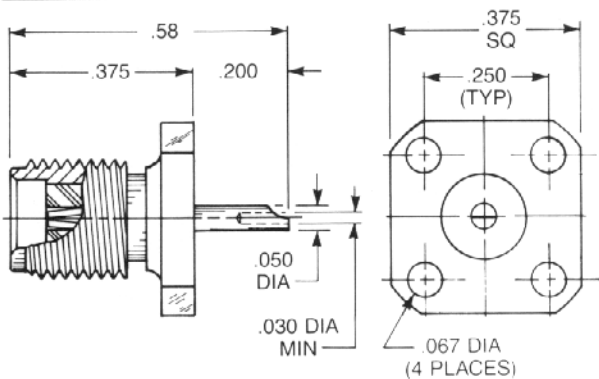


Straight Panel Jack Receptacle

- Solder pot contact
- 3/8" square flange

Captive contact:

9476-1113-000 (Gold plated)

9476-9113-000 (Passivated)

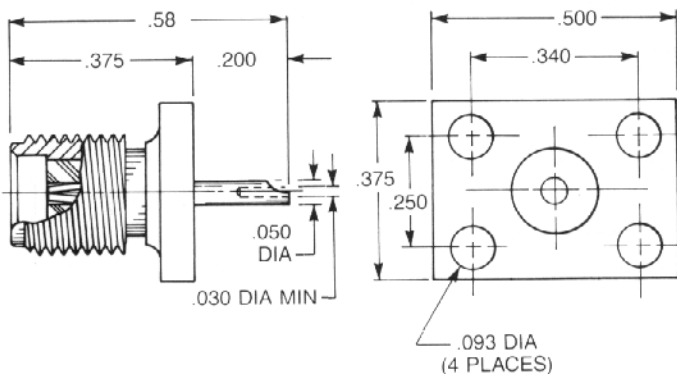

Straight Panel Jack Receptacle

- Solder pot contact
- Rectangular flange

Captive contact:

9407-1113-000 (Gold plated)

9407-9113-000 (Passivated)

Straight Panel Jack Receptacle

- Tab contact
- 1/2" square flange

Captive contact:


9104-1113-000 (Gold plated)

9104-9113-000 (Passivated)

Noncaptive contact:

9104-1213-000 (Gold plated)

9104-9213-000 (Passivated)

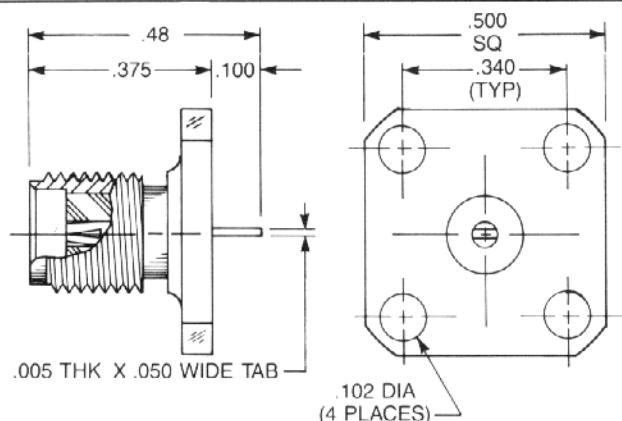

Straight Panel Jack Receptacle

- Tab contact
- 2-hole flange

Captive contact:


9108-1113-000 (Gold plated)

9108-9113-000 (Passivated)

Noncaptive contact:

9108-1213-000 (Gold plated)

9108-9213-000 (Passivated)

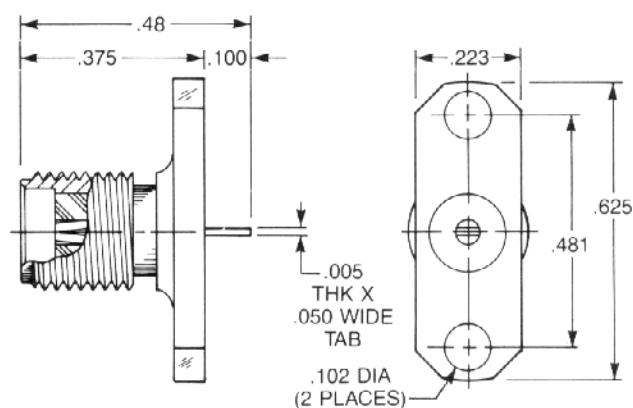

Straight Panel Jack Receptacle

- Tab contact
- 3/8" square flange

Captive contact:


9176-1113-000 (Gold plated)

9176-9113-000 (Passivated)

Noncaptive contact:

9176-1213-000 (Gold plated)

9176-9213-000 (Passivated)

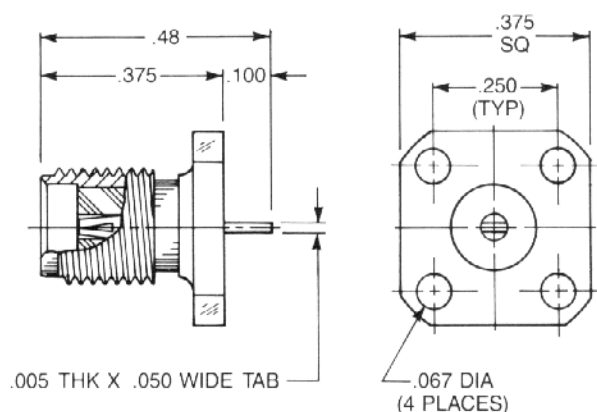

Straight Panel Jack Receptacle

- Tab contact
- Rectangular flange

Captive contact:


9107-1113-000 (Gold plated)

9107-9113-000 (Passivated)

Noncaptive contact:

9107-1213-000 (Gold plated)


9107-9213-000 (Passivated)

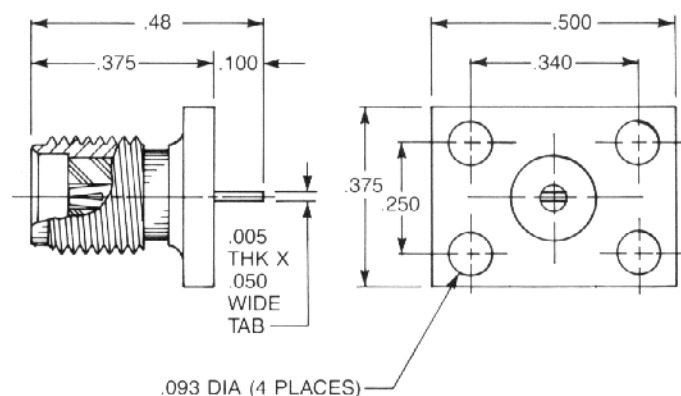



Straight Panel Jack Receptacle

- Slotted contact
- 1/2" square flange

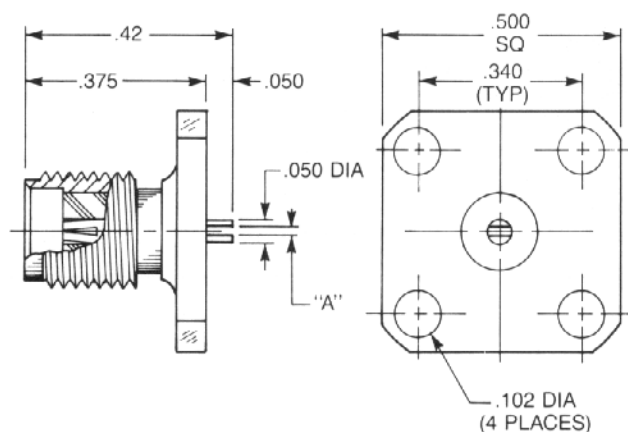

Dim. A Captive contact:


.012	9204-1113-002	(Gold plated)
	9204-9113-002	(Passivated)
.018	9204-1113-001	(Gold plated)
	9204-9113-001	(Passivated)
.025	9204-1113-003	(Gold plated)
	9204-9113-003	(Passivated)

Noncaptive contact:

.012	9204-1213-002	(Gold plated)
	9204-9213-002	(Passivated)
.018	9204-1213-001	(Gold plated)
	9204-9213-001	(Passivated)
.025	9204-1213-003	(Gold plated)
	9204-9213-003	(Passivated)

Straight Panel Jack Receptacle

- Slotted contact
- 2-hole flange

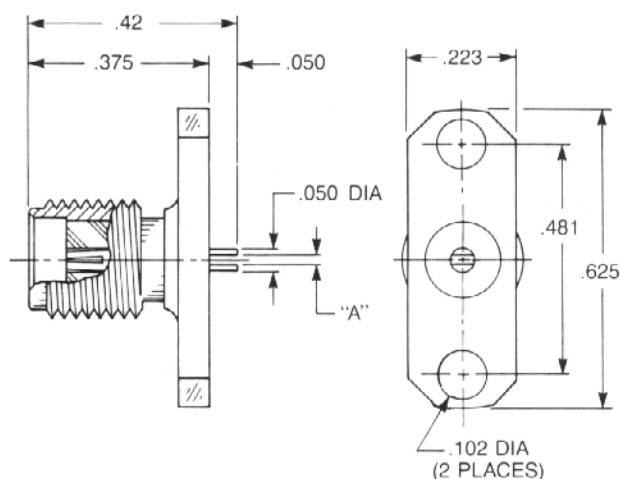

Dim. A Captive contact:

.012	9208-1113-000	(Gold plated)
	9208-9113-000	(Passivated)
.018	9208-1113-001	(Gold plated)
	9208-9113-001	(Passivated)
.025	9208-1113-002	(Gold plated)
	9208-9113-002	(Passivated)

Noncaptive contact:


.012	9208-1213-000	(Gold plated)
	9208-9213-000	(Passivated)
.018	9208-1213-001	(Gold plated)
	9208-9213-001	(Passivated)
.025	9208-1213-002	(Gold plated)
	9208-9213-002	(Passivated)

Right Angle Panel Jack Receptacle

- Solder pot contact
- 1/2" square flange

9424-1513-000 (Gold plated)

9424-9513-000 (Passivated)

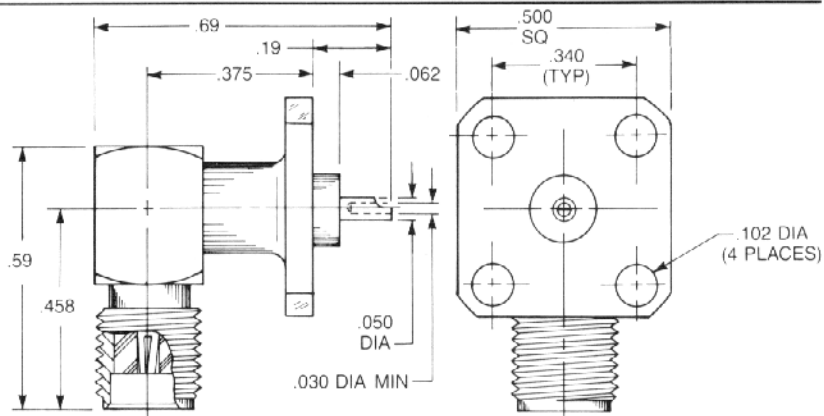


Low Profile Right Angle Panel Jack Receptacle

- Solder pot contact
- 1/2" square flange

9425-1513-000 (Gold plated)

9425-9513-000 (Passivated)

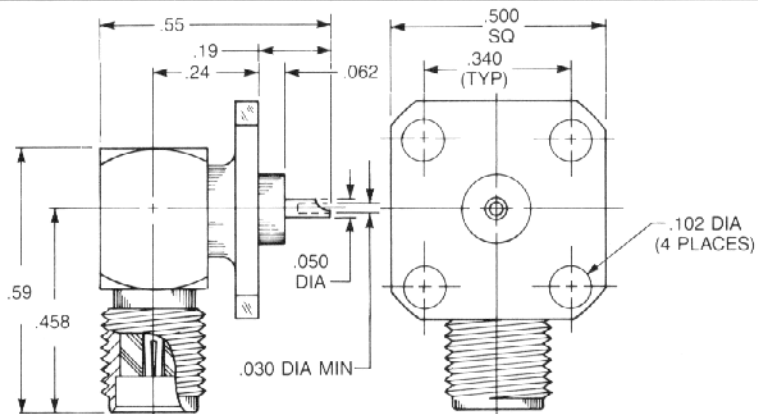


Right Angle Panel Jack Receptacle

- Tab contact
- 1/2" hole flange

9124-1513-000 (Gold plated)

9124-9513-000 (Passivated)

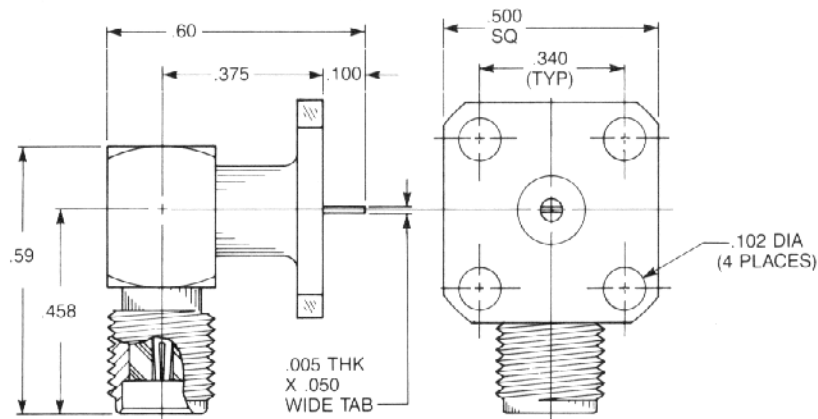

Right Angle Panel Jack Receptacle

- Tab contact
- 2-hole flange

9126-1513-000 (Gold plated)

9126-9513-000 (Passivated)

