

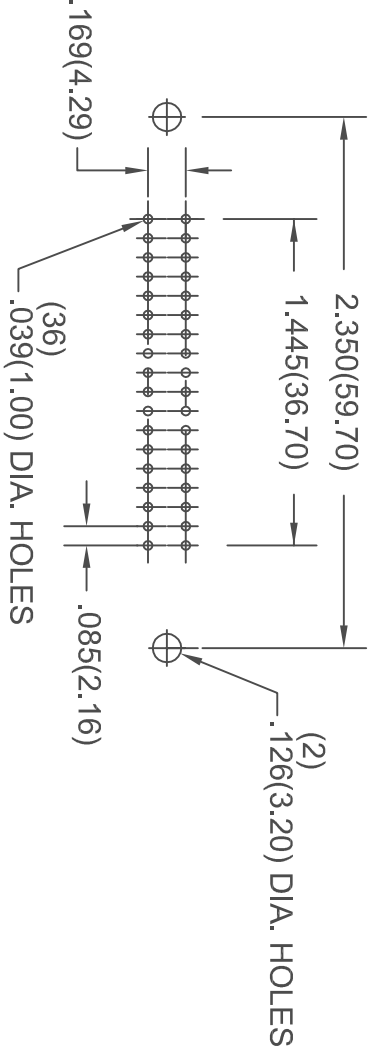
 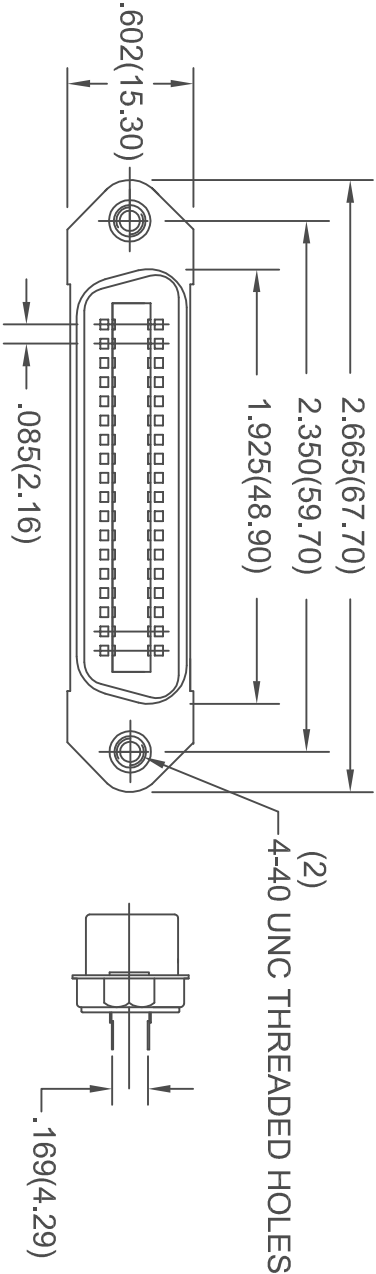


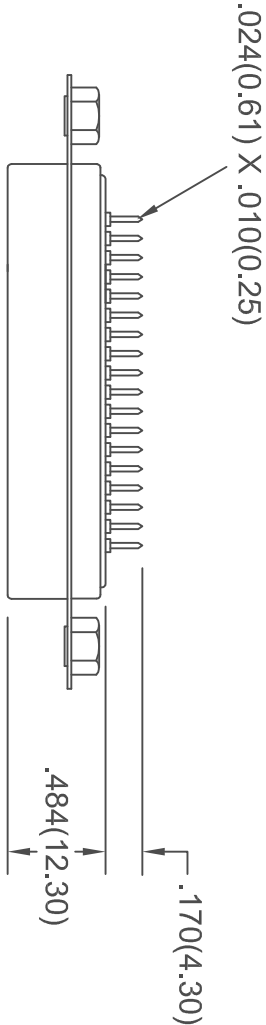

MATERIALS:

INSULATOR: THERMOPLASTIC P.B.T.
UL RATED 94V-0
CONTACTS: COPPER ALLOY
GOLD PLATED ON CONTACT AREA
TIN ON COMPLAINT SECTION OVER NICKEL
SHELL : STEEL NICKEL PLATED

ELECTRICALS:
CONTACT CURRENT RATING: 5 AMPS
DIELECTRIC WITHSTANDING VOLTAGE:
1000 VAC MIN.
INSULATION RESISTANCE: 1000 mohms
MIN. AT 500V DC
CONTACT RESISTANCE: 30 MOHMS MAXIMUM
OPERATING TEMPERATURE: -55°C TO +105°C



THIS SERIES FULLY CONFORMS TO THE
EUROPEAN UNION DIRECTIVES 2002/95/EC
AND 2002/96/EC FOR ROHS COMPLIANCY.

36 POSITION MINIATURE RIBBON RECEPTACLE

EDAC INC
TORONTO, ONTARIO
CANADA
YOUR CONNECTION TO QUALITY & SERVICE

THESE DRAWINGS AND SPECIFICATIONS
ARE THE PROPERTY OF EDAC INC. AND
SHALL NOT BE REPRODUCED OR COPIED
OR USED AS THE BASIS FOR THE
MANUFACTURE OR SALE OF APPARATUS
WITHOUT WRITTEN PERMISSION.

ACAD REFERENCE NO. B57-036-221-802

DRAWN: F BRIONES DATE: JAN. 09/07

PART NUMBER

B57-036-221-802

DRAWING NUMBER

B57-036-221-802

ISSUE

1