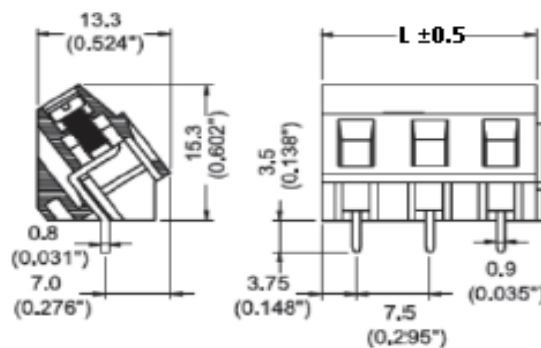
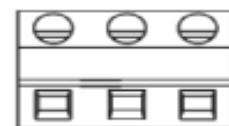
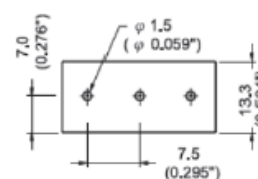


EM3227 Series**EuroMag Terminal Blocks**

35° Angle, 7.50 Centers; Modular

SPECIFICATIONS**Rating:** 16A, 300V**Center Spacing:** 0.295" (7.50mm)**Wire Range:** #12-26 AWG**Housing Material:** UL rated 94V0 Thermoplastic**Contact Material:** Brass Tin-Plated**Cage Material:** Brass, Nickel-Plated**Screw Size:** M2.6 Zinc-Plated Steel**Operating Temperature:** 105°C (221°F) max., -40°C (-40°F) min.**Torque Rating:** 5.0 lb-in.**Recommended PCB Hole Diameters:** 0.055" (1.40mm)**Construction:** Modular design features dovetails for interlocking to achieve longer lengths**Agency Information:** cULus File E62622; CE Certified

EM322705

Dimensions - mm (in)**PCB Layout**

Poles	L (mm)	Poles	L (mm)
2	15.0	14	105.0
3	22.5	15	112.5
4	33.0	16	120.0
5	37.5	17	127.5
6	45.0	18	133.0
7	52.5	19	142.5
8	60.0	20	150.0
9	67.5	21	157.5
10	75.0	22	165.0
11	82.5	23	172.5
12	90.0	24	180.0
13	97.5		

To convert to inches, divide by 25.4

Part Numbering System**Series****# of Poles**

EM3227

□□

02 to 24