


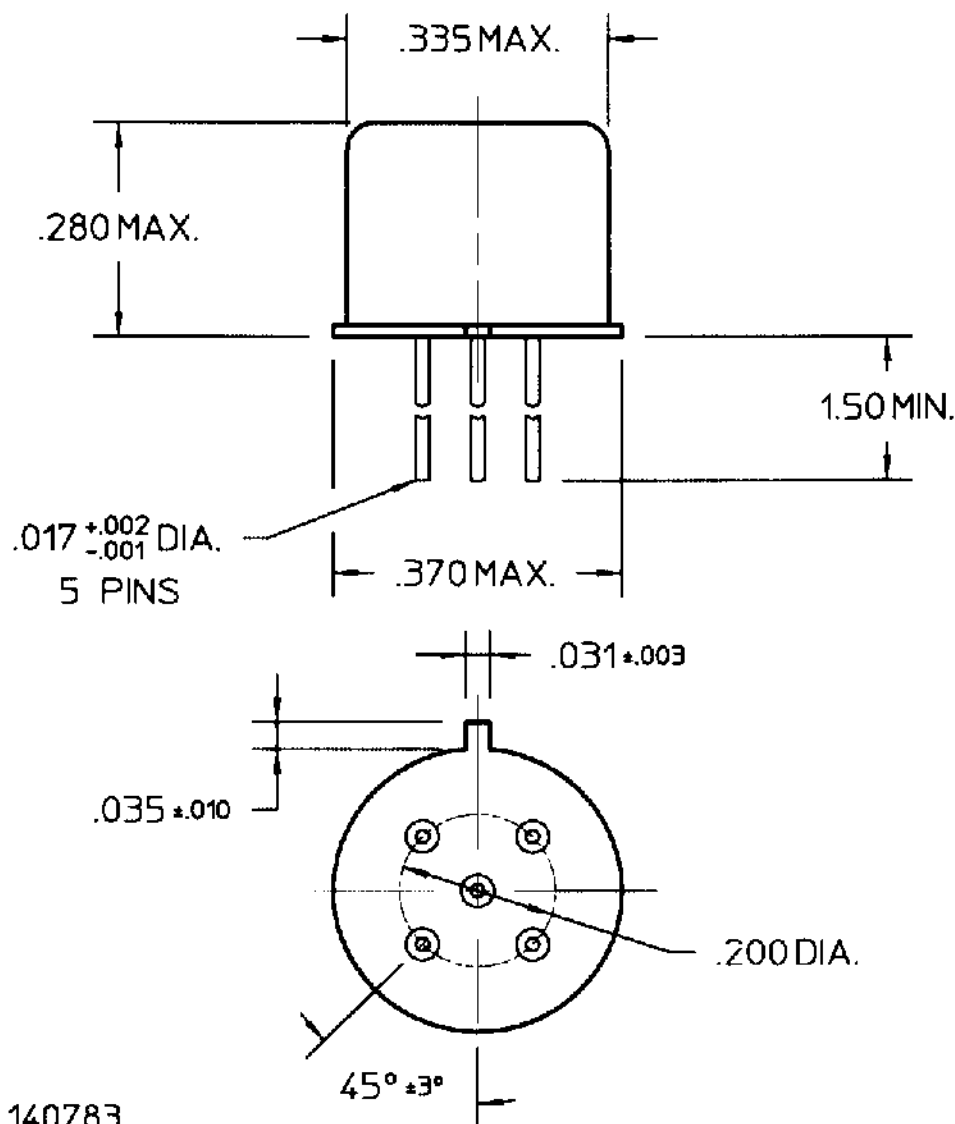

REV. 0 DCO 140783


COIL: @ 25°C
 RESISTANCE 1130 OHMS $\pm 10\%$
 NOMINAL VOLTAGE 18.0 VDC
 MUST OPERATE 11.6 VDC
 MUST RELEASE 6.0 VDC MAX, 0.91 VDC MIN.

ENVIRONMENT:

VIBRATION 10 CPS TO 3000 CPS @ 30 g's
 SHOCK 75 g's 6 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 2.0 MS MAX.
 RELEASE TIME 4.0 MS MAX.
 CONTACT STABILIZATION 2.0 MS MAX.

CUSTOMER DATA SHEET

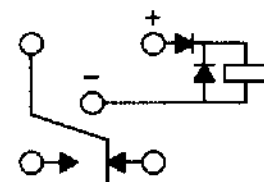

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 1A
 28 VDC RESISTIVE 100,000 OPERATIONS

DR. R.B. 12/3/98 *CK Jerry* 12/4/98

COMMUNICATIONS
 INSTRUMENTS, INC.

CUST. QPL
 CUST. NO. M39016/24-017P

TYPE J1MADD RELAY

J1MAWDD-18XP