


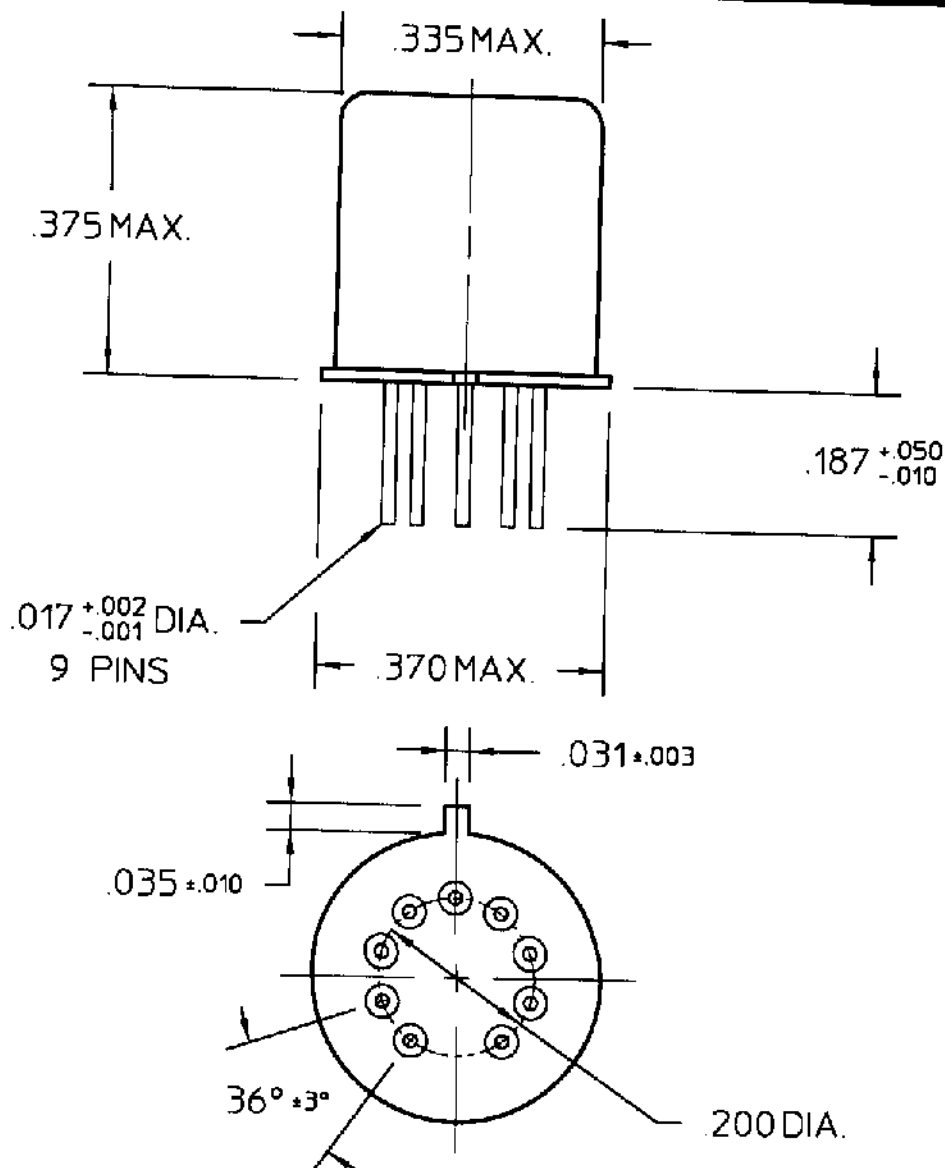


COIL: @ 25°C
 RESISTANCE 100 OHMS $\pm$ 10%
 NOMINAL VOLTAGE 5.0 VDC
 MUST OPERATE VOLTAGE 2.8 VDC
 TURN-ON BASE CURRENT 0.37 mADC
 MUST RELEASE 1.4 VDC MAX, 0.22 VDC MIN.

ENVIRONMENT:
 VIBRATION 10 CPS TO 3000 CPS @ 30 g's
 SHOCK 75 g's 6 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES: TURN-ON TIME 4.0 MS MAX
TURN-OFF TIME 7.5 MS MAX
CONTACT STABILIZATION 2.0 MS MAX

CUSTOMER DATA SHEET

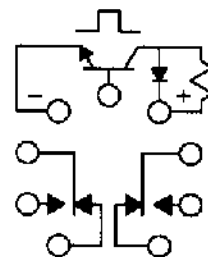

CONTACT RATING: LOW LEVEL TO 1A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. R.B. 4/14/98 CK ERRY 4/14/98

COMMUNICATIONS
INSTRUMENTS, INC.

JMSPT-5XP

CUST. QPL
 CUST. NO M28776/3-025P

TYPE JMST RELAY