


COIL:

RESISTANCE	$700 \Omega \pm 10\%$
NOMINAL VOLTAGE	26.5 VDC
MUST OPERATE	13.5 VDC
MUST RELEASE	1.5 VDC

CUSTOMER DATA SHEET

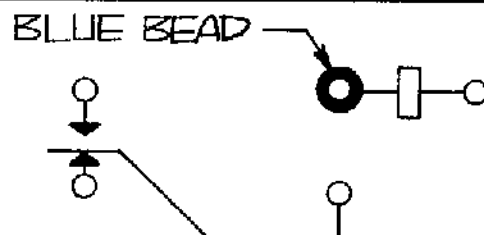

ENVIRONMENT:

VIBRATION 10 CPS TO 2000 CPS @ 20 g's
SHOCK 100 g's 5 MS. DURATION
TEMPERATURE -65 °C TO +125 °C

CONTACT RATING: 10 AMP/28 VDC
RESISTIVE 50,000 OPERATIONS

NOTES: DIELECTRIC-1000 VRMS EXCEPT
500 VRMS ACROSS OPEN CONTACTS

DR. R.B. 1-30-91 CK.1/50/9/548

CUST. C.I.I. STD
CUST. NO.

TYPE "C" RELAY



**Communications
Instruments, Inc.**

CEW-1C-24A