

**Mallory Sonalert Products, Inc.**

Part #:

SBT5DHPC**Sales Outline Drawing**


Revision:

D**Specifications:****cUL Recognized to IEC60601-1-8 AMD1
Drug or Fluid Delivery Melody - High Priority Only**

| | |
|-------------------------------|--|
| Sound Level Category: | Loud |
| Mode of Operation: | High Priority Alarm - 10 beeps repeating every 2.5 sec |
| Voltage Rating: | 3.3 to 5 VDC |
| Frequency: | 150 to 4000 Hz |
| Loudness @ 10cm: | 85 to 95 dB(A) Typ. |
| Average Current Draw: | <35mA Typ. |
| Ipk Current*: | 300mA |
| Housing Material: | ABS 777D Plastic Resin, Black |
| Storage Temperature: | -40° to +85° C |
| Operating Temperature: | -30° to +65° C |
| Weight Typical: | 0.6 oz (17g) |
| Options: | Please contact factory. |
| Condition by wave solder (°C) | 260 ± 5 within 5 sec |
| Condition by hand solder (°C) | 350 ± 20 within 5 sec |

Dimensions: Inches (mm)**cUL Recognized****ROHS Compliant**

PATENT NUMBER: 7880593

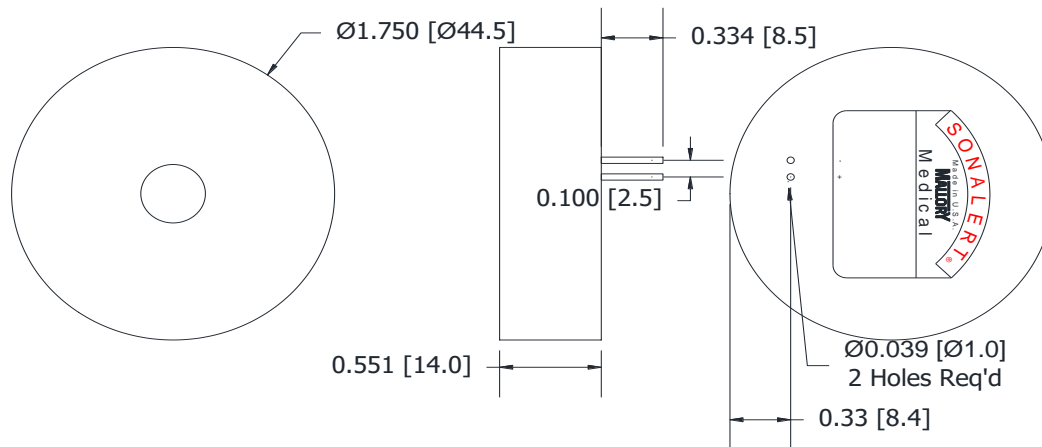

*Ipk = Instantaneous Peak

tolerances:

 ± 0.01 [± 0.3] ± 0.005 [± 0.1]