



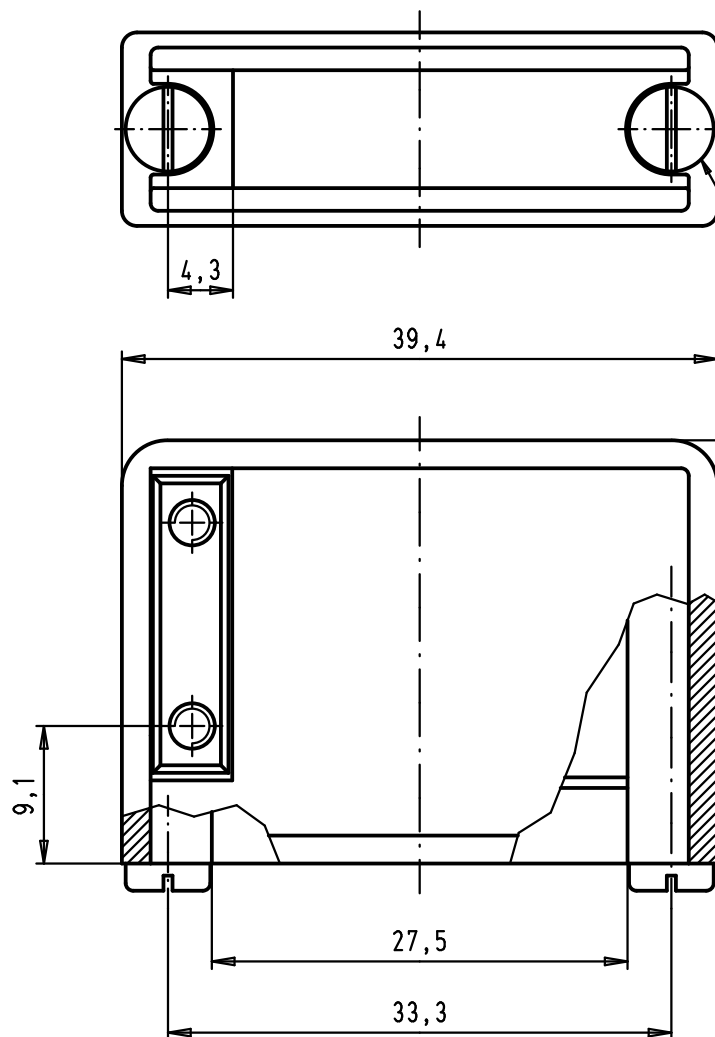


Slotted pan head tapping screws
DIN 7971-ST 2,9x6,5-F
screwing torque=35Ncm +/-5Ncm

Slotted pan head tapping screws
DIN 7971-ST 2,2 x 9,5-F
Maximum screwing torque= 0,25 mN

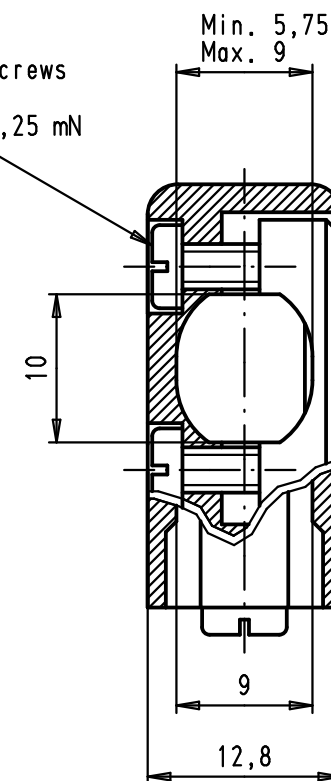

				Dat.	Name		D-Sub, hood 15 poles for spring or slide locking, side cable entry	Maßstab/ Scale 2:1
			Detail.	28/03/02	CV			
			Insp.	25-MAY-11	JMDV			
EC03223	25-MAY-11	SD	Stand.					
34886	26/02/08	PK	HARTING EURL F-95972 Paris				TB 09 67 015 051X	Blatt/ Page 1 / 1
29760	28/03/02	CV						
Mod.	Dat.	Name						

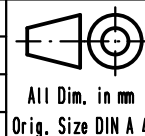

Sub.