

HPF-10-02-T-S

HPF SERIES

POWER SOCKETS

Mates with:
HPM, HPW

RV[®]
FILE NO. E111594



FILE NO. E111594

0893-3200/93 \$05.00

**POWER
EYE
CONTACT**

HPF/HPM	
PINS	CURRENT RATING (PER CONTACT)
1	16.6 A
2	14.4 A
3	13.2 A
4	12.7 A
ALL	8.9 A

Surface Mount
or
Through-hole



- Three-finger Power Eye contact
- Locking clip option

HPF

**NO. PINS
PER ROW**

LEAD STYLE

PLATING OPTION

S

OTHER OPTIONS

02 thru 20

—01
Through-hole


—02
Surface Mount

-T
= Matte Tin

–LC
= Locking Clip
(Manual
placement
required)
(Style –02 only)

-K
= (6,50 mm) .256"
**DIA Polyimide
Film Pick &
Place Pad**

-TR
= Tape & Reel
Packaging
(14 positions
maximum)
(Style -02 only)

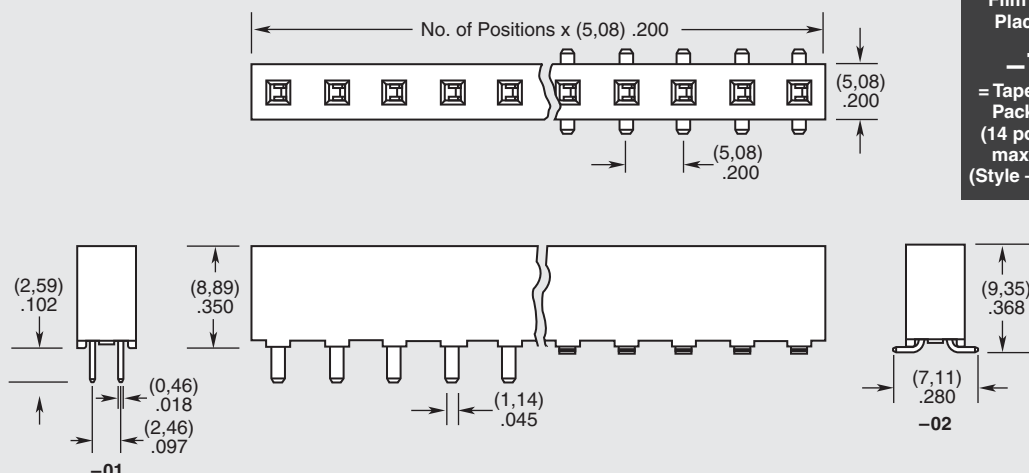

Note: Some lengths, styles and options are non-standard, non-returnable.

WWW.SAMTEC.COM

Due to technical progress, all designs, specifications and components are subject to change without notice.