


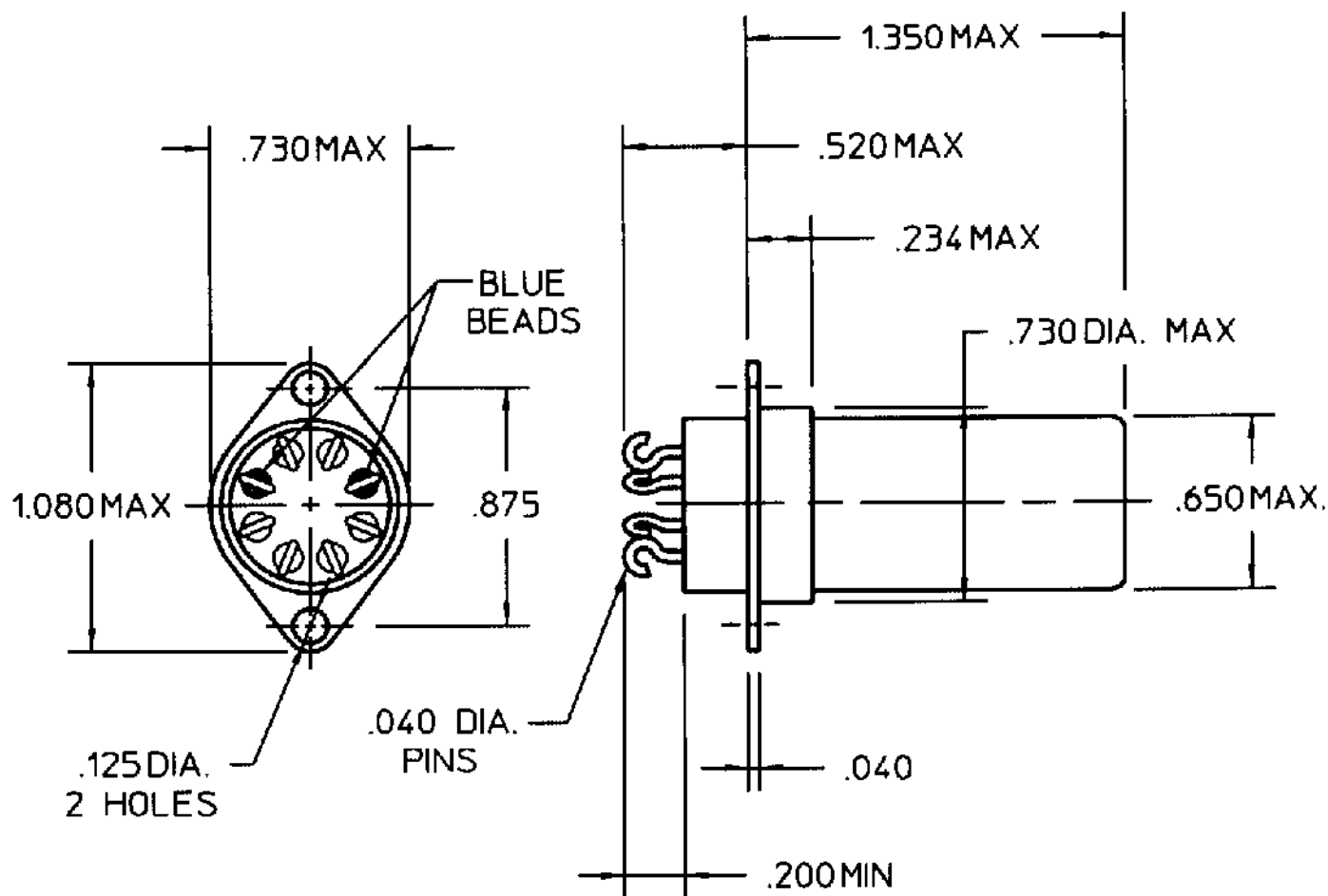

COIL: @ 25°C

RESISTANCE 400 OHMS $\pm 10\%$

NOMINAL VOLTAGE 26.5 VDC

MUST OPERATE 13.0 VDC

MUST RELEASE 10.1 VDC MAX

ENVIRONMENT:

VIBRATION 10 CPS TO 2000 CPS @ 15 g's

SHOCK 100 g's 6 MS. DURATION


TEMPERATURE -65 °C TO +125 °C

NOTES: MEETS MIL-R-5757

OPERATE & RELEASE TIME 10 MS MAX.

CONTACT BOUNCE 1 MS MAX.

CUSTOMER DATA SHEET

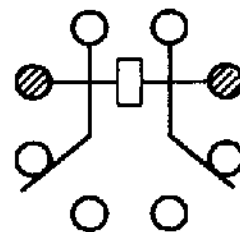

CONTACT RATING: 2 AMPS 28 VDC
RESISTIVE 100,000 OPERATIONS

DR. R.B. 5/17/94 CK.5/17/94



COMMUNICATIONS
INSTRUMENTS, INC.

CUST. QPL
CUST. NO. M5757/8-002

TYPE '02' RELAY

02A312HC2-0030