


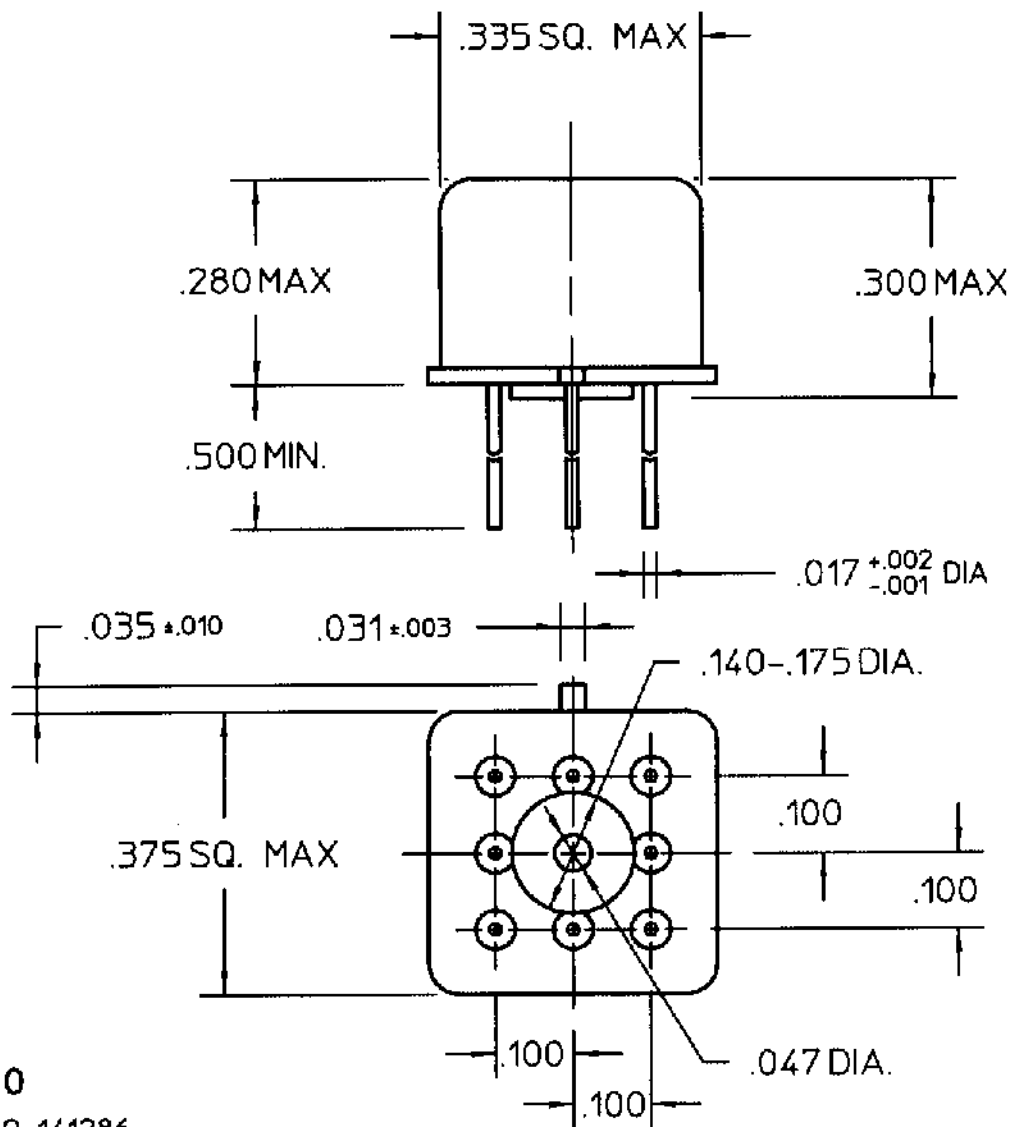

REV. 0

DCO 141286

COIL: @ 25°C
 RESISTANCE _____ 50 OHMS ±10%
 NOMINAL VOLTAGE _____ 5.0 VDC
 MUST OPERATE _____ 2.7 VDC

 MUST RELEASE _____ 1.4 VDC MAX, 0.22 VDC MIN.

ENVIRONMENT:


VIBRATION _____ 10 _____ CPS TO _____ 3000 _____ CPS @ _____ 30 _____ g's
 SHOCK _____ 75 _____ g's _____ 6 _____ MS. DURATION.
 TEMPERATURE _____ -65 _____ °C TO _____ +125 _____ °C

NOTES: _____ OPERATE TIME 2.0 MS MAX

_____ RELEASE TIME 15 MS MAX

_____ CONTACT STABILIZATION 2.5 MS MAX

CUSTOMER DATA SHEET

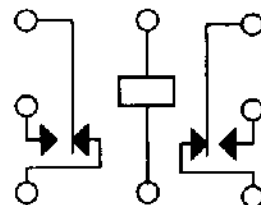

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 1 AMP
 28 VDC RESISTIVE 100,000 OPERATIONS

DR. _____ B.D. 8/17/99 CK ~~copy~~ 8/17/99

COMMUNICATIONS
 INSTRUMENTS, INC.

CUST. _____ QPL
 CUST. NO. M39016/17-037P REV. _____

JMGA RELAY

JMGAC-5PW