


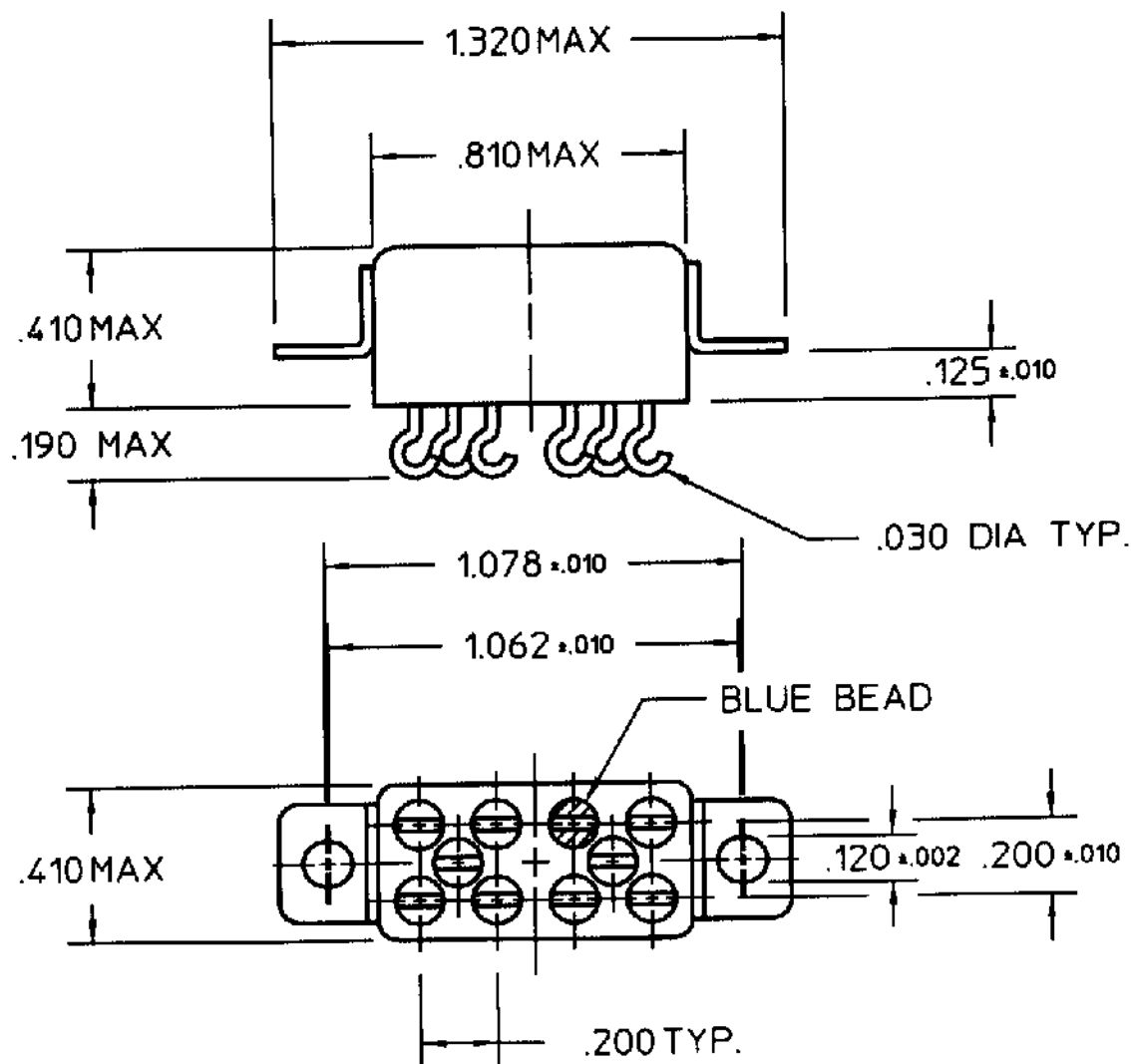

COIL: 26.5 VDC

WINDING #1

1000 OHMS ± 10% @ 25° C

13.0 VDC MUST OPERATE

26.5 VDC NOMINAL VOLTAGE

WINDING #2

1000 OHMS ± 10% @ 25° C

13.0 VDC MUST OPERATE

26.5 VDC NOMINAL VOLTAGE

ENVIRONMENT:

VIBRATION 10 CPS TO 2500 CPS @ 20 g's


SHOCK 100 g's 6 MS. DURATION

TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE & RELEASE 5 MS MAX
BOUNCE 2.0 MS MAX

CUSTOMER DATA SHEET

CONTACTS WILL SWITCH WHEN EITHER COIL IS ENERGIZED WITH POLARITY SHOWN

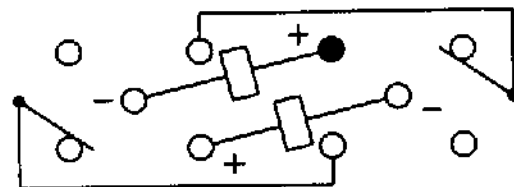

CONTACT RATING: LOW LEVEL TO 2 AMPS
28 VDC RESISTIVE 100,000 OPERATIONS

DR. R.B. 11/2/93 CK. 11/3/93



COMMUNICATIONS
INSTRUMENTS, INC.

CUST. C. I. I. STD.

CUST. NO.

TYPE "LS" RELAY

LSBW-2C-24A