


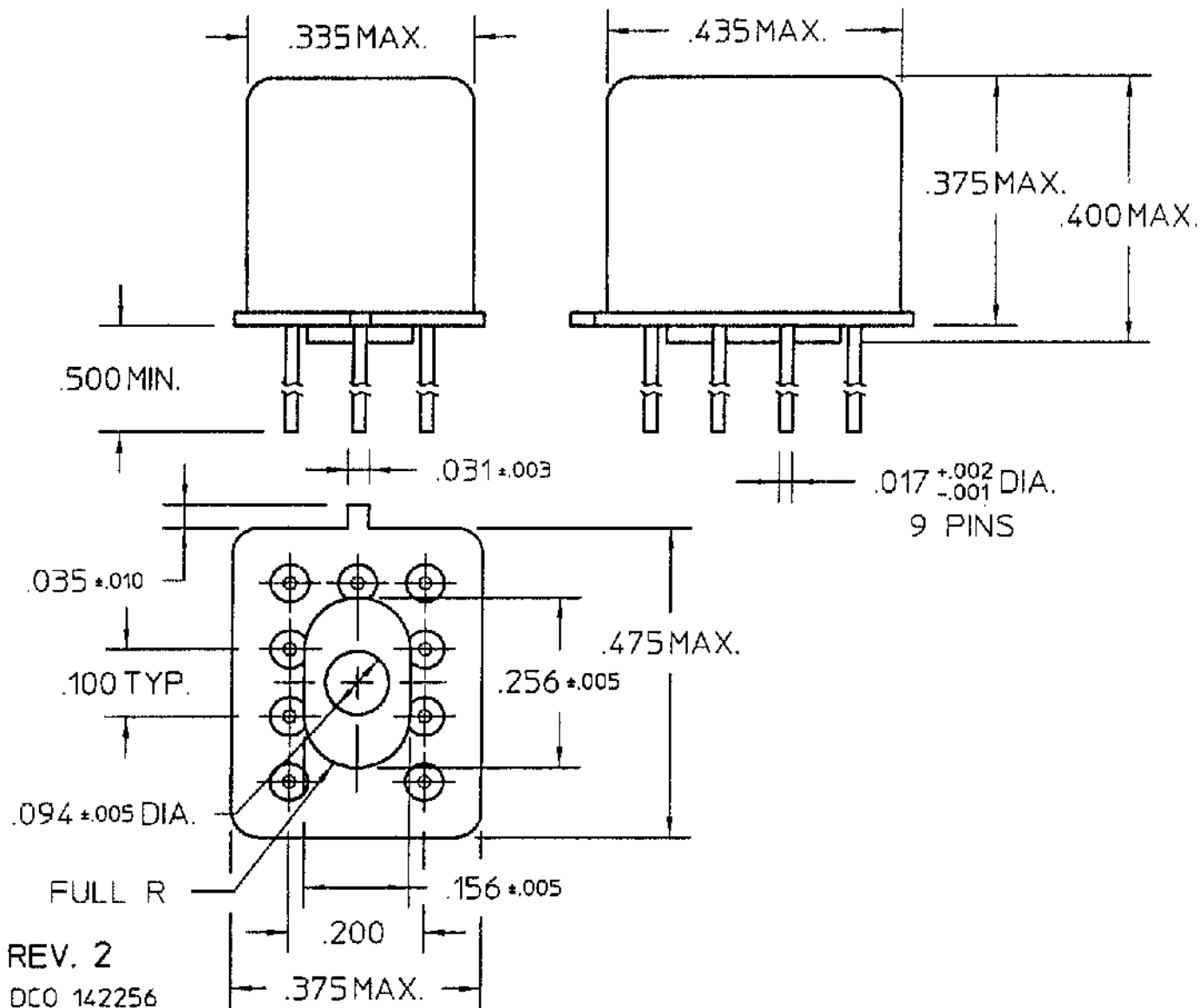

REV. 2
DCO 142256

COIL: @ 25°C	
RESISTANCE	800 OHMS ± 10%
NOMINAL VOLTAGE	12.0 VDC
GATE TURN-ON	4.3 VDC MAX.
GATE TURN-OFF	0.5 VDC MAX.
MUST OPERATE	7.1 VDC
MUST RELEASE	4.0 VDC MAX, 0.65 VDC MIN.


ENVIRONMENT:

VIBRATION	10	CPS TO	3000	CPS @	30	g's
SHOCK	75	g's	6	MS. DURATION		
TEMPERATURE	-65	°C TO	+125	°C		

NOTES:

OPERATE TIME 4.0 MS MAX.
RELEASE TIME 7.5 MS MAX.
CONTACT BOUNCE 1.5 MS MAX.

CUSTOMER DATA SHEET

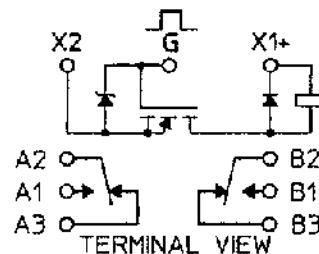

CONTACT RATING: LOW LEVEL TO 1A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. R.B. 11/19/97 CK. *[Signature]*

COMMUNICATIONS
INSTRUMENTS, INC.

CUST. QPL
CUST. NO. M28776/7-010L REV.

"JMGST" RELAY

JMGST-12LW