

SUMMARY

Wires

Coax	1
------	---



Image is for illustrative purpose only

Series	0A
Termination type	Coupler/adapter/bridge
IP rating	50
AWG wire size	0.00 - 0.00
Cable Ø	0.00 - 0.00 mm
Status	active

Download

[Request a quote](#)

[Catalog](#)

TECHNICAL DETAILS

Mechanics

Shell Style/Model	ABF*: Adapter
-------------------	---------------

Keying

Housing Material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
------------------	---

Weight	10.45 g
--------	---------

Performance

Configuration	0A.250 : 1 Coax (50 Ohm)
---------------	--------------------------

Insulator

Rated Current

Specifications

Contact Type: Solder


Others

Endurance (Shell): >1000 mating cycles

Salt Spray Corrosion: >1000 hr

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

DRAWINGS

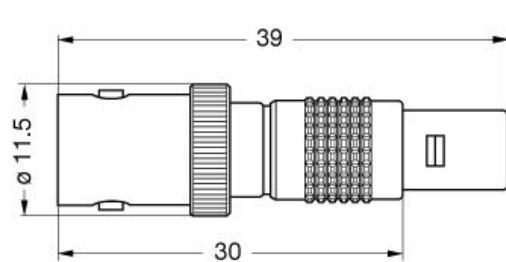

RECOMMENDED BY LEMO

Tools

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.