



Metal Guardian System universal connector and adapter fitting

 
How To Order

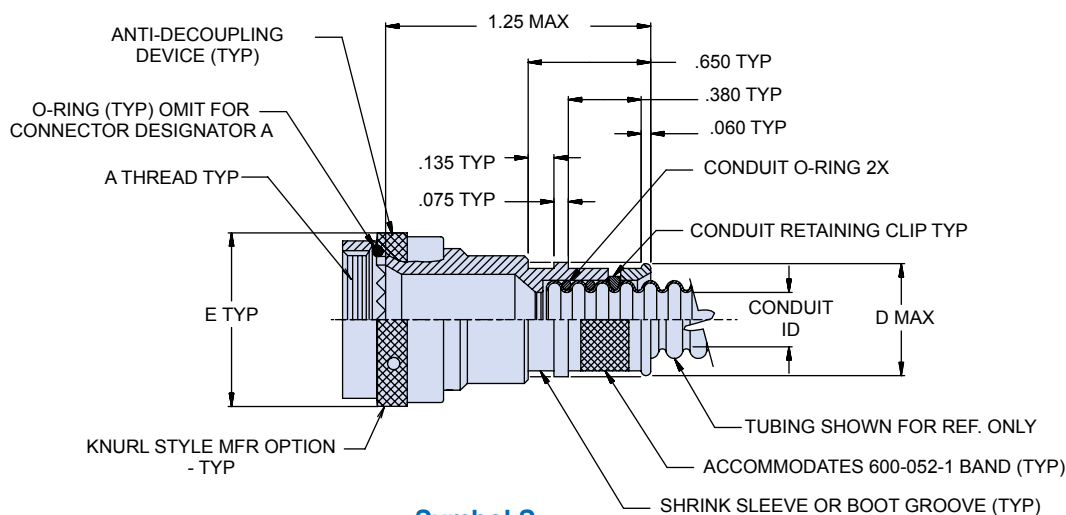

Self-Locking

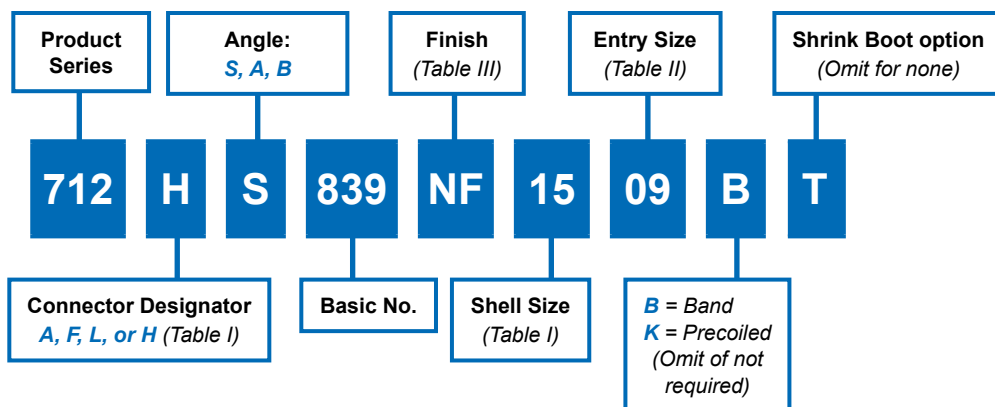

Symbol S
Straight



BAND OPTION
 (K OPTION SHOWN-
 SEE NOTES)

Material and Finish

Adapters, elbows, coupling nut: Aluminum Alloy or Stainless Steel per Table III
 O-ring: Silicone/NA
 Retaining clip: High grade engineering thermoplastic/NA
 Anti-decoupling device: Corrosion resistant material

Tools and Assembly notes

Conduit retaining clip and conduit O-ring to be supplied unassembled
 For effective grounding, connector with conductive Finish should be used
 Glenair assembly procedure AP74-010 is recommended for adapter to conduit termination
 Glenair 600 Series backshell assembly tools are recommended for assembly and installation
 Interfacial O-ring not supplied with Connector Designator "A"

712-839
Metal Self- Locking EMI/RFI Environmental
Connector Adapter
for Series 72 Annular Convolute Tubing



Series 72
Guardian

Standard Profile
Symbol B
45°

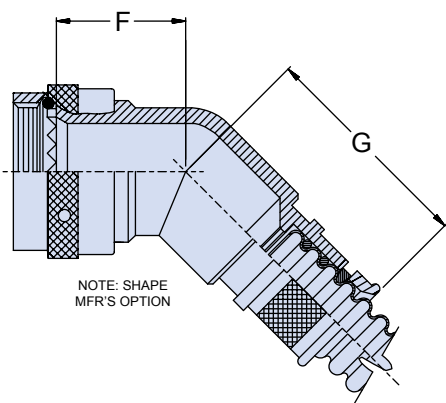


Table I

Shell Size		F Max	G Max	H Max	J Max
A,F,L	H				
08	09	1.01 (25.7)	1.16 (29.5)	1.150 (29.2)	1.417 (36.0)
10	11	1.03 (26.2)	1.19 (30.2)	1.177 (29.9)	1.480 (37.6)
12	13	1.06 (26.9)	1.21 (30.7)	1.302 (33.1)	1.553 (39.4)
14	15	1.08 (27.4)	1.24 (31.5)	1.367 (34.7)	1.614 (41.0)
16	17	1.11 (28.2)	1.26 (32.0)	1.395 (35.4)	1.678 (42.6)
18	19	1.12 (28.4)	1.27 (32.3)	1.455 (37.0)	1.773 (45.0)
20	21	1.15 (29.2)	1.30 (33.0)	1.518 (38.6)	1.796 (45.6)
22	23	1.17 (29.7)	1.33 (33.8)	1.612 (40.9)	1.859 (47.2)
24	25	1.20 (30.5)	1.35 (34.3)	1.645 (41.8)	1.919 (48.7)

Table II

Entry Code	D Max	Conduit ID		T Shrink Boot
		Min	Max	
06	.53 (13.5)	.16 (4.1)	.19 (4.8)	770-001S103
09	.63 (16.0)	.24 (6.1)	.28 (7.1)	770-001S103
12	.73 (18.5)	.33 (8.4)	.37 (9.4)	770-001S104
16	.86 (21.8)	.45 (11.4)	.50 (12.7)	770-001S104
20	.98 (24.9)	.57 (14.5)	.62 (15.8)	770-001S105
24	1.15 (29.2)	.69 (17.5)	.75 (19.1)	770-001S106
28	1.27 (32.3)	.81 (20.6)	.87 (22.2)	770-001S107
32	1.40 (35.6)	.93 (23.6)	1.00 (25.4)	770-001S107
40	1.62 (41.1)	1.18 (30.0)	1.25 (31.8)	770-001S107

Standard Profile
Symbol A
90°

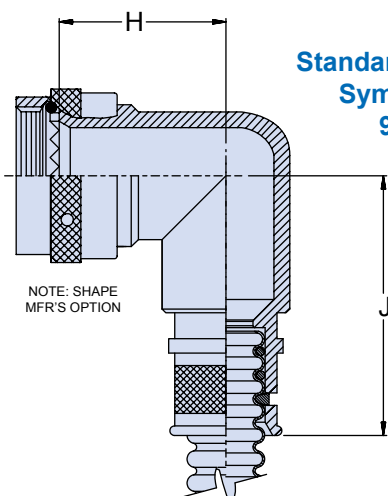


Table III

Sym	Material	Finish Description
M	Aluminum	Electroless Nickel
MT		Nickel-PTFE
NF		Cad/Olive Drab over Electroless Nickel
ZN		Zinc Nickel/Olive Drab over Electroless Nickel
ZNU		Zinc Nickel/Black over Electroless Nickel
Z1	Stainless Steel	Passivate