


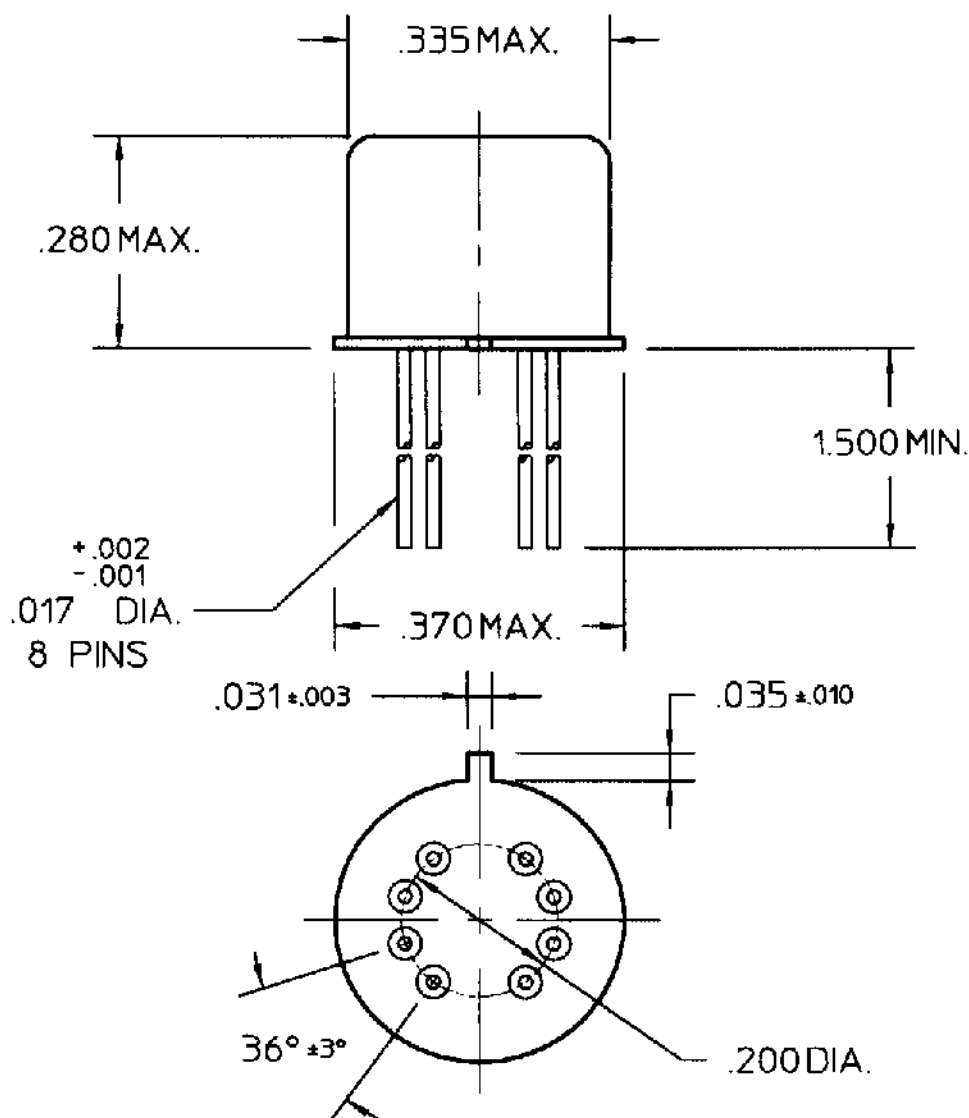

REV. 0
DCO 140970


COIL: @ 25°C
RESISTANCE 220 OHMS ± 10%
NOMINAL VOLTAGE 9.0 VDC
MUST OPERATE 5.3 VDC
MUST RELEASE 3.0 VDC MAX, 0.54 VDC MIN.

ENVIRONMENT:

VIBRATION 10 CPS TO 3000 CPS @ 30 g's
SHOCK 75 g's 6 MS. DURATION
TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 2 MS MAX
RELEASE TIME 4 MS MAX
CONTACT STABILIZATION 2.5 MS MAX

CUSTOMER DATA SHEET

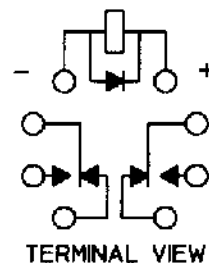

CONTACT RATING: LOW LEVEL TO 1A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. R.B. 3/22/99 CK *[Signature]* 3-22-99

COMMUNICATIONS
INSTRUMENTS, INC.

CUST. QPL
CUST. NO. M39016/15-030P

TYPE JMAD RELAY

JMAWD-9XP