


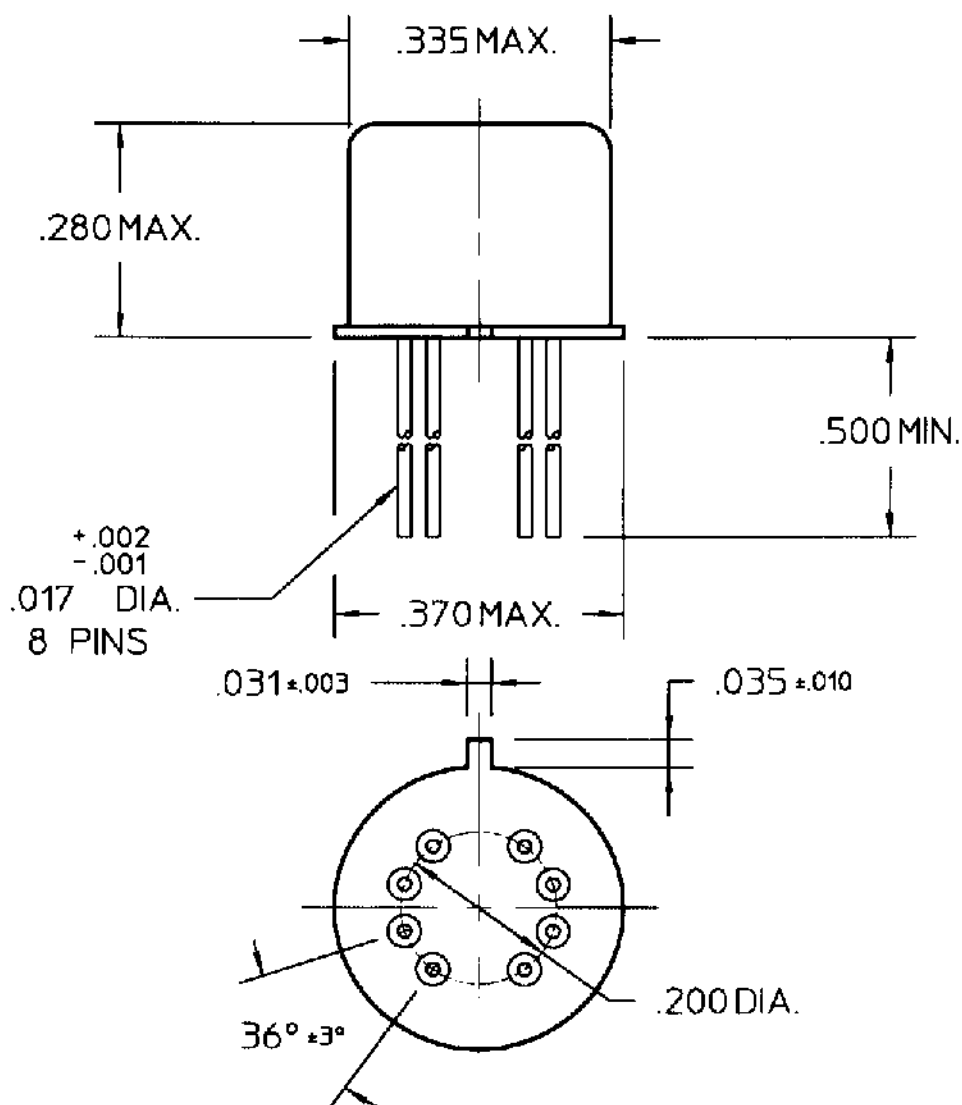

REV. 0
DCO 140994


COIL: @ 25°C
RESISTANCE 390 OHMS ± 10%
NOMINAL VOLTAGE 12.0 VDC
MUST OPERATE 7.0 VDC
MUST RELEASE 4.0 VDC MAX, 0.63 VDC MIN.

ENVIRONMENT:

VIBRATION 10 CPS TO 3000 CPS @ 30 g's
SHOCK 75 g's 6 MS. DURATION
TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 2 MS MAX
RELEASE TIME 4 MS MAX
CONTACT BOUNCE 1.5 MS MAX

CUSTOMER DATA SHEET

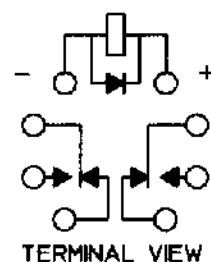

CONTACT RATING: LOW LEVEL TO 1A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. R.B. 3/31/99 EK 3-31-99

COMMUNICATIONS
INSTRUMENTS, INC.

CUST. QPL
CUST. NO. M39016/15-079L

TYPE JMAD RELAY

JMACD-12XL