


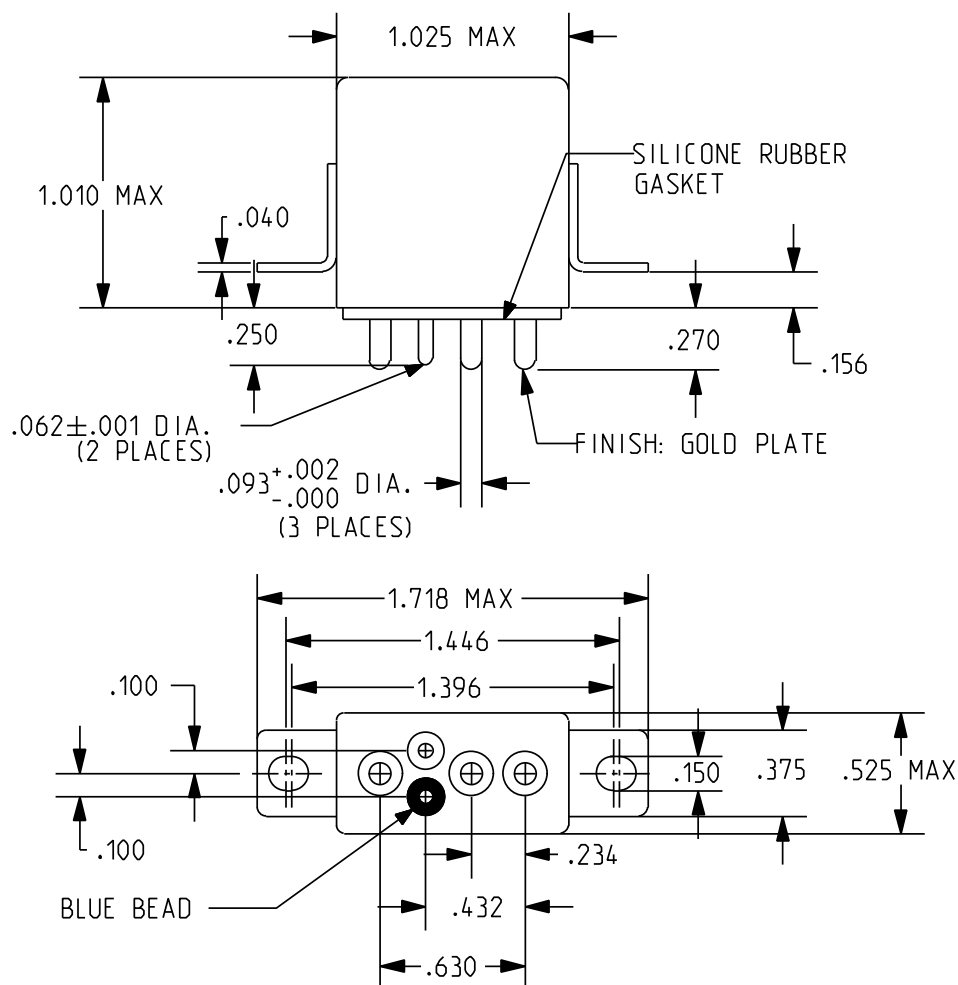

REV. B
DCO 300860

TOLERANCES $\pm .010"$ - UNLESS
OTHERWISE SPECIFIED

COIL: @ 25°C
 RESISTANCE 320 OHMS $\pm 10\%$
 NOMINAL VOLTAGE 28 VDC
 MUST OPERATE 13.5 VDC MAX.
 MUST RELEASE 5.5 VDC MAX., 2.3 VDC MIN.

ENVIRONMENT:
 VIBRATION 10 Hz TO 3000 Hz @ 30 g's
 SHOCK 200 g's 6 MS. DURATION
 TEMPERATURE -70 °C TO +125 °C


NOTES: OPERATE, RELEASE 10 MS MAX.
CONTACT BOUNCE 1 MS MAX.

CUST. QPL
 CUST. NO. M6106/19-004 REV. ----

TE NUMBER
 4-1617748-0

CUSTOMER DATA SHEET

A1 - X2 A2 A3

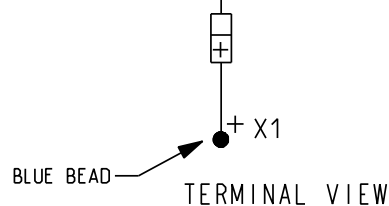

CONTACT RATING:
25 AMPS 28 VDC, 115 VAC 400 Hz RESISTIVE
50,000 OPERATIONS

DR. B.D. 21MAY2008 CK. J.M.B. 5/21/08

Tyco Electronics

©COPYRIGHT 2005
 TYCO ELECTRONICS CORPORATION
 ALL INTERNATIONAL RIGHTS RESERVED

CII PART NUMBER

FCA-125-4