


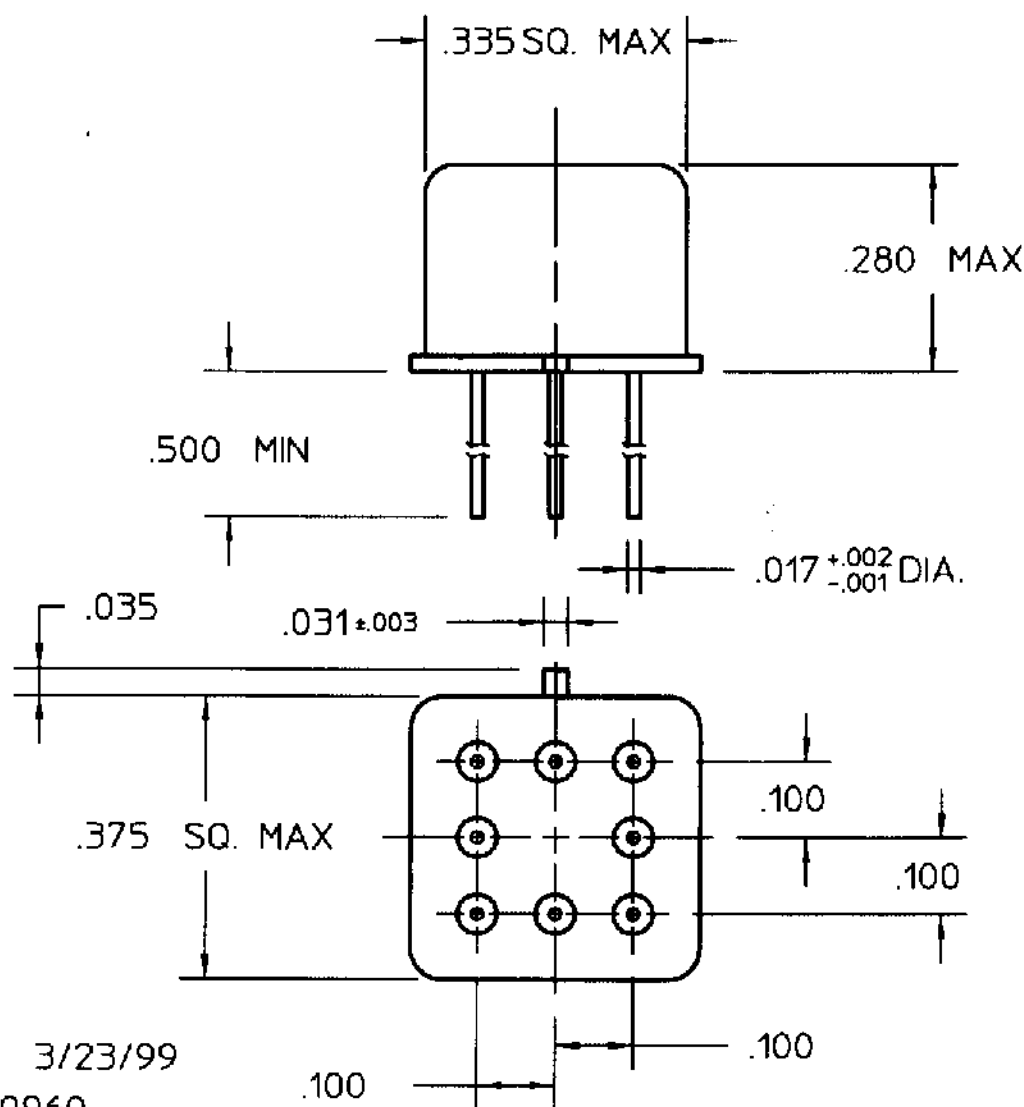

REV. 2 3/23/99

DCO 140960

COIL: @ 25°C

RESISTANCE 50 OHMS ± 10%

NOMINAL VOLTAGE 5.0 VDC

MUST OPERATE 2.7 VDC

MUST RELEASE 1.4 VDC MAX, 0.22 VDC MIN.

CUSTOMER DATA SHEET

ENVIRONMENT:

VIBRATION 10 CPS TO 3000 CPS @ 30 g's


SHOCK 75 g's 6 MS. DURATION

TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 2.0 MS MAX

RELEASE TIME 1.5 MS MAX

CONTACT BOUNCE 1.5 MS MAX

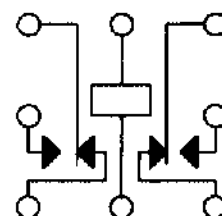

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 1 AMP
28 VDC RESISTIVE 100,000 OPERATIONS

DR. R.B. 4/4/97 [Signature] 3-23-99

COMMUNICATIONS
INSTRUMENTS, INC.

CUST. QPL
CUST. NO. M39016/17-031L

TYPE JMGA RELAY

JMGAC-5L