


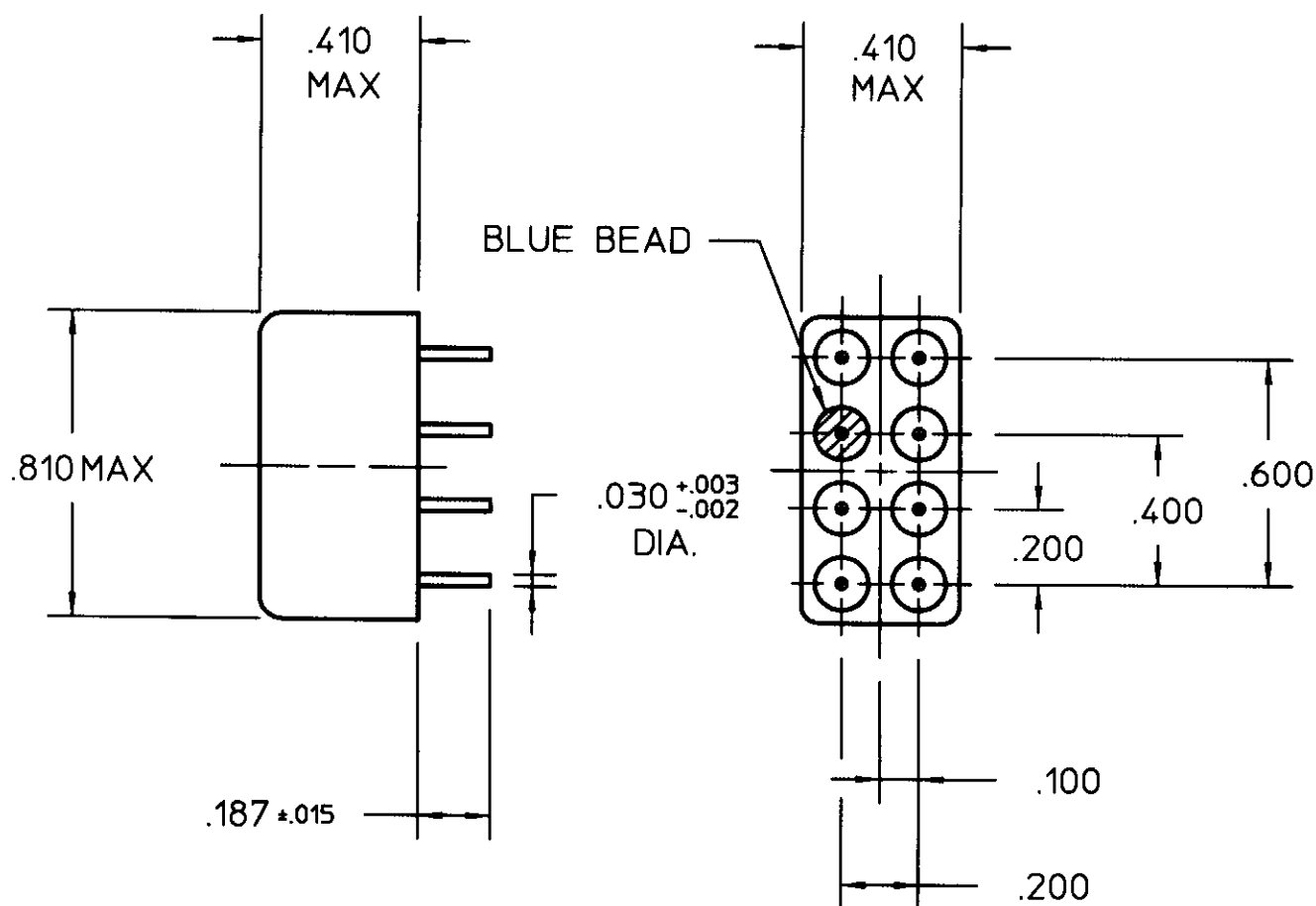


REV. 3 3/7/96

COIL: @ +25 °C
 RESISTANCE 700 OHMS ± 10%
 NOMINAL VOLTAGE 26.5 VDC
 MUST OPERATE 13.5 VDC
 MUST RELEASE 1.5 VDC

ENVIRONMENT:
 VIBRATION 10 CPS TO 2000 CPS @ 20 g's
 SHOCK 100 g's 6 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE 4 MS MAX
 RELEASE 2 MS MAX
 BOUNCE 3 MS MAX

CUSTOMER DATA SHEET

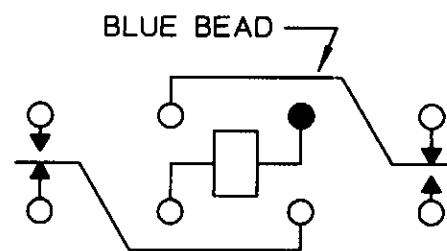

CONTACT RATING: 2A 30 VDC
 RESISTIVE .75A 30 VDC INDUCTIVE
 100,000 OPERATIONS

DR. R.B. 7/17/92 CK. GQH 3-7-96

COMMUNICATIONS
 INSTRUMENTS, INC.

CUST. HI-G
 CUST. NO. 2K-2A-126

TYPE "HFW" RELAY

HFW1201S99