


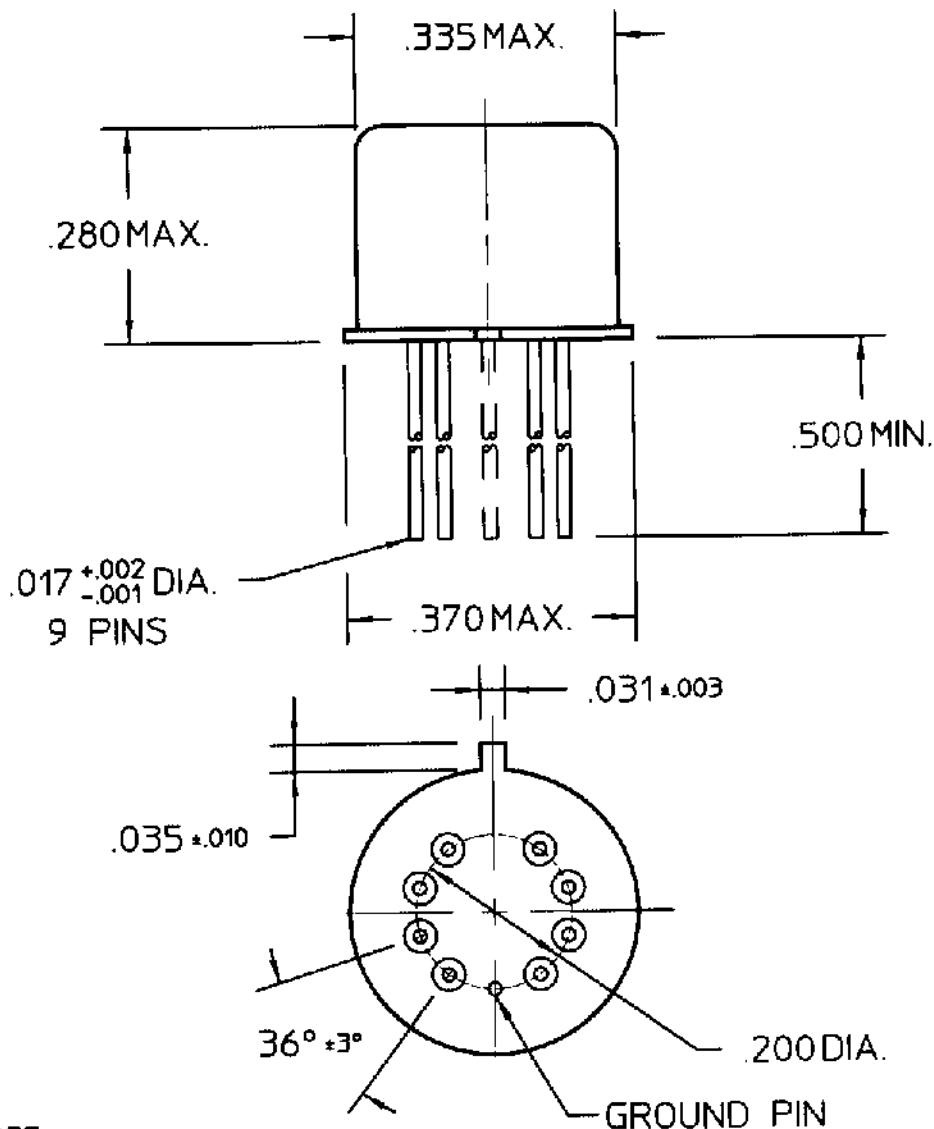

REV. 0

DCO 141077


COIL: @ 25°C
 RESISTANCE 1560 OHMS $\pm$ 10%
 NOMINAL VOLTAGE 26.5 VDC
 MUST OPERATE 14.2
 MUST RELEASE 8.0 VDC MAX., 1.37 VDC MIN.

ENVIRONMENT:

VIBRATION 10 CPS TO 3000 CPS @ 30 g's
 SHOCK 75 g's 6 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 2.0 MS MAX.
RELEASE TIME 1.5 MS MAX.
CONTACT STABILIZATION 2.0 MS MAX.

CUSTOMER DATA SHEET

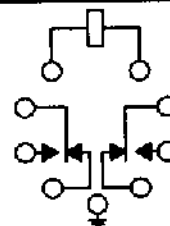

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 1A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. B.D. 5/24/99 *CK* *VERA* 5/24/99

COMMUNICATIONS
INSTRUMENTS, INC.

JMACG-26XP

CUST. QPL
 CUST. NO. M39016/9-090P

TYPE JMA RELAY