



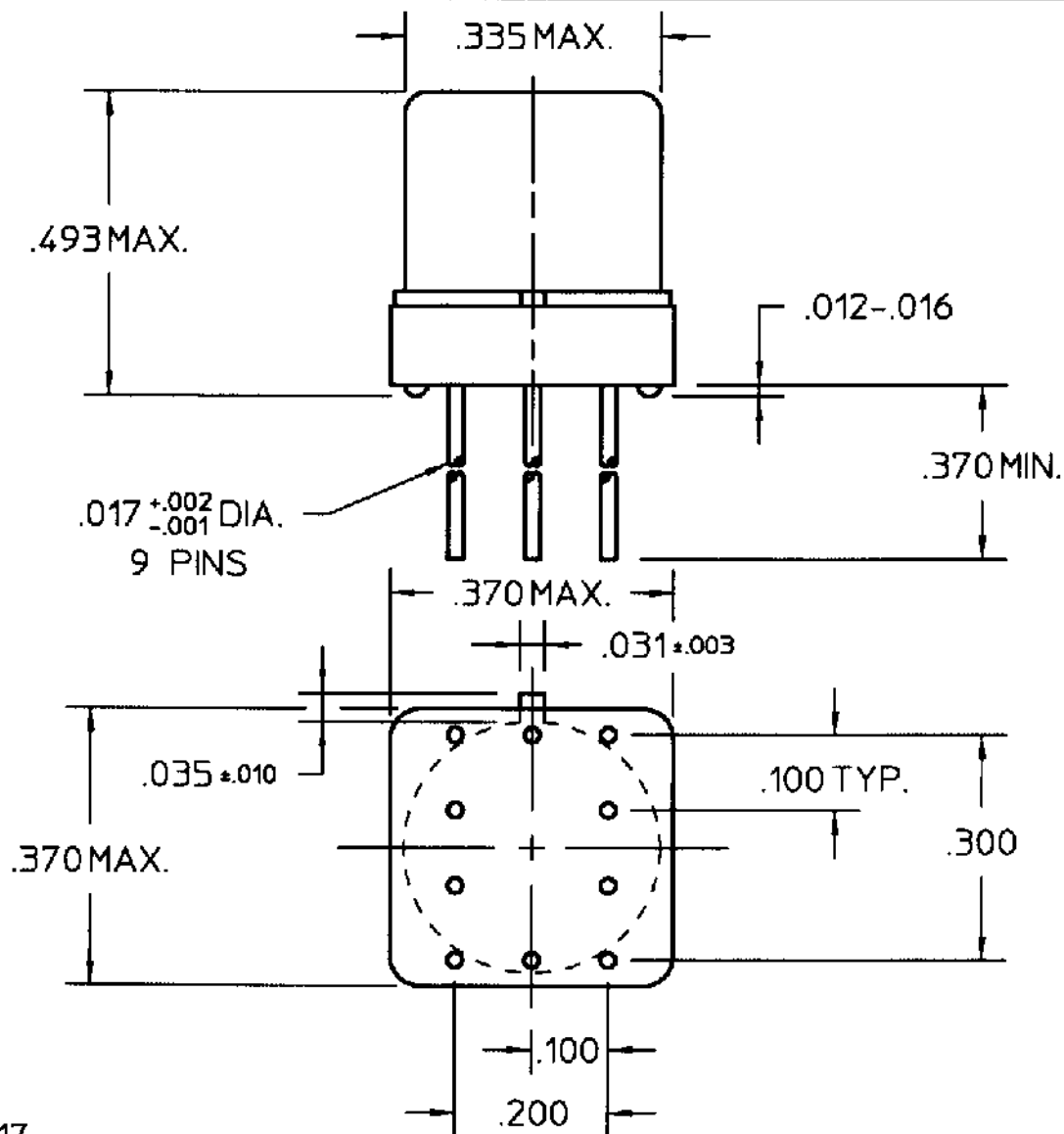

REV. 0
DCO 140817

COIL: @ 25°C
RESISTANCE 850 OHMS $\pm$ 10%
NOMINAL VOLTAGE 12.0 VDC
MUST OPERATE 7.4 VDC
TURN-ON BASE CURRENT 0.12 mADC
MUST RELEASE 4.0 VDC MAX, 0.63 VDC MIN.

CUSTOMER DATA SHEET

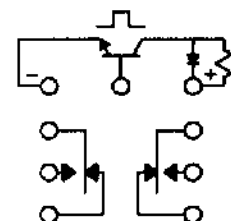

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO
1A 28 VDC RESISTIVE 100,000
OPERATIONS

ENVIRONMENT:
VIBRATION 10 CPS TO 3000 CPS @ 30 g's
SHOCK 75 g's 6 MS. DURATION
TEMPERATURE -65 °C TO +125 °C

NOTES: TURN-ON TIME 4.0 MS MAX
TURN-OFF TIME 7.5 MS MAX
CONTACT BOUNCE 1.5 MS MAX

DR. R.B. 12/17/98 GK 12/17/98

COMMUNICATIONS
INSTRUMENTS, INC.

CUST. QPL
CUST. NO. M28776/3-044L

TYPE JMST RELAY

JMSCT-12XLS