


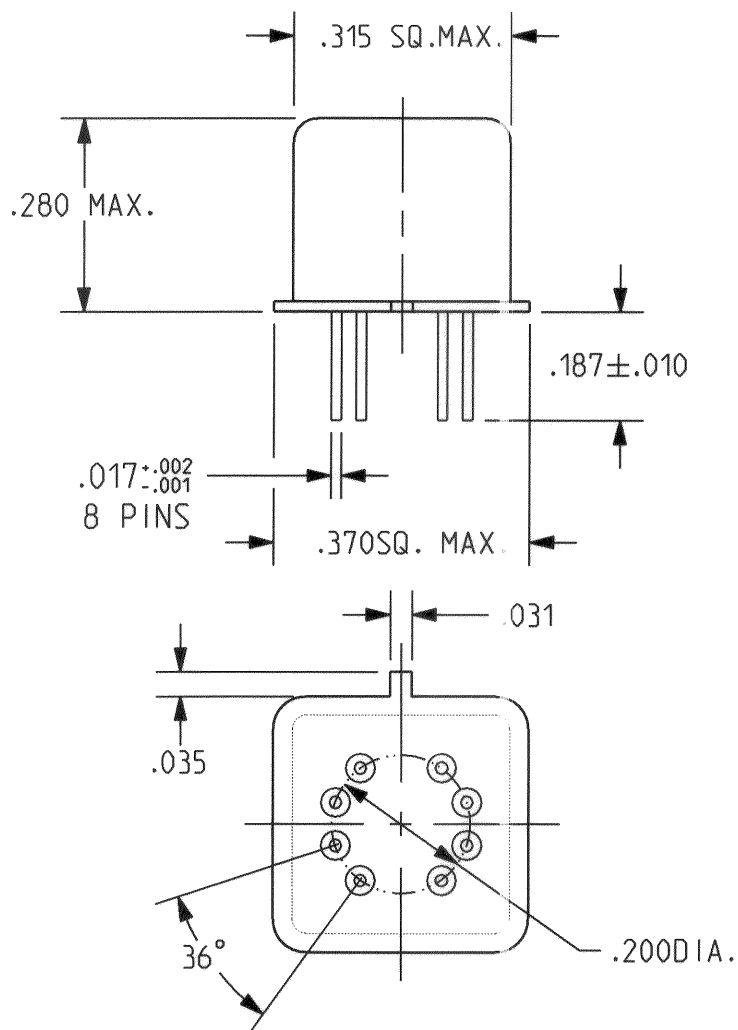

REV. A

DCO 144521

COIL: @ 25°C

RESISTANCE 880 OHMS ±10%

NOMINAL VOLTAGE 18.0 VDC

MUST OPERATE 10.5 VDC

MUST RELEASE 6.0 VDC MAX, 0.91 VDC MIN.

ENVIRONMENT:

VIBRATION 10 Hz TO 3000 Hz @ 30 g's

SHOCK 100 g's 11 MS. DURATION

TEMPERATURE -65 °C TO +125 °C


NOTES: OPERATE TIME 2 MS MAX

RELEASE TIME 1.5 MS MAX

OPERATE BOUNCE 1.0 MS MAX

RELEASE BOUNCE 1.5 MS MAX

CUSTOMER DATA SHEET

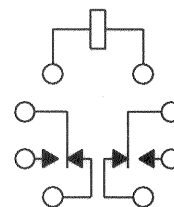

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 1A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. B.D. 11SEP2008

CK *[Signature]* 9/11/08

Tyco Electronics

©COPYRIGHT 2005

TYCO ELECTRONICS CORPORATION
ALL INTERNATIONAL RIGHTS RESERVED

CUST. C. I. I. STD.

CUST. NO. REV.

TE NUMBER

1617105-5

CII PART NUMBER

MW 6HP-18P