
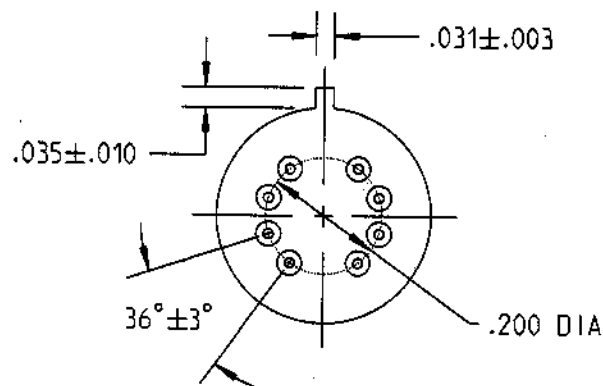


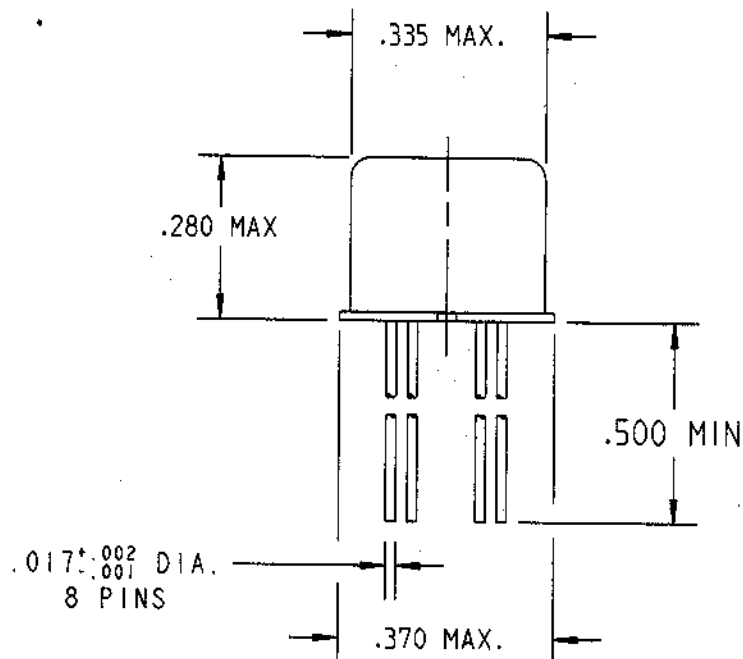


REV. 0  
DCO 143824

|                 |                           |
|-----------------|---------------------------|
| COIL: @ 25°C    |                           |
| RESISTANCE      | 220 OHMS ±10%             |
| NOMINAL VOLTAGE | 9.0 VDC                   |
| MUST OPERATE    | 6.3 VDC                   |
| MUST RELEASE    | 4.2 VDC MAX. 0.9 VDC MIN. |

|              |                                   |
|--------------|-----------------------------------|
| ENVIRONMENT: |                                   |
| VIBRATION    | 10 Hz TO 3000 Hz @ 30 g's         |
| SHOCK        | 75 g's 6 MS. DURATION             |
| TEMPERATURE  | -65 °C TO +125 °C                 |
| NOTES:-      | OPERATE TIME 2.0 MS MAX.          |
|              | RELEASE TIME 4.0 MS MAX.          |
|              | CONTACT STABILIZATION 2.0 MS MAX. |

# CUSTOMER DATA SHEET

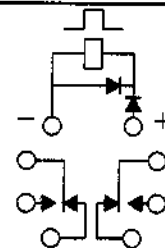

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 1A  
28 VDC RESISTIVE 100,000 OPERATIONS

DR. B.D. 310CT03

*Handwritten signature and date: 10/31/03*

**CII Technologies**  
advanced control electronic solutions

CUST. QPL  
CUST. NO. M39016/20-051P REV.

"JMADD" RELAY

JMACDD-9XP