


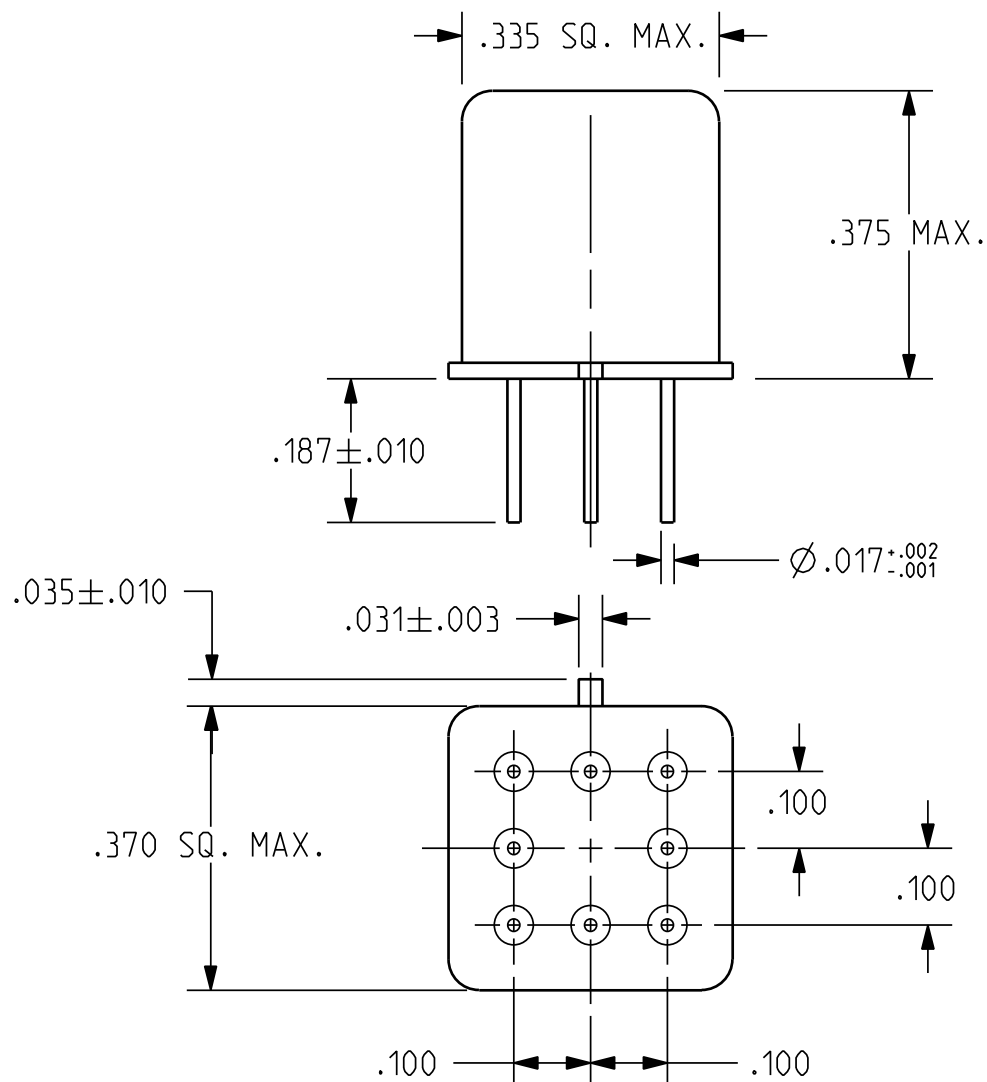


REV.0
DCO 143870

COIL: @ 25°C
 RESISTANCE 1600 OHMS ±10%
 NOMINAL VOLTAGE 18.0 VDC
 MUST OPERATE 9.8 VDC
 MUST RELEASE 6.0 VDC MAX., 0.92 VDC MIN.

ENVIRONMENT:
 VIBRATION 10 Hz TO 3000 Hz @ 30 g's
 SHOCK 75 g's 6 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C
 NOTES: OPERATE TIME 4.0 MS MAX.
 RELEASE TIME 2.5 MS MAX.
 CONTACT STABILIZATION TIME 2.5 MS MAX.

CUSTOMER DATA SHEET

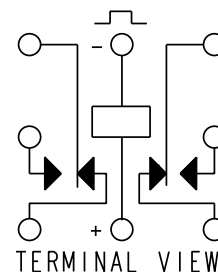

CONTACT RATING: LOW LEVEL TO 1 AMP
 28 VDC RESISTIVE 100,000 OPERATIONS MIN.

DR. B.D. 22APR04

CK. JERRY C. 4/22/04

CII Technologies
 advanced control electronic solutions

CUST. QPL
 CUST. NO. M39016/41-048M REV.

"JMGS" RELAY

JMGSP-18M