


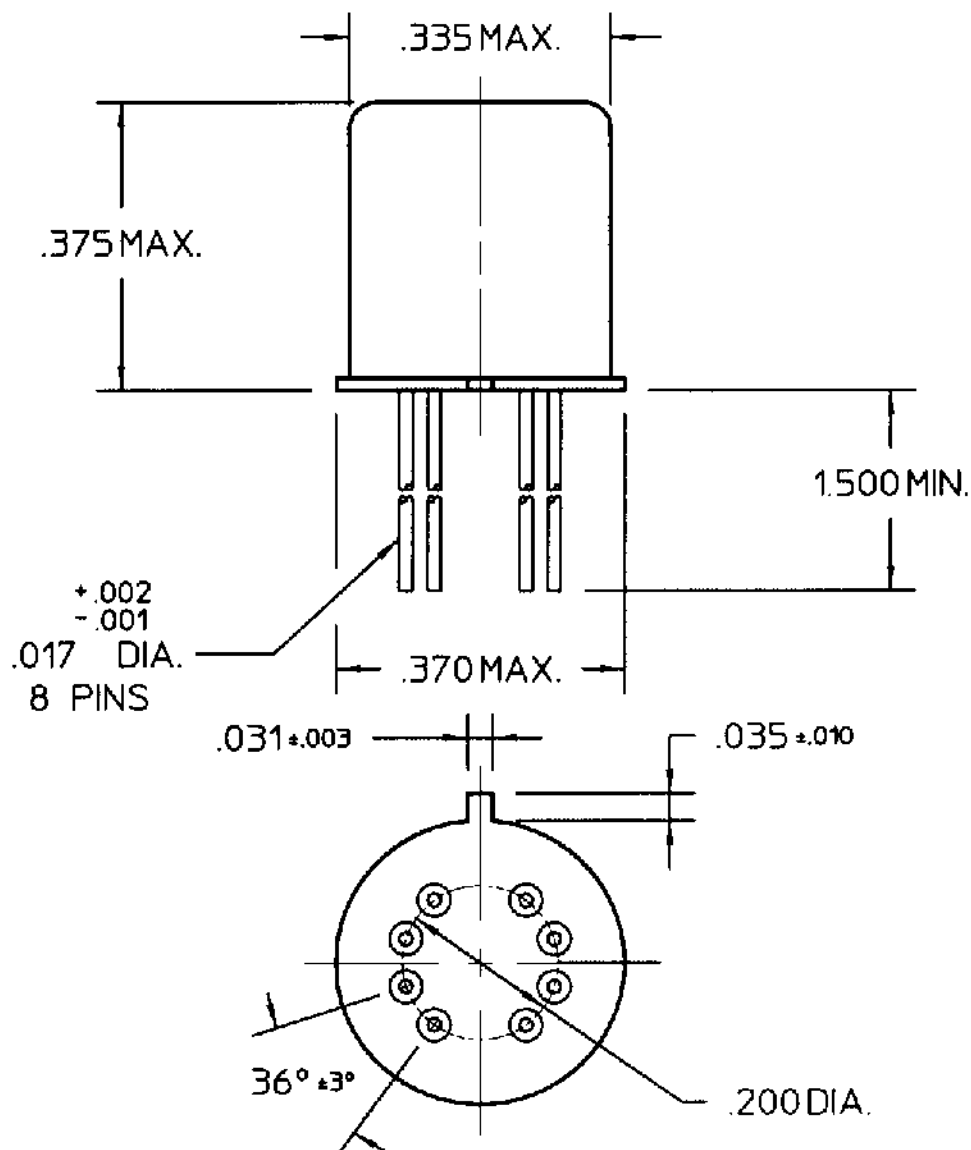

REV. 0

DCO 142073

COIL: @ 25°C
 RESISTANCE 64 OHMS ±10%
 NOMINAL VOLTAGE 5.0 VDC
 MUST OPERATE 2.9 VDC

MUST RELEASE 2.2 VDC MAX, 0.8 VDC MIN.

ENVIRONMENT:

VIBRATION 10 CPS TO 3000 CPS @ 30 g's

SHOCK 75 g's 6 MS. DURATION


TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 4.0 MS MAX

RELEASE TIME 7.5 MS MAX

CONTACT STABILIZATION 2.0 MS MAX

CUSTOMER DATA SHEET

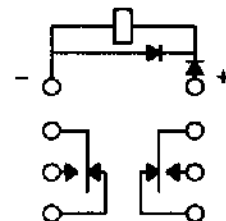

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 1A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. PBB 6/6/00

CK. *[Signature]* 6/6/00



COMMUNICATIONS
 INSTRUMENTS, INC.

CUST. QPL

CUST. NO. M39016/21-007P

REV.

JMSDD RELAY

JMSWDD-5XP