
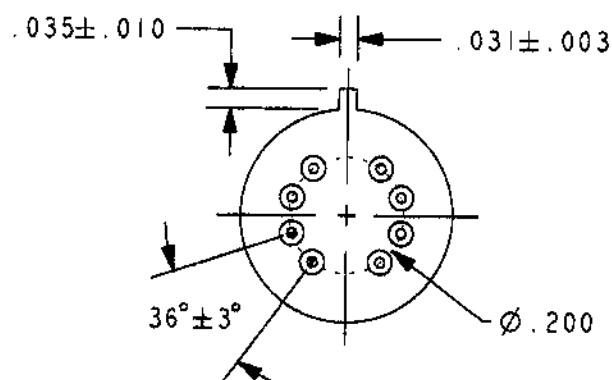


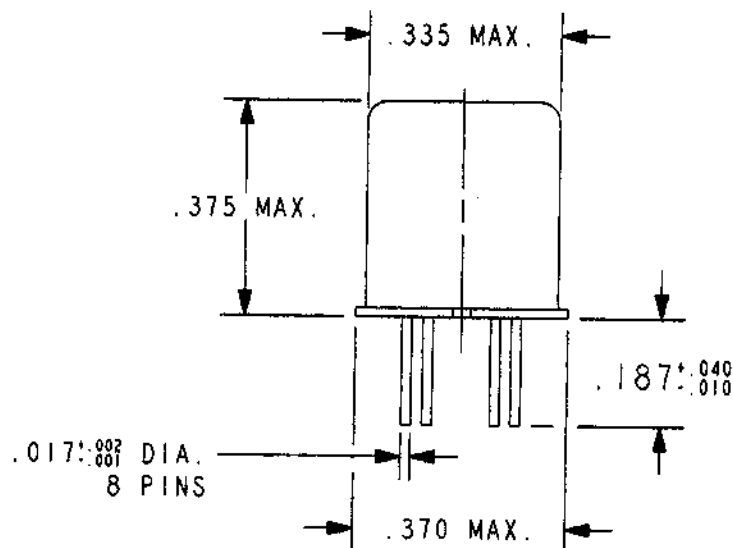

REV. 0

DCO 143180

COIL: @ 25°C
 RESISTANCE 850 OHMS ±10%
 NOMINAL VOLTAGE 12.0 VDC
 MUST OPERATE 7.0 VDC
 MUST RELEASE 4.0 VDC MAX, 0.64 VDC MIN.


ENVIRONMENT:

VIBRATION 10 CPS TO 3000 CPS @ 30 g's
 SHOCK 75 g's 6 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 4.0 MS MAX.
 RELEASE TIME 7.5 MS MAX.

CONTACT STABILIZATION 2.0 MS MAX.

CUSTOMER DATA SHEET

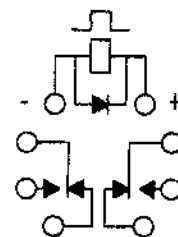

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 1A
 28 VDC RESISTIVE 100,000 OPERATIONS

DR. B.D. 8/29/01 CA Jazay 8/30/01

CII Technologies
 advanced control electronic solutions

CUST. OPL
 CUST. NO. M39016/16-027P REV.

"JMSPD" RELAY

JMSPD-12XP