

SUMMARY

Wires

Coax	1
------	---

Image is for illustrative purpose only

Series	0A
Termination type	Coupler/adaptor/bridge
IP rating	50
AWG wire size	0.00 - 0.00
Cable Ø	0.00 - 0.00 mm
Status	active

Download

[Request a quote](#)[Catalog](#)

TECHNICAL DETAILS

Mechanics

Shell Style/Model	ABA*: Adapter from LEMO receptacle to BNC plug
Keying	
Housing Material	Brass (nickel plated [SAE AMS QQ N 290]) shell, collet nut, latch sleeve and mid pieces
Weight	17.51 g

Performance

Configuration	0A.275 : 1 Coax (75 Ohm)
Insulator	
Rated Current	

Specifications


Contact Type: Coaxial 75 Ohm

Others

Endurance (Shell): >1000 mating cycles
Salt Spray Corrosion: >144 hr

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

DRAWINGS

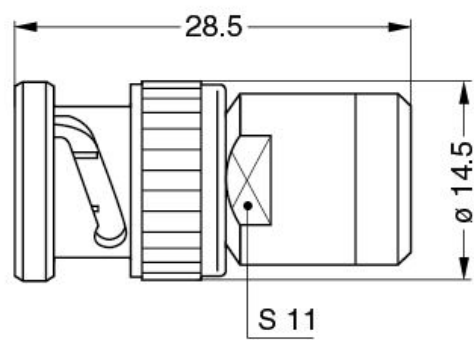

Dimensions

	A	L	S1
mm.	14.5	28.5	11
in.	0,57	1,12	0,43

RECOMMENDED BY LEMO

Tools

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.