

产品规格书

PRODUCT SPECIFICATION SHEET

物料名称

APPELLATION: A11 无线接收单线圈模组

MODE: YX-A11-R421524-G0825

客户料号

No.:

生 产 方	工艺审核 TECHNICAL	品质审核 QUALITY	项目审核 PROJECT	开发审核 DEVELOPING


客 户 方	材料工程师 Materials Engineer	设计工程师 Engineer	主管审批 Approval	研发体系 R & D System



变更履历表

[illegible]

1. DIMENSIONS & MARKING:

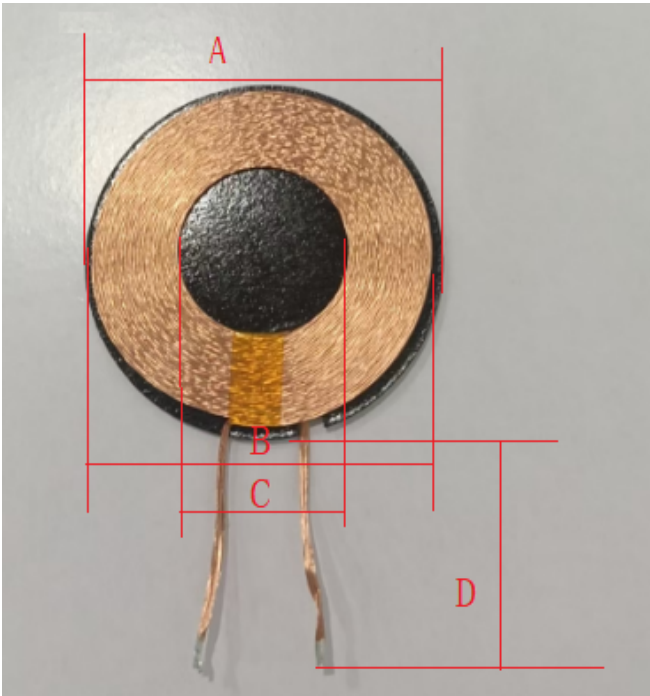

背部带手撕贴

Symbol	A	B	C	D	E	F
Value(mm)	42.0max	41.0max	20.50±1	25.00±1.00		

2. ELECTRICAL SPECIFICATIONS @25℃

- 2.1 Operating Temperature range: -40℃~+85℃
- 2.2 Storage temperature range: -25℃ TO +125℃
- 2.3 The test frequency: 100 KHz, 100mV @ 25℃,65%
- 2.4 OCL : 12.5±10% μH .
- 2.5 Diameter : 0.08*24P*2P
- 2.6 Turns Ratio: 15T
- 2.7 DCR: 200mR

DRAWN BY:	CHECKED BY:	APPROVED BY:	CUSTOMER:
jiuguijiang	jiuguijiang	wangchunxia	PART NO. : YX-A11-R421524-G0825

CND-TEK


深圳磁联达电子有限公司

REV. : A
PAGE: 3 Of 4

3、 Bill of materials:

序号	物料名称	物料规格	材料使用	备注
1	丝包线	0.08mm*24*2P	√	
2	软磁片	42*0.3mm单槽软磁	√	
3	锡条	Sn97.3-0.7Cu	√	

4、 Packaging:

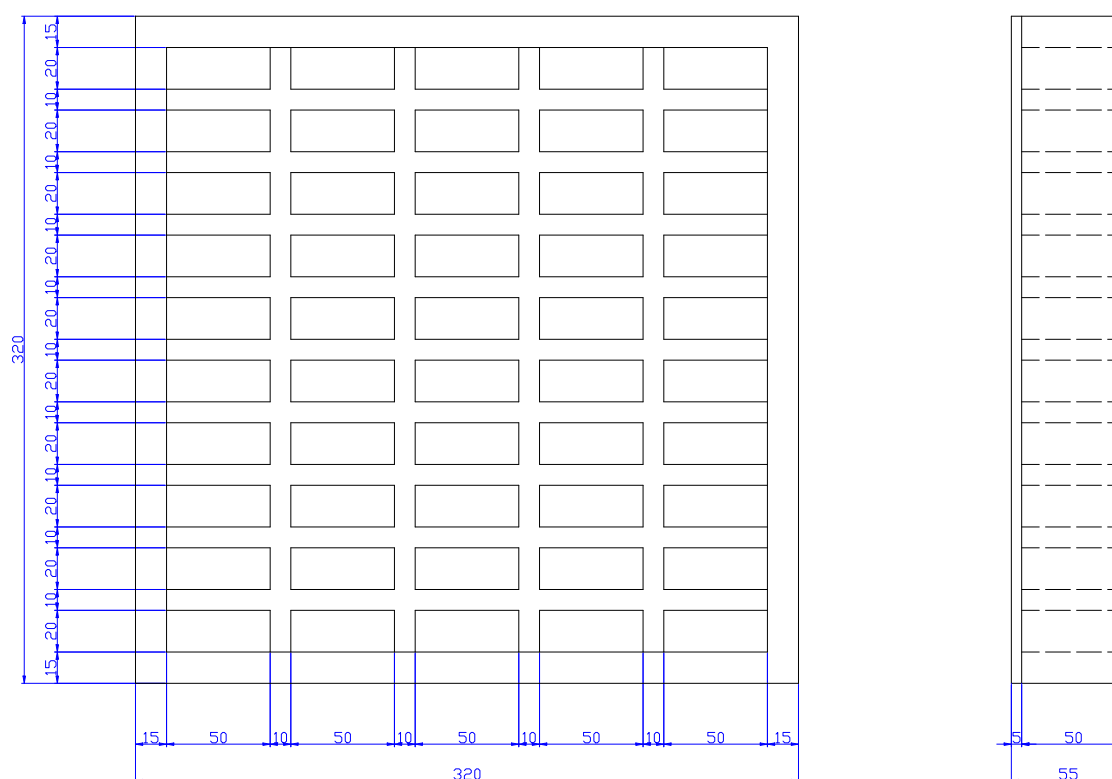

- 4.1 Quantity per grid: 20 PCS
- 4.2 Quantity per carton: $20 \times 50 = 1000$ PCS
- 4.3 Quantity per carton: $1000 \times 3 = 3000$ PCS
- 4.4 Carton size: $350 \times 350 \times 180$ mm.

DRAWN BY:	CHECKED BY:	APPROVED BY:	CUSTOMER:
jiuguijiang	jiuguijiang	wangchunxia	PART NO. : YX-A11-R421524-G0825
 深圳磁联达电子有限公司			REV. : A
			PAGE: 4 Of 4