


RoHS


Specifications(规格):

- 1.Impedance(特性阻抗) : 50Ω;
- 2.Frequency (工作频率) : DC~20GHz;
- 3.VSWR (电压驻波比) : 1.20 Max.@18GHz;
- 4.Insulation resistance(绝缘阻抗) : ≥1000MΩ;
- 5.Dielectric withstand voltage (介质耐电压) : ≥500V AC;
- 6.Mating cycles (耐久性) : ≥500 cycles;
- 7.Temperature range(使用温度): -40℃~+125℃;

REVISIONS					
REV.	ECN NO.	LOCATION	DESCRIPTION	DATE	DESIGN
A0	N/A		INITIAL RELEASE		

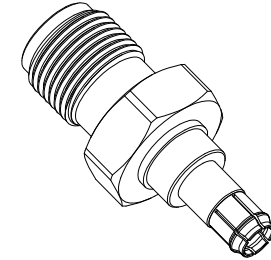

3D View

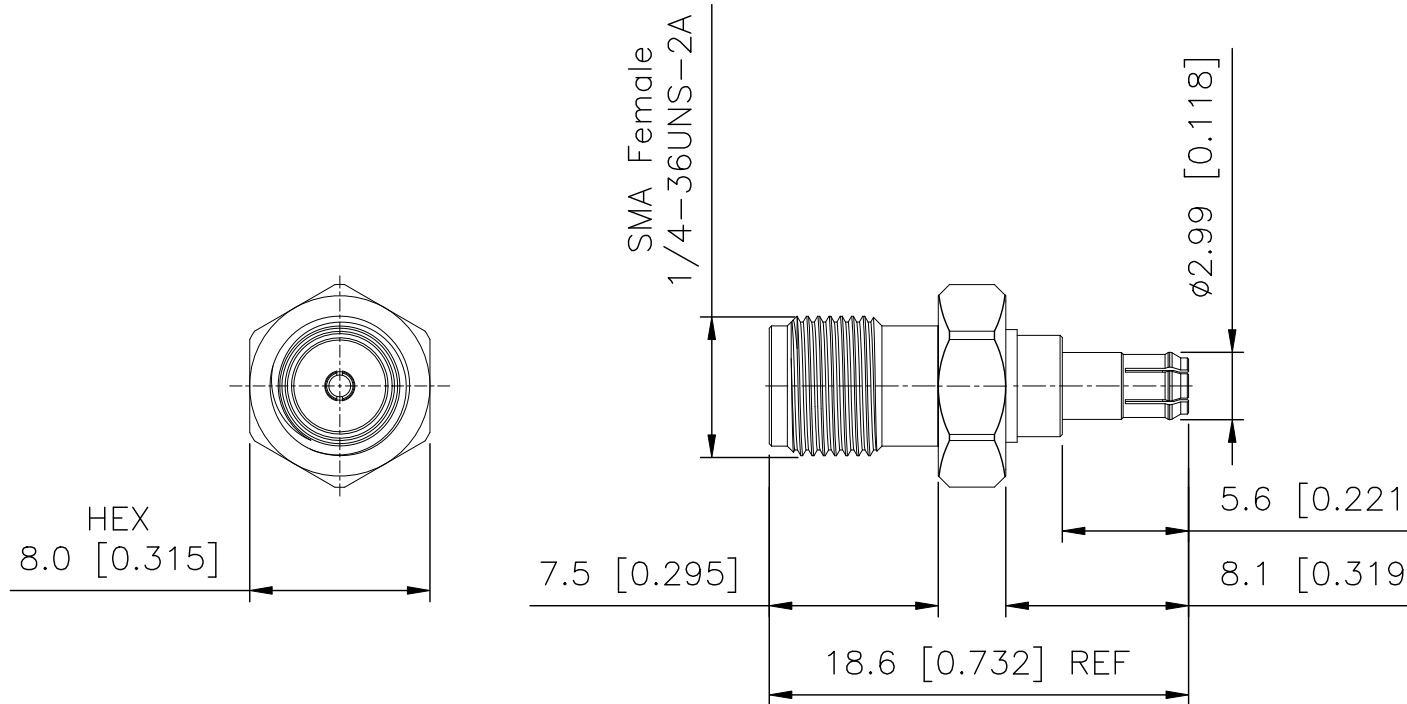

ANGULAR	±5°
X.	±0.50
X.x	±0.20
X.xx	±0.10
X.xxx	±0.05
UNSPECIFIED TOLERANCES	

3	Center Conductor	Beryllium Bronze	Gold PLATED	1 PC	
2	Dielectric	PTFE		1 PC	
1	Outer Conductor	SUS/BeCu	Passivation/Ni PLATED	1 PC	
NO.	NAME	MATERIAL	FINISH (Contact)	Q'TY	Note

www.helloxkb.com www.helloxkb.cn www.xk-dg.cn



DESIGN	希文	VIEW:	MODEL TYPE: SMA/MINI FAKRA(R) Adapter
CHECKED		UNIT: mm/in	PART NO.: XMADMK-5FFS20-CC01R
APPROVED		SIZE: A4	DWG NO.: X-XMADMK-5FFS20-CC01R
			SCALE PAGE REVISION
			N/A 1/1 A0

XKB INDUSTRIAL PRECISION CO.,LIMITED