




Wire Wound Chip Common Mode Choke Coil

High Common Mode Impedance at High Frequency.
Excellent Noise Suppression Performance.
Small Size and Low Profile, Surface Mount Type.
Operating Temperature Range: -40°C to $+85^{\circ}\text{C}$.
RoHS Compliant.


Part Number	Electrical Specifications @25°C				
	Common mode Impedance (ohm $\pm 25\%$ @100M)	DCR (Ω Max)	Rated Current mA Max	Rated Volt (Vdc)	IR M(Ω Min)
CW2012-2-801TS	800	0.78	300	50	10

MECHANICAL

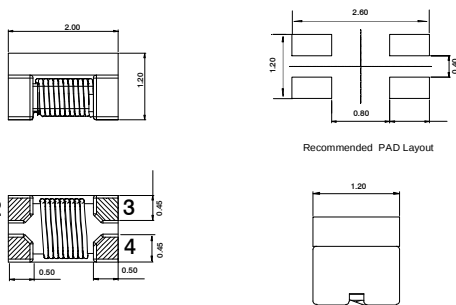


Dimensions in mm


SCHEMATICS

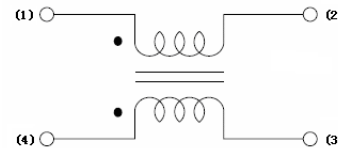

IMPEDEANCE FREQUENCY

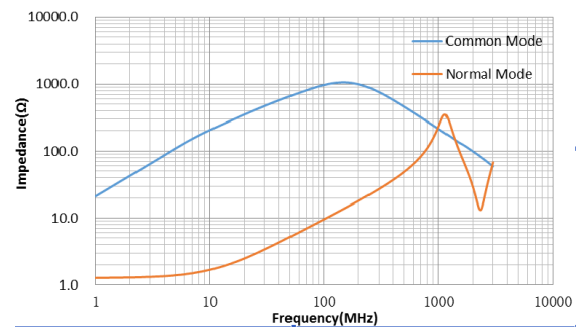

TAPING AND PACKING

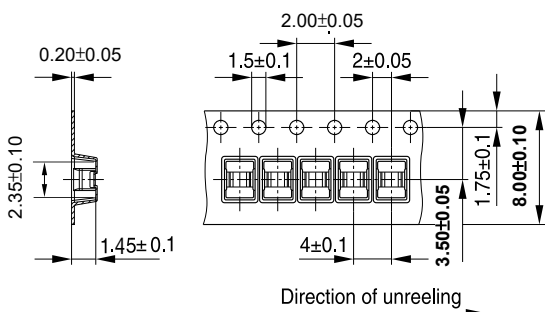


Quantity (pcs):

10000 PCS PER REEL
5 REELS PER CARTON
50000 PCS PER CARTON

IND1752-J-E

Reel

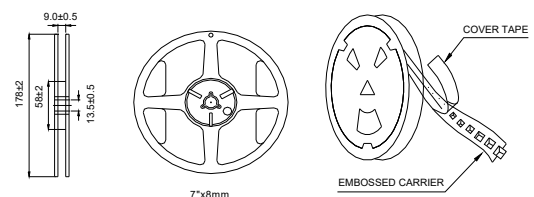

Dimensions in mm