
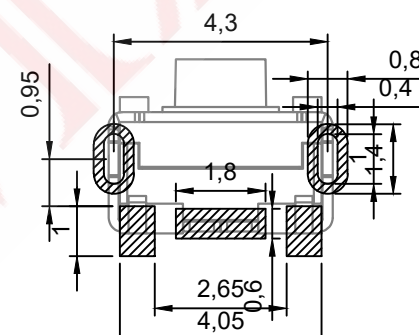


主要技术参数、性能

The Main Thchnology Performance

额定电流、电压 Rate voltage,current	50mA DC12V
接触电阻 Contact resistance	$\leq 100\text{m}\Omega$
按力 Operating force	$\pm 50\text{gf}$
行程 Travel	$0.20 \pm 0.10\text{mm}$
绝缘电阻 Insulated resistance	$\geq 100\text{M}\Omega$
介电强度 Dielectric strength	$\geq 250\text{VAC}/1\text{mi}$

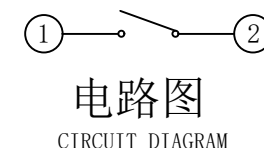


PCB. 焊接图
PCB. WELDING DRAWING

G	按钮	LCP	1	黑色
F	铜盖	黄铜	1	镀银
E	塑盖	LCP	1	白色
D	黄膜	聚酰亚胺	1	黄色
C	弹片	不锈钢	2	镀银
B	本体	PPA	1	黑色
A	卡件	黄铜	1	镀银
ITEM	名称	材质	数量	表面处理/颜色
	DESCRIPTION	MATERIAL	QTY	FINISH/COLOR

A. 系列:B-2.5*3.0系列
B. 贴装方式:5-卧式贴片
C. 规格:B-5P
D. 操作高度:35-3.5mm
E. 操作力度:1-180/2-260gf
F. 操作寿命:1-50,000次
G. 固定方式:1-无柱
H. 物料编码:E-常规(确认待编)

			GENERAL TOLERANCE	
			$\geq 0 \sim 2 <$	± 0.15
DESIGN	WANGGUIFA	2018.06.12	$\geq 2 \sim 5 <$	± 0.25
CHECKED	ZHENGUILAN	2018.06.12	$\geq 0 \sim 2 <$	± 0.15
APPROVED	LILIANJIANG	2018.06.14	≥ 5	± 0.35

 FIRST VIEW



The copyright belongs to samzo parts [China] Co., Ltd. please use the material after samzo parts agree to authorize. The final right of interpretation belongs to samzo parts.

WWW.KKK-JP.COM

TITLE:	
--------	--

1.9*4.5*3.5 mm 5P卧式

of DWG NO: B5B35-P061

PART NO: B5B3519012

MODEL NO: B5B35-* -11E

NAME:

TACT SWITCH

SAMZO COMPONENTS
Electronic switch and connector manufacturer