

地址: 广东省深圳市宝安区松岗沙浦围前海聚英产业园

官网: www.18sz.cn

版本: A0

电话: 0755-23322028

传真: 0755-23322028

邮箱: jyjm@18sz.cn

一、产品简介:

名称: 0B-EXG插座

外壳材料: 铜合金镀珍珠

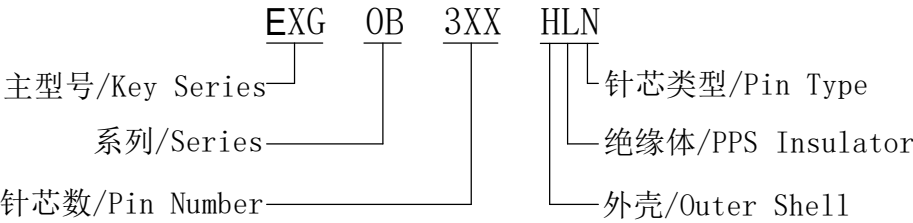
铭型号: EXG. 0B. 3XX. HLN

针芯材料: 铜合金镀金

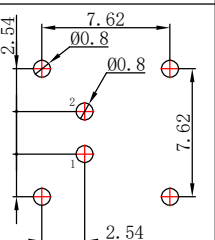
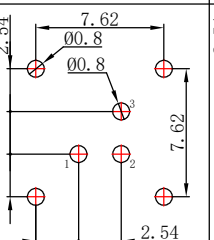
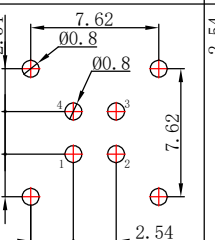
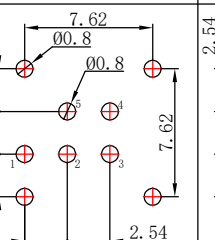
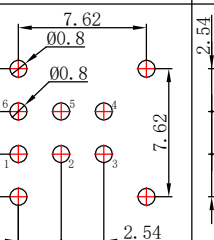
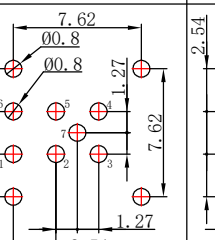
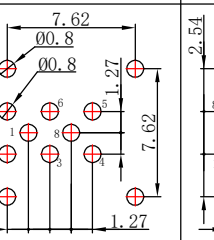
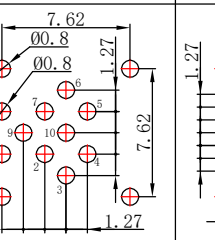
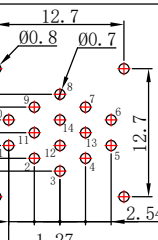
二、主要性能参数:

使用环境	室内	温度等级	-40° C, +80° C
冲击	100g, 6ms	机械寿命	>3000次
绝缘电阻	≥5000MΩ (常态下)	震动	15 g [10 Hz - 2000 Hz]
温度	60° C, 95% Max	盐雾	>144h
防水等级	IP50(插合时)	屏蔽	>75dB at 10Mhz, >40dB at 1Ghz

三、编码规则:



四、PCB开孔尺寸:

编号/针芯数	302	303	304	305	306	307	308	310	314
PCB板开孔尺寸 A-A									

五、外形尺寸及结构 (未注公差: GB/T 1804-m) 单位: mm

