
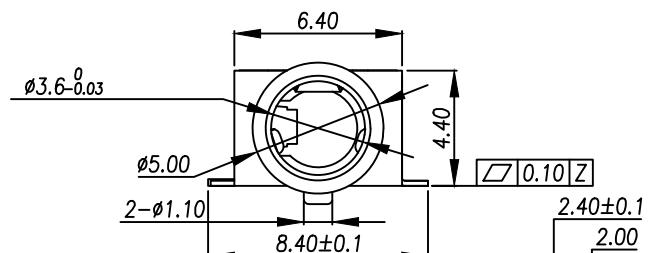
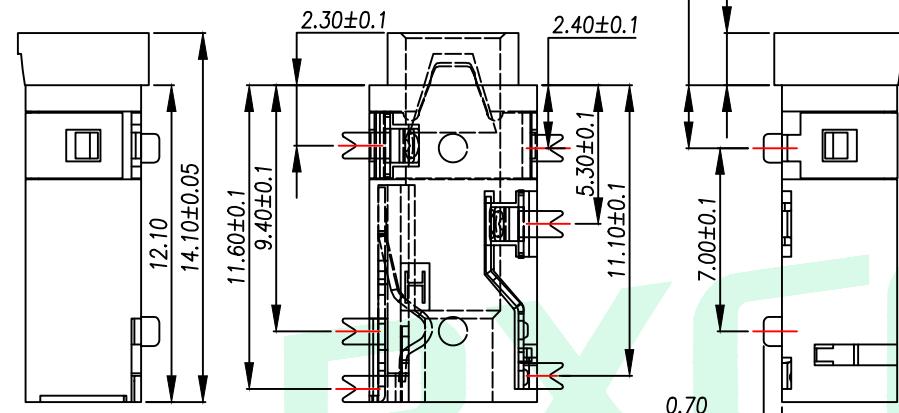
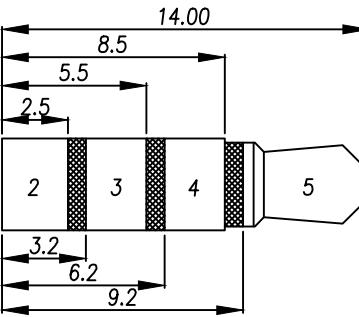
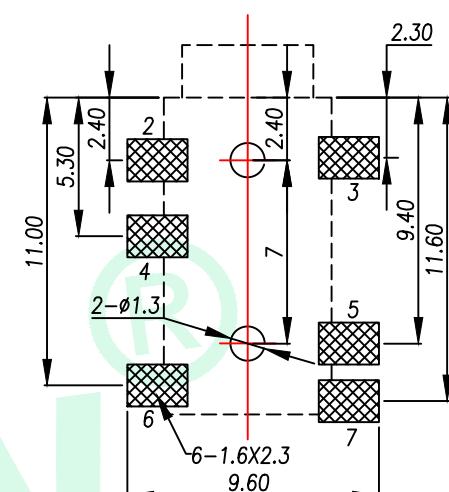


A	B	C	D	E																																														
1	2	3	4	5																																														
																																																		
				P.C.B LAYOUT TOP VIEW																																														
4			<table border="1"> <tr> <td>PJ-342P6C1</td> <td>单定位柱</td> </tr> <tr> <td>PJ-342P6C2</td> <td>双定位柱</td> </tr> </table>	PJ-342P6C1	单定位柱	PJ-342P6C2	双定位柱	<table border="1"> <tr> <td>序号</td> <td>产品名称</td> <td>数量</td> <td>材料</td> <td>规格</td> <td>电镀</td> </tr> <tr> <td>6</td> <td>4#开关脚</td> <td>1</td> <td>磷铜</td> <td>0.25T</td> <td>镀金</td> </tr> <tr> <td>5</td> <td>4#弹片脚</td> <td>1</td> <td>磷铜</td> <td>0.25T</td> <td>镀金</td> </tr> <tr> <td>4</td> <td>3#开关脚</td> <td>1</td> <td>磷铜</td> <td>0.2T</td> <td>镀金</td> </tr> <tr> <td>3</td> <td>3#脚</td> <td>2</td> <td>磷铜</td> <td>0.2T</td> <td>镀金</td> </tr> <tr> <td>2</td> <td>盖脚</td> <td>1</td> <td>磷铜</td> <td>0.2T</td> <td>镀金</td> </tr> <tr> <td>1</td> <td>基座</td> <td>1</td> <td>PPA</td> <td></td> <td>黑色</td> </tr> </table>	序号	产品名称	数量	材料	规格	电镀	6	4#开关脚	1	磷铜	0.25T	镀金	5	4#弹片脚	1	磷铜	0.25T	镀金	4	3#开关脚	1	磷铜	0.2T	镀金	3	3#脚	2	磷铜	0.2T	镀金	2	盖脚	1	磷铜	0.2T	镀金	1	基座	1	PPA		黑色
PJ-342P6C1	单定位柱																																																	
PJ-342P6C2	双定位柱																																																	
序号	产品名称	数量	材料	规格	电镀																																													
6	4#开关脚	1	磷铜	0.25T	镀金																																													
5	4#弹片脚	1	磷铜	0.25T	镀金																																													
4	3#开关脚	1	磷铜	0.2T	镀金																																													
3	3#脚	2	磷铜	0.2T	镀金																																													
2	盖脚	1	磷铜	0.2T	镀金																																													
1	基座	1	PPA		黑色																																													
5		SCHEMATIC	<table border="1"> <tr> <td>GENERAL TOLERANCE</td> <td colspan="3">DONGGUAN BAOXUN PRECISION TECHNOLOGY CO., LTD</td> </tr> <tr> <td>DIM. x x.x x.xx x.x.x</td> <td>TOL. ±0.20 ±0.10 ±0.05</td> <td colspan="2">TITLE: PJ 耳机插座</td> </tr> <tr> <td colspan="2">GENERAL ANGLE: x° ±5°</td> <td colspan="2">DWG. NO.: PJ-342P6CX</td> </tr> <tr> <td colspan="2"></td> <td colspan="2">DRAWN: ELLA</td> </tr> <tr> <td>UNIT: mm</td> <td>SCALE: none</td> <td>SHEET: 1 of 1</td> <td>DWG. SIZE: A4</td> </tr> <tr> <td></td> <td></td> <td></td> <td>LAYER: bxconn</td> </tr> <tr> <td></td> <td></td> <td></td> <td>APPROVED: WILL</td> </tr> </table>	GENERAL TOLERANCE	DONGGUAN BAOXUN PRECISION TECHNOLOGY CO., LTD			DIM. x x.x x.xx x.x.x	TOL. ±0.20 ±0.10 ±0.05	TITLE: PJ 耳机插座		GENERAL ANGLE: x° ±5°		DWG. NO.: PJ-342P6CX				DRAWN: ELLA		UNIT: mm	SCALE: none	SHEET: 1 of 1	DWG. SIZE: A4				LAYER: bxconn				APPROVED: WILL																			
GENERAL TOLERANCE	DONGGUAN BAOXUN PRECISION TECHNOLOGY CO., LTD																																																	
DIM. x x.x x.xx x.x.x	TOL. ±0.20 ±0.10 ±0.05	TITLE: PJ 耳机插座																																																
GENERAL ANGLE: x° ±5°		DWG. NO.: PJ-342P6CX																																																
		DRAWN: ELLA																																																
UNIT: mm	SCALE: none	SHEET: 1 of 1	DWG. SIZE: A4																																															
			LAYER: bxconn																																															
			APPROVED: WILL																																															

主要技术性能	
额定电负荷	DC 12V/0.5A
接触电阻	≤0.03Ω
绝缘电阻	≥100MΩ
耐压	AC500V(50Hz)/min
插拔力	3-20N
使用温度范围	-25~+85
使用寿命	5000次

GENERAL TOLERANCE	DONGGUAN BAOXUN PRECISION TECHNOLOGY CO., LTD		
DIM. x x.x x.xx x.x.x	TOL. ±0.20 ±0.10 ±0.05	TITLE: PJ 耳机插座	
GENERAL ANGLE: x° ±5°		DWG. NO.: PJ-342P6CX	
		DRAWN: ELLA	
UNIT: mm	SCALE: none	SHEET: 1 of 1	DWG. SIZE: A4
			LAYER: bxconn
			APPROVED: WILL

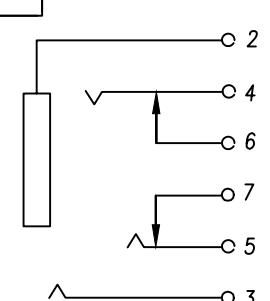