


● SPECIFICATION TABLE:

PART NUMBER 品名	INDUCTANCE (μ H) 电感值	DCR (Max) (Ω) 直流电阻	Isat (Max.) (A) 饱和电流	Irms (Max.) (A) 额定电流	S. R. F. (Min.) (MHz) 自谐频率
NR6045-1R0N	1.0 $\pm$ 30%	0.011	9.85	5.14	100
NR6045-1R5N	1.5 $\pm$ 30%	0.012	8.80	4.95	65
NR6045-2R2N	2.2 $\pm$ 30%	0.014	6.75	4.60	52
NR6045-3R3N	3.3 $\pm$ 30%	0.024	5.90	3.70	32
NR6045-4R7M	4.7 $\pm$ 20%	0.031	4.97	3.30	24
NR6045-6R8M	6.8 $\pm$ 20%	0.035	3.90	3.00	20
NR6045-100M	10 $\pm$ 20%	0.048	3.20	2.45	15
NR6045-150M	15 $\pm$ 20%	0.068	2.50	2.05	12
NR6045-220M	22 $\pm$ 20%	0.089	2.05	1.80	10
NR6045-330M	33 $\pm$ 20%	0.137	1.65	1.45	8
NR6045-470M	47 $\pm$ 20%	0.200	1.40	1.20	6
NR6045-560M	56 $\pm$ 20%	0.221	1.30	1.10	6
NR6045-680M	68 $\pm$ 20%	0.289	1.20	1.00	6
NR6045-101M	100 $\pm$ 20%	0.433	0.95	0.80	4
NR6045-121M	120 $\pm$ 20%	0.484	0.85	0.77	4
NR6045-151M	150 $\pm$ 20%	0.580	0.80	0.70	4
NR6045-221M	220 $\pm$ 20%	0.834	0.70	0.59	4
NR6045-331M	330 $\pm$ 20%	1.270	0.57	0.57	3
NR6045-471M	470 $\pm$ 20%	1.800	0.50	0.42	2
NR6045-681M	680 $\pm$ 20%	2.500	0.42	0.33	2
NR6045-102M	1000 $\pm$ 20%	4.500	0.30	0.30	1
NR6045-152M	1500 $\pm$ 20%	6.500	0.24	0.21	1

Remark: 1. Inductance Tested at 1MHz, 0.25Vrms (20℃)
2. Isat: DC current at which the inductance drops approximate 30% from its value without current;
3. Irms: DC current that causes the temperature rise ($\Delta T = 40^{\circ}C$) from 25° C ambient.
4. Operating Temperature : -25℃ ~ +125℃




● SHAPES AND DIMENSIONS 外形尺寸 (Unit:mm)

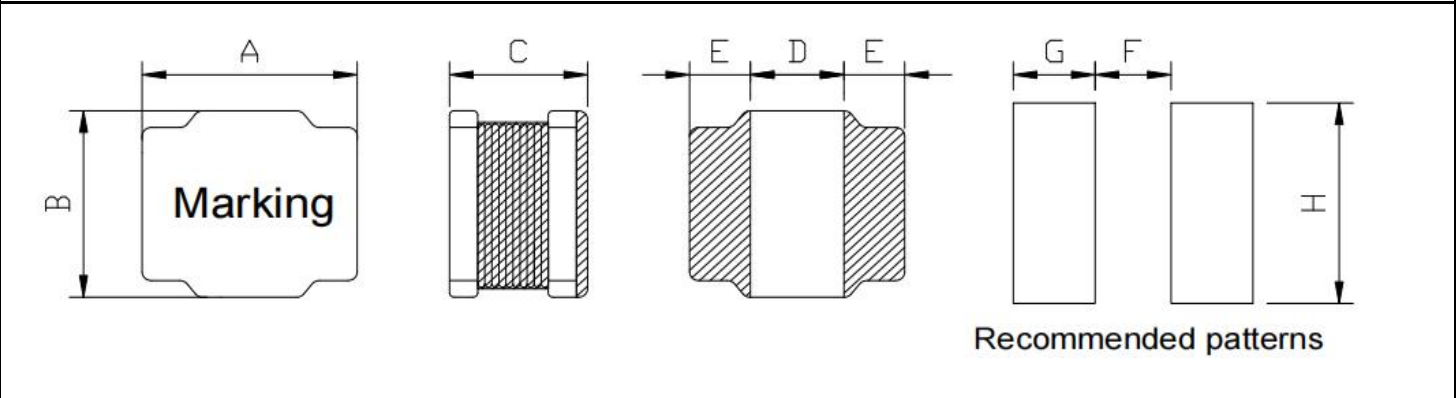

TYPE(型号)	A	B	C	D	E	F	G	H
NR6045	6.0±0.3	6.0±0.3	4.7Max	2.3±0.3	1.85±0.3	2.4	1.8	5.7

● SPECIFICATION TABLE:

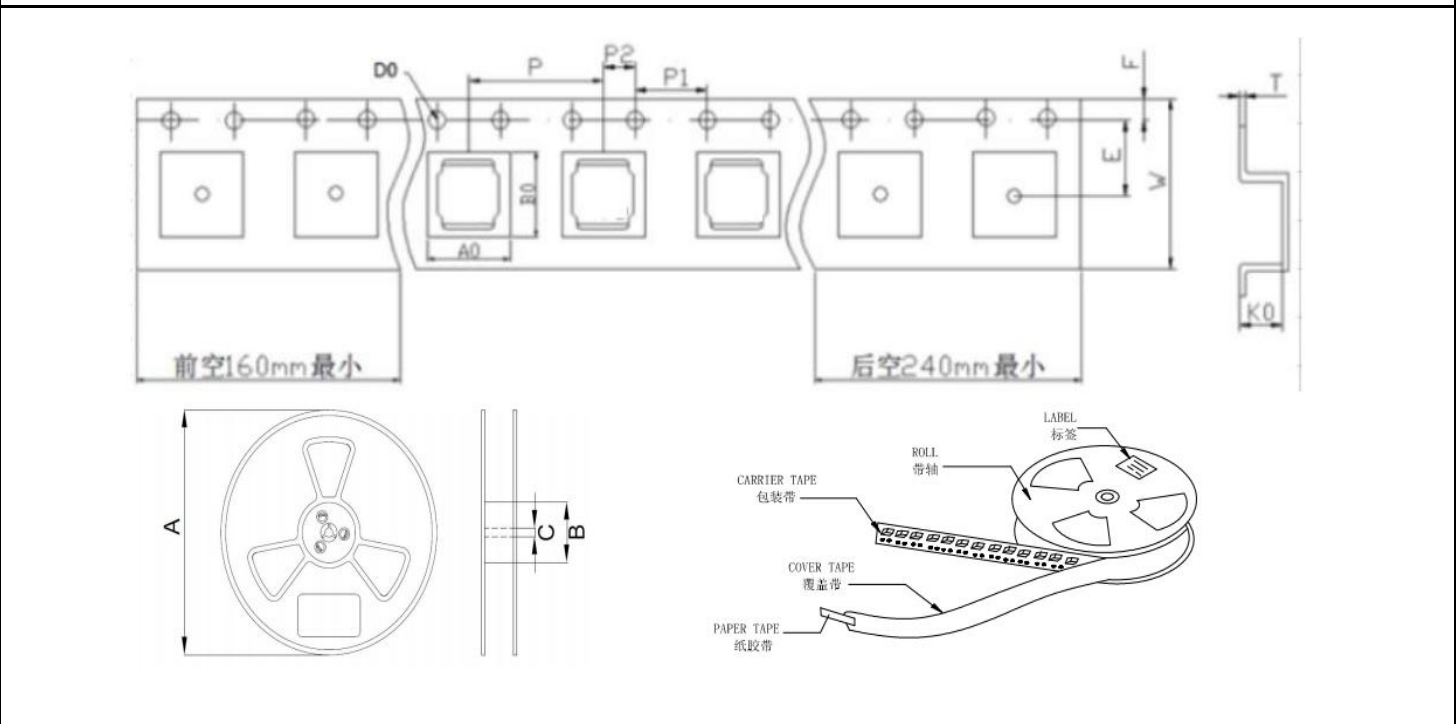

Type	Tape Dimension (mm)						Reel Dimension (mm)		
	W	A0	B0	K0	D	P	A	B	C
NR6045	16	6.4	6.4	4.8	1.5	8	330	100	13