


● SPECIFICATION TABLE:					
PART NUMBER 品名	INDUCTANCE (μ H) 电感值	DCR (Max) (Ω) 直流电阻	Isat (Max.) (A) 饱和电流	Irms (Max.) (A) 额定电流	S. R. F. (Min.) (MHz) 自谐频率
NR4030-1R0N	1.0 $\pm$ 30%	0.016	5.26	4.14	70.0
NR4030-1R5N	1.5 $\pm$ 30%	0.020	4.84	3.34	62.0
NR4030-2R2N	2.2 $\pm$ 30%	0.030	4.40	2.95	52.0
NR4030-3R3M	3.3 $\pm$ 20%	0.040	3.30	2.40	38.0
NR4030-4R7M	4.7 $\pm$ 20%	0.060	2.90	2.00	31.0
NR4030-6R8M	6.8 $\pm$ 20%	0.090	2.75	1.60	24.0
NR4030-100M	10 $\pm$ 20%	0.100	1.95	1.50	21.0
NR4030-150M	15 $\pm$ 20%	0.190	1.65	1.11	16.0
NR4030-220M	22 $\pm$ 20%	0.225	1.30	1.00	10.0
NR4030-330M	33 $\pm$ 20%	0.330	1.10	0.84	10.0
NR4030-470M	47 $\pm$ 20%	0.445	0.95	0.72	8.4
NR4030-680M	68 $\pm$ 20%	0.868	0.72	0.52	7.0
NR4030-101M	100 $\pm$ 20%	1.150	0.60	0.45	5.6
NR4030-151M	150 $\pm$ 20%	1.800	0.50	0.30	4.0
NR4030-221M	220 $\pm$ 20%	2.500	0.40	0.35	4.2
NR4030-331M	330 $\pm$ 20%	4.000	0.30	0.25	6.8
NR4030-471M	470 $\pm$ 20%	7.200	0.30	0.20	2.0
NR4030-681M	680 $\pm$ 20%	7.580	0.19	0.14	1.2


Remark:
 1. Inductance Tested at 1MHz, 0.25Vrms (20℃)
 2. Isat: DC current at which the inductance drops approximate 30% from its value without current;
 3. Irms: DC current that causes the temperature rise ($\Delta T = 40^{\circ}C$) from 25° C ambient.
 4. Operating Temperature : -25℃ ~ +125℃

● SHAPES AND DIMENSIONS 外形尺寸 (Unit:mm)

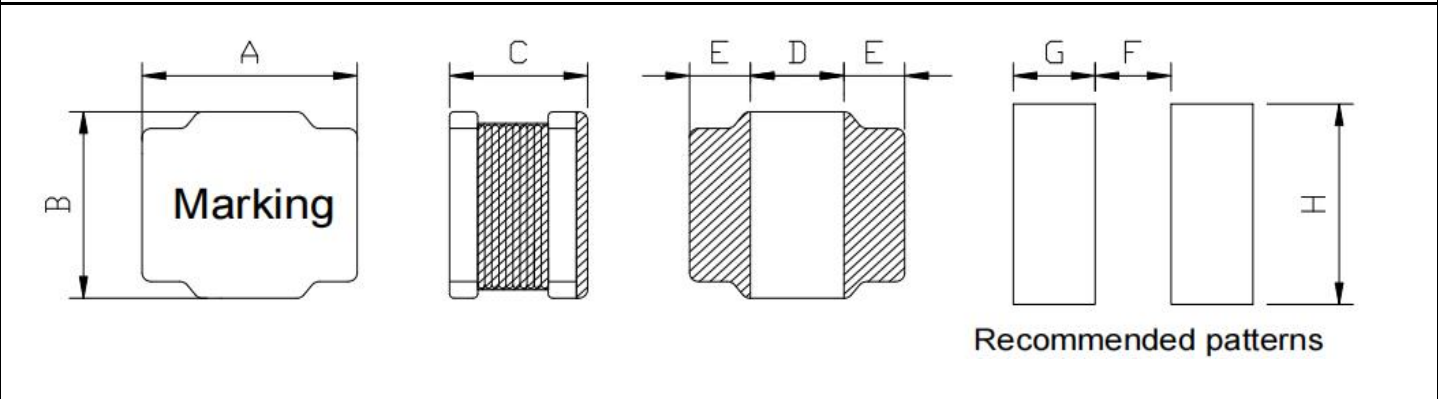

TYPE(型号)	A	B	C	D	E	F	G	H
NR4030	4.0±0.2	4.0±0.2	3.0Max	1.3±0.3	1.35±0.3	1.2	1.40	3.7

● SPECIFICATION TABLE:

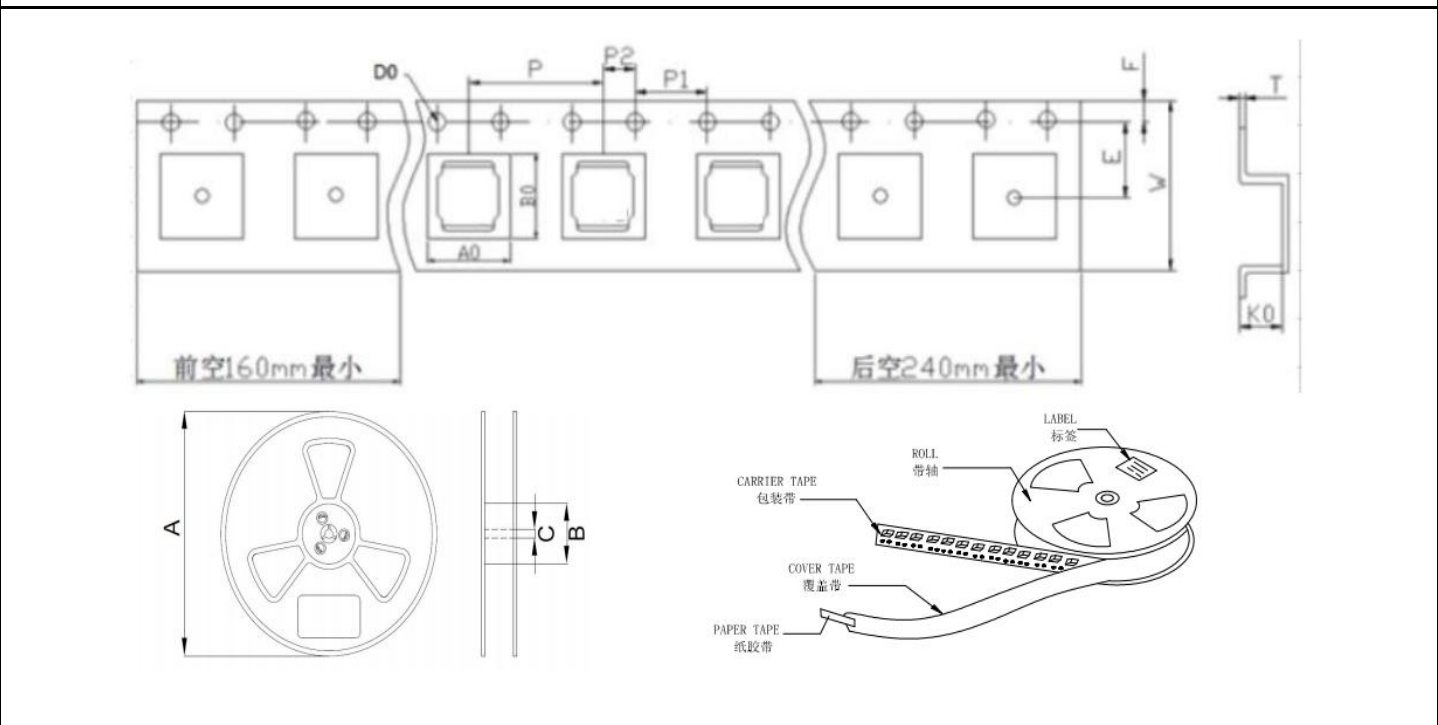

Type	Tape Dimension (mm)						Reel Dimension (mm)		
	W	A0	B0	K0	D	P	A	B	C
NR4030	12	4.3	4.3	3.4	1.5	8	330	100	13