



HBD26F

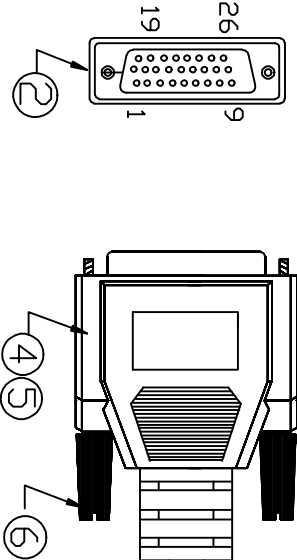

HBD26F

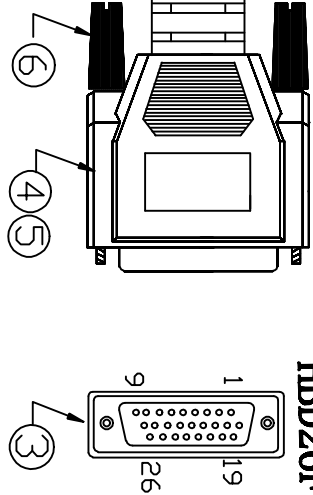

Connecting List:

HDB26F	HDB26F	HDB26F	HDB26F
1	1	15	15
2	2	16	16
3	3	17	17
4	4	18	18
5	5	19	19
6	6	20	20
7	7	21	21
8	8	22	22
9	9	23	23
10	10	24	24
11	11	25	25
12	12	26	26
13	13	S	S
14	14		


Inspection And Testing:

- 1、Product must be 100% testin 4 times , No short、No Open Circuit、And No Dislocation
- 2、Electronics Testing :Insulation Resistance : 5MΩ
- Conductor Resistance : 5Ω
- Voltage Rating : 300V

Material List:

Item	Part	Specifications	Unit	Q'TY
1	Cable	UL2919 28# 13P+1+B Black OD:7.0MM	PCS	1
2	Connector	HDB26 Female	PCS	1
3	Connector	HDB26 Female	PCS	1
4	InnerMolding	LDPE Transparent	Gram	
5	OuterMolding	45P PVC Black	Gram	
6	Screw	2.3*47	PCS	4

Customer No:	
Customer sign:	
Product Name:	HDB26F /F
Packing:	75 Bag/One PCS

 

Drawing No:	Data:	Approval:
Proportion: 2.5:1	Edition: A1	Drawing By: Zhangwei
Unit: MM	Confirm:	